

CAB 3™ marking system


markers for wiring and Viking 3 terminal blocks



Perfect alignment of label holders



0 382 12

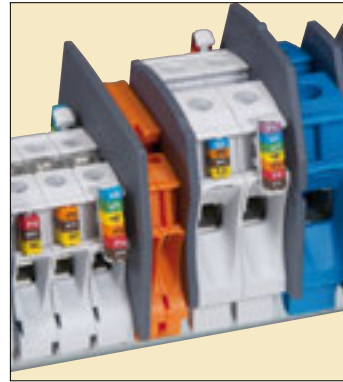

Terminal block with CAB 3 markers and label-holders

For marking wiring or Viking 3 terminal blocks

Pack	Cat.Nos		<p>Markers for wiring 0.15 to 0.5 mm² and 0.5 to 1.5 mm² cross-section and terminal blocks</p> <p>On Viking 3 terminal blocks - 4 markers 0.15 to 0.5 mm² max - 3 markers 0.5 to 1.5 mm² max. Pack: - Up to 0.5 mm²: strips of 25 markers From 0.5 mm² to 2.5 mm²: strips of 30 markers Price per marker</p> <p>Digits: international colour code</p>
	0.15 to 0.5 ²	0.5 to 1.5 ²	
1000	1200	0 381 00	0 382 10
1000	1200	0 381 01	0 382 11
1000	1200	0 381 02	0 382 12
1000	1200	0 381 03	0 382 13
1000	1200	0 381 04	0 382 14
1000	1200	0 381 05	0 382 15
1000	1200	0 381 06	0 382 16
1000	1200	0 381 07	0 382 17
1000	1200	0 381 08	0 382 18
1000	1200	0 381 09	0 382 19
Letters: black on yellow background			
300	0 381 10	0 383 00	A
300	0 381 11	0 383 01	B
300	0 381 12	0 383 02	C
300	0 381 13	0 383 03	D
300	0 381 14	0 383 04	E
300	0 381 15	0 383 05	F
300	0 381 16	0 383 06	G
300	0 381 17	0 383 07	H
300	0 381 18	0 383 08	I
300	0 381 19	0 383 09	J
300	0 381 20	0 383 10	K
300	0 381 21	0 383 11	L
300	0 381 22	0 383 12	M
300	0 381 23	0 383 13	N
300	0 381 24	0 383 14	O
300	0 381 25	0 383 15	P
300	0 381 26	0 383 16	Q
300	0 381 27	0 383 17	R
300	0 381 28	0 383 18	S
300	0 381 29	0 383 19	T
300	0 381 30	0 383 20	U
300	0 381 31	0 383 21	V
300	0 381 32	0 383 22	W
300	0 381 33	0 383 23	X
300	0 381 34	0 383 24	Y
300	0 381 35	0 383 25	Z
Conventional symbols: black on yellow background			
300	0 381 40	0 382 70	/
300	0 381 41	0 382 71	•
300	0 381 42	0 382 72	+
300	0 381 43	0 382 73	-
300	0 381 44	0 382 74	~
300	0 381 45	0 382 75	≡
300	0 381 46	0 382 76	⊕

Pack	Cat.Nos		<p>Markers for wiring 1.5 to 2.5 mm² and 4 to 6 mm² cross-section</p> <p>Pack: From 0.5 mm² to 2.5 mm²: strips of 30 markers - Upper 2.5 mm²: strips of 20 markers Price per marker</p> <p>Digits: international colour code</p>
	1.5 to 2.5 ²	4 to 6 ²	
1200	800	0 382 20	0 382 30
1200	800	0 382 21	0 382 31
1200	800	0 382 22	0 382 32
1200	800	0 382 23	0 382 33
1200	800	0 382 24	0 382 34
1200	800	0 382 25	0 382 35
1200	800	0 382 26	0 382 36
1200	800	0 382 27	0 382 37
1200	800	0 382 28	0 382 38
1200	800	0 382 29	0 382 39
Letters: black on yellow background			
300	0 383 30	0 383 60	A
300	0 383 31	0 383 61	B
300	0 383 32	0 383 62	C
300	0 383 33	0 383 63	D
300	0 383 34	0 383 64	E
300	0 383 35	0 383 65	F
300	0 383 36	0 383 66	G
300	0 383 37	0 383 67	H
300	0 383 38	0 383 68	I
300	0 383 39	0 383 69	J
300	0 383 40	0 383 70	K
300	0 383 41	0 383 71	L
300	0 383 42	0 383 72	M
300	0 383 43	0 383 73	N
300	0 383 44	0 383 74	O
300	0 383 45	0 383 75	P
300	0 383 46	0 383 76	Q
300	0 383 47	0 383 77	R
300	0 383 48	0 383 78	S
300	0 383 49	0 383 79	T
300	0 383 50	0 383 80	U
300	0 383 51	0 383 81	V
300	0 383 52	0 383 82	W
300	0 383 53	0 383 83	X
300	0 383 54	0 383 84	Y
300	0 383 55	0 383 85	Z
Conventional symbols: black on yellow			
300	0 382 80	0 382 90	/
300	0 382 81	0 382 91	•
300	0 382 82	0 382 92	+
300	0 382 83	0 382 93	-
300	0 382 84	0 382 94	~
300	0 382 85	0 382 95	≡
300	0 382 86	0 382 96	⊕