

German standard multi-socket plugs and extensions



0 506 56


3 902 33



0 503 77

Pack	Cat.Nos	2P multi-socket plugs - 6 A
10	0 506 50	For connection onto 2P+E socket Max. admissible power: 3.680 W at 230 V~ 4 side outlets ○ White ● Black
10	0 506 51	
10	0 506 55	2P+E multi-socket plugs - 16 A Max. admissible power 3.680 W at 230 V~ 2 front outlets ○ White/Grey 3 front outlets ○ White/Grey 2 side outlets With extraction button for easy disconnection of the plugs ○ White/Grey
10	0 506 56	
5	0 506 65	3 side outlets ○ White ○ Transparent
10	0 506 62	
10	0 506 63	
5	3 902 33	2P+E extension leads With shutters for child protection to allow easy insert of the plug in the socket and to ensure safety 2P+E ergonomic socket with easy disconnection H05 VVF 3G 1.5 mm ² cord Supplied with plastic hook for hanging with Gencod 3 m length ○ White 5 m length ○ White 10 m length ○ White
5	3 900 86	
5	3 902 34	
5	0 503 77	Multi-socket "octopus" extension leads ready to use - rubber ● Black - 2P+E - 16 A - IK 10 With 1 plug and 3 extensions H07 RNF 3G 1.5 and 2.5 mm ² cable Length: 0.8 m

German standard multi-outlet extensions without cord

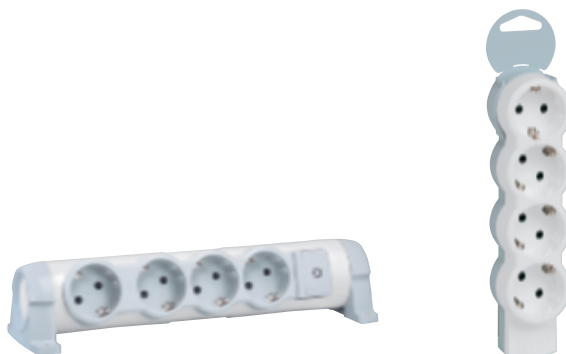

6 946 29

6 950 09

Pack	Cat.Nos	Multi-outlet extensions for comfort without cord
5	6 946 24	Sockets with child protection shutters tested to withstand 10000 operations Orientable socket outlets To be equipped with flexible cable of 3G 1.5 mm ² or 3G 1mm ² minimum On/off switch with a light indicator, can be operated by foot or by hand Maximum space between 2 sockets to connect transformers, chargers, etc. Direct wall-mounting possibilities (with screws) Possibility to manage the cable around the feet Supplied with self-gripping tie for grouping the cords of the connected devices 16 A max. power 3500 W at 230 V
5	6 946 29	
5	6 946 34	
5	6 946 39	
10	6 950 04	Standard multi-outlet extensions without cord To connect several devices equipped with plugs with or without earth: appliances class I (simple insulation) or class II (double insulation), lamps, PC, TV, stereo, etc. Ultra-flat: can be slid underneath furniture Wall-mounting possibilities with the packaging accessory 90° socket for connecting a transformer without blocking another socket 16 A max. power 3500 W at 230 V To be equipped with flexible cable of 3G 1.5 mm ² or 3G 1mm ² minimum
10	6 950 09	
10	6 950 14	
10	6 950 19	