



Cat.Nos for 35 x 105 trunking

 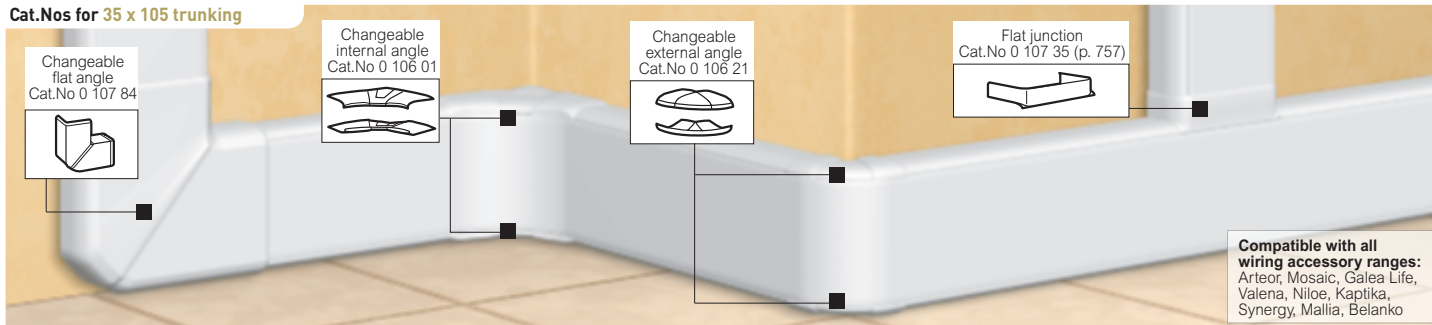


Cat.Nos for 50 x 105 trunking

 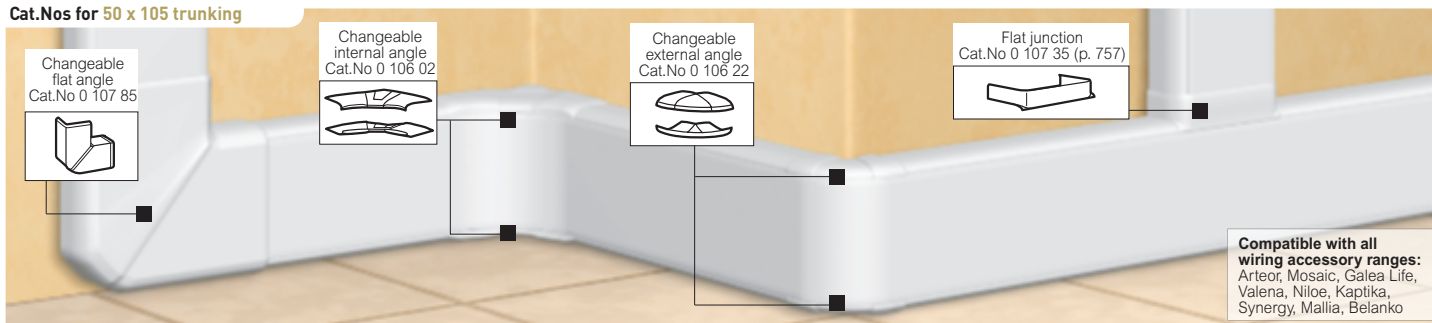


Selection chart **p. 752-753**
Wiring capacity chart **see e-catalogue**

Pack	Cat.Nos	Universal trunking 35 x 105
20'	0 104 63	Trunking without partition Supplied with: - one 35 x 105 mm body - one flexible 85 mm width cover Fits onto the whole trunking including in internal and external angles Installation: can be used with Mosaic/Arteor ranges or DIN rail equipment Length 2 m
24'	0 105 82	Partition Separation partition Length 2 m
20	0 106 91	Joints Body joint For aligning bases during installation
20	0 106 92	Body joint, attached with adhesive (fit at the end of installation)
10	0 108 02	Cover joint



Pack	Cat.Nos	Universal trunking 50 x 105
16'	0 104 64	Trunking without partition Supplied with: - one 50 x 105 mm body - one flexible 85 mm width cover Fits onto the whole trunking including in internal and external angles Installation: can be used with Mosaic/Arteor ranges or DIN rail equipment Length 2 m
24'	0 105 82	Partition Separation partition Length 2 m
20	0 106 91	Joints Body joint For aligning bases during installation
20	0 106 92	Body joint, attached with adhesive (fit at the end of installation)
10	0 108 02	Cover joint



Angles and end cap for universal trunking 35 x 105		
Internal and external bends Include the 2 components for the top and bottom of the trunking on which the flexible cover is fitted		
10	0 106 01	Changeable internal bend, from 85° to 95° for 35 x 80 and 35 x 105 mm trunking
10	0 106 21	Changeable external bend, from 60° to 120° for 35 x 80 and 35 x 105 mm trunking
10	0 107 84	Flat angle 90° flat angle
20	0 107 01	End cap For 35 x 105 mm trunking

Angles and end cap for universal trunking 50 x 105		
Internal and external bends Include the 2 components for the top and bottom of the trunking on which the flexible cover is fitted		
10	0 106 02	Changeable internal bend, from 85° to 95° for 50 x 80/50 x 105/50 x 150 and 50 x 195 mm trunkings
10	0 106 22	Changeable external bend, from 60° to 120° for 50 x 80/50 x 105/50 x 150 and 50 x 195 mm trunkings
10	0 107 85	Flat angle 90° angle For 50 x 105 mm trunking
20	0 107 02	End cap For 50 x 105 mm trunking

1: Number of metres in pack