



Legrand cabling system LCS² category 6

cables and cords

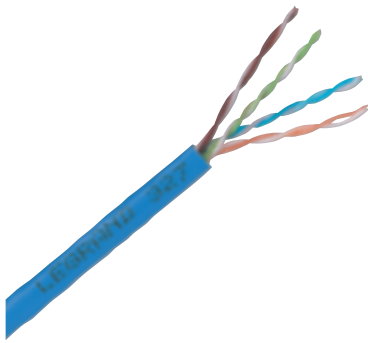

0 327 54

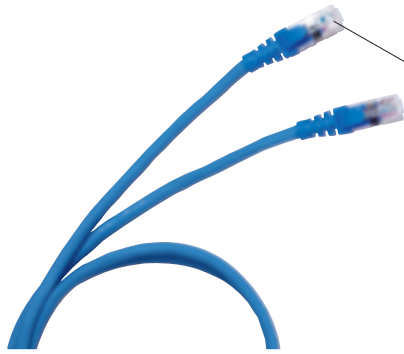

0 517 62



New plug
Convenient for gripping

Pack	Cat.Nos	Cables for local networks cat. 6
		Cables 4 pairs or 2 x 4 twisted pairs 100 ohms Blue RAL 5015 Colour code TIA/EIA Conform to standards ISO/IEC 11801 Ed. 2.0, EN 50173-1 and TIA/EIA 568C
		U/UTP - 4 pairs
305 ¹	0 327 54	Length 305 m Supplied in cardboard box. Weight 16 kg
500 ¹	0 328 61	Length 500 m Supplied on reel. Weight 18 kg
305 ¹	0 327 55	Length 305m Supplied in cardboard box. Weight 13 kg
		U/UTP - 2 x 4 pairs
500 ¹	0 328 63	Length 500 m Supplied in cardboard box. Weight 38 kg
		F/UTP - 4 pairs
305 ¹	0 328 56	Length 305 m Supplied on reel. Weight 17 kg
500 ¹	0 327 56	Length 500 m Supplied on reel. Weight 25 kg
		F/UTP - 4 pairs
305 ¹	0 328 57	Length 305 m Supplied in cardboard box. Weight 17 kg
500 ¹	0 327 58	Length 500 m Supplied on reel. Weight 25 kg
		F/UTP - 2 x 4 pairs
500 ¹	0 327 76	Length 500 m Supplied on reel. Weight 48 kg
		SF/UTP - 4 pairs
500 ¹	0 327 57	Length 500 m Supplied on reel. Weight 29 kg
500 ¹	0 327 59	Length 500 m Supplied on reel. Weight 30 kg

1: in meter(s)

Pack	Cat.Nos	RJ 45 patch cords and user cords cat. 6
		RJ 45 - RJ 45 right
		U/UTP unscreened impedance 100 Ω
		PVC
1	0 518 18	Length 0.5 m
1	0 517 72	Length 1 m
1	0 517 73	Length 2 m
1	0 517 74	Length 3 m
1	0 517 75	Length 5 m
		LSZH
1	0 518 62	Length 1 m
1	0 518 63	Length 2 m
1	0 518 64	Length 3 m
1	0 518 65	Length 5 m
		PVC
		F/UTP screened impedance 100 Ω
1	0 518 15	Length 0.5 m
1	0 517 62	Length 1 m
1	0 517 63	Length 2 m
1	0 517 64	Length 3 m
1	0 517 65	Length 5 m
		LSZH
1	0 518 54	Length 1 m
1	0 518 55	Length 2 m
1	0 518 56	Length 3 m
1	0 518 57	Length 5 m
		PVC
		SF/UTP shielded impedance 100 Ω
5	0 517 52	Length 1 m
5	0 517 53	Length 2 m
5	0 517 54	Length 3 m
5	0 517 55	Length 5 m