


## Legrand cabling system LCS<sup>2</sup> category 5e patch panels, blocks of connectors



0 335 52

Pack	Cat.Nos	Patch panels cat. 5e 24 x RJ 45 connectors
		<p>Panels supplied with quick-fixing Panels ensure automatic grounding of each connector Fitted with rear cable guide to hold cables during maintenance Fitted with 4 units of 6 LCS<sup>2</sup> RJ 45 connectors cat 5e with fast connection thanks to integrated crimping, with colour code and wiring schemes T 568 A and T 568 B Supplied with colour labels numbered from 1 to 24 Conform to standards ISO/IEC 11801 Ed. 2.0, EN 50173-1 and TIA/EIA 568 19" panel - 1 U</p> <p><b>UTP panel</b> 1 0 335 51 UTP panel - 8 contacts 1 0 335 83 UTP high density panel - 8 contacts - connection with 110 tool</p> <p><b>FTP panel</b> 1 0 335 52 FTP panel - 9 contacts</p> <p><b>UTP through panel</b> 1 0 335 88 24 RJ 45 connectors UTP through panel</p>
		<p><b>Modular panels</b> Panels supplied with fast assembly Panels ensure automatic grounding of each connector Fitted with rear cable guide to hold cables during maintenance Modular empty panels for up to 4 units Takes the following equipment: - units of 6 LCS<sup>2</sup> RJ 45 connectors - units for telephone inlets - fibre optic units - PoE injector units - video streaming units - switch units - telephone/Ethernet doubler units - copper/fibre optic converter units - blanking plates 1 0 335 90 19" panel - 1 U</p>
		<p><b>Units of 6 x RJ 45 connectors cat. 5e</b> Fitted with 6 x LCS<sup>2</sup> RJ 45 connectors cat. 5e with fast connection thanks to integrated crimping, with colour code and wiring schemes T 568 A and T 568 B Supplied with colour labels Conforms to standards ISO/IEC 11801 Ed. 2.0, EN 50173-1 and TIA/EIA 568 2 0 335 54 UTP unit 2 0 335 55 FTP unit 10 0 335 91 Blanking plate for 19" panel - Black</p>

## Legrand cabling system LCS<sup>2</sup> category 5e cables and cords

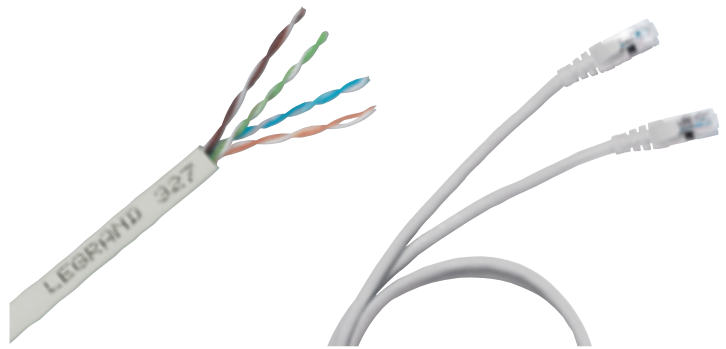

0 328 50

0 516 40

Pack	Cat.Nos	Cables for local networks cat. 5e
		<p>4 twisted pair cables 100 ohms LSZH sleeve: non-halogen Grey RAL 7035 Colour code TIA/EIA</p> <p><b>U/UTP - 4 pairs</b> Length 305m Supplied in cardboard box. Weight 10 kg Length 500 m Supplied on reel. Weight 15 kg</p> <p>305<sup>1</sup> 0 327 51 LSZH PVC 0 327 51 Length 305m Supplied in cardboard box. Weight 9 kg</p> <p><b>U/UTP - 2 x 4 pairs</b> Length 500 m Supplied on reel</p> <p><b>F/UTP - 4 pairs</b> Length 305 m Supplied in cardboard box. Weight 12 kg Length 500 m Supplied on reel. Weight 21 kg</p> <p>305<sup>1</sup> 0 327 52 LSZH PVC 0 327 53 Length 305 m Supplied by box. Weight 11 kg</p> <p><b>F/UTP - 2x4 pairs</b> Length 500 m Supplied on reel. Weight 38 kg</p>
		<p><b>RJ 45 patch cords and user cords cat. 5e</b> RJ 45 - RJ 45 right</p> <p><b>U/UTP unshielded impedance 100 Ω</b> Grey Length 0.5 m 1 0 518 17 Length 1 m 1 0 516 36 Length 2 m 1 0 516 37 Length 3 m 1 0 516 38 Length 5 m 1 0 516 39</p> <p><b>F/UTP shielded impedance 100 Ω</b> Grey Length 0.5 m 1 0 518 14 Length 1 m 1 0 516 40 Length 2 m 1 0 516 41 Length 3 m 1 0 516 42 Length 5 m 1 0 516 43</p>

1: in metre(s)