


RCBOs DX™ **10000** - blue neutral lead

cross reference list old range / new range

RCBOs DX³ **6000** - 6 kA

residual current circuit breakers from 6 A to 32 A - A type

Nominal rating I _n (A)	Cat. Nos	
	Old range DX	New range DX ³
6	-	4 189 80
10	6 064 10	4 189 81
16	6 064 11	4 189 82
20	6 064 12	4 189 83
25	6 064 13	4 189 84
32	6 064 14	4 189 85
40	-	4 189 86
45	6 064 15	4 189 87

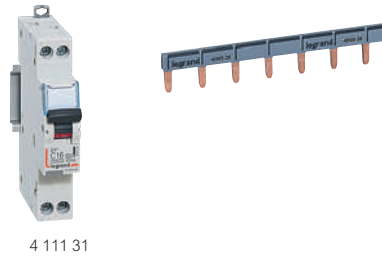

Technical characteristics [see e-catalogue](#)

Conform to IEC 61009-1
 Compatible with prong-type supply busbars
 Voltage dependent tripping
 Breaking capacity:
6000 - IEC 61009-1 - 6 kA / IEC 60947-2 for single pole + neutral
 • A type : detect AC and DC component faults
 Enhanced immunity to unwanted tripping in disturbed environments
 Can be equipped with DX³ signalling and remote tripping auxiliaries and motorised controls (p. 72)

Pack	Cat.Nos	Single pole + neutral - 230 V~	
		Neutral on left-hand side	
		A Type	10 mA
	C curve	Nominal rating I _n (A)	Number of modules
1	4 111 21	6	1
1	4 111 22	10	1
1	4 111 24	16	1
1	4 111 25	20	1
1	4 111 26	25	1
1	4 111 27	32	1
		A Type	30 mA
1	4 111 28	6	1
1	4 111 29	10	1
1	4 111 31	16	1
1	4 111 32	20	1
1	4 111 33	25	1
1	4 111 34	32	1