


# CX<sup>3</sup> changeover switches, push-buttons, control switches and LED indicators

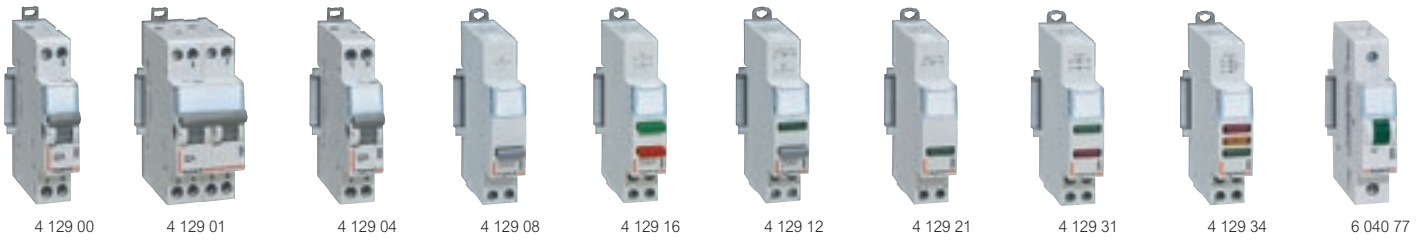

Technical characteristics [see e-catalogue](#)

| Pack | Cat.Nos  | Changeover switches   | Number of modules |
|------|----------|---|-------------------|
| 10   | 4 129 00 | Conform to IEC 60669-1<br>Nominal rating 32 A<br>Compatible with fluorescent lamps (20 AX)<br><b>Two-way - 250 V~</b><br>Connection | 1                 |
| 5    | 4 129 01 | <b>Double two-way - 400 V~</b><br>Connection  | 2                 |
| 10   | 4 129 02 | <b>Two way with centre point - 250 V~</b><br>Connection   | 1                 |
| 5    | 4 129 03 | <b>Double two way with centre point - 250 V~</b><br>Connection  | 2                 |
| 10   | 4 129 04 | <b>Switch NO + NC - 250 V~</b><br>Connection  | 1                 |

| Pack | Cat.Nos  | Momentary contact push-buttons   | Number of modules |
|------|----------|--|-------------------|
| 10   | 4 129 08 | Conform to IEC 60669-1<br>Nominal rating 20 A - 250 V~<br>Compatible with fluorescent lamps (20 AX)<br>Accept prong-type supply busbars<br><b>Single function push-buttons</b><br>1 NO<br>Connection | 1                 |
| 10   | 4 129 09 | 1 NC<br>Connection   | 1                 |
| 10   | 4 129 16 | <b>Dual functions push-buttons without indicator</b><br>1 NO (green push-button)<br>+ 1 NC (red push-button)<br>Connection   | 1                 |
| 10   | 4 129 18 | <b>Dual functions push-buttons with indicator</b><br>1 NO + green LED indicator<br>12/48 V~/=  | 1                 |
| 10   | 4 129 19 | 1 NC + red LED indicator<br>12/48 V~/=   | 1                 |
| 10   | 4 129 20 | 1 NO + green LED indicator<br>100/400 V~   | 1                 |
| 10   | 4 129 40 | 1 NC + red LED indicator<br>100/400 V~   | 1                 |

| Pack | Cat.Nos  | Maintained contact control switches  | Number of modules |
|------|----------|--|-------------------|
| 10   | 4 129 10 | Conform to IEC 60669-1<br>Nominal rating 20 A - 250 V~<br>Compatible with fluorescent lamps (20 AX)<br>Maximum power with self-ballasted lamps (SBL): 250 W<br>Accept prong-type supply busbars<br><b>Single function control switches</b><br>2 NO<br>Connection | 1                 |
| 10   | 4 129 11 | 1 NO + NC<br>Connection  | 1                 |
| 10   | 4 129 12 | <b>Dual functions control switches with indicator</b><br>1 NO + green LED indicator<br>12/48 V~/=  | 1                 |
| 10   | 4 129 13 | 1 NC + red LED indicator<br>12/48 V~/=   | 1                 |
| 10   | 4 129 14 | 1 NO + green LED indicator<br>110/400 V~   | 1                 |
| 10   | 4 129 15 | 1 NC + red LED indicator<br>110/400 V~   | 1                 |

| Pack | Cat.Nos  | LED indicators  | Number of modules |
|------|----------|---|-------------------|
| 10   | 4 129 21 | Equipped with non replaceable LED lamps<br>LED life: 100 000 h<br>LED consumption: 0.17 W under 230 V~/<br>0.11 W under 24 V~<br>Conform to IEC 60947-5-1<br>Accept prong-type supply busbars<br><b>Single - 12/48 V~/=</b><br>Connection | 1                 |
| 10   | 4 129 22 | ● Green   | 1                 |
| 10   | 4 129 23 | ● Red   | 1                 |
| 10   | 4 129 24 | ● Yellow  | 1                 |
| 10   | 4 129 25 | ● Blue  | 1                 |
| 10   | 4 129 25 | ○ White   | 1                 |
| 10   | 4 129 26 | <b>Single - 110/400 V~</b><br>● Green   | 1                 |
| 10   | 4 129 27 | ● Red   | 1                 |
| 10   | 4 129 28 | ● Yellow  | 1                 |
| 10   | 4 129 29 | ● Blue  | 1                 |
| 10   | 4 129 30 | ○ White   | 1                 |
| 10   | 4 129 41 | <b>Double - 12/48 V~</b><br>● ● Green/Red<br>Connection   | 1                 |
| 10   | 4 129 31 | <b>Double - 110/400 V~</b><br>● ● Green/Red<br>Connection   | 1                 |
| 10   | 4 129 32 | <b>Triple - 230/400 V~</b><br>○ ○ ○ White   | 1                 |
| 10   | 4 129 33 | ● ● ● Red   | 1                 |
| 10   | 4 129 34 | ● ● ● Red/Yellow/Green  | 1                 |
| 10   | 4 129 35 | ● ● ● Red/Yellow/Blue   | 1                 |

| Pack | Cat.Nos  | TX <sup>3</sup> LED indicators - 230 V~                                | Number of modules |
|------|----------|--|-------------------|
| 12   | 6 040 77 | Equipped with non replaceable LED lamps<br><b>Single</b><br>Connection | 1                 |
| 12   | 6 040 78 | ● Green  | 1                 |
| 12   | 6 040 79 | ● Red  | 1                 |
| 12   | 6 040 79 | ● Orange   | 1                 |