



## DPX<sup>3</sup> 160 and 250 common auxiliaries and accessories

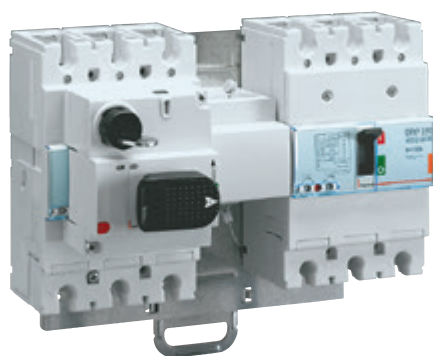

4 210 58



 4 210 00



4 210 10



4 210 11



4 210 16



4 210 22

Pack	Cat.Nos	
		<b>Fixing plates for transfer switches</b>
1	4 210 58	Plate for mounting and interlocking of 2 DPX <sup>3</sup> For 2 DPX <sup>3</sup> 160 or 2 DPX <sup>3</sup> 250 or 1 DPX <sup>3</sup> 160 and 1 DPX <sup>3</sup> 250 For fixed version
		<b>Rotary handles</b>
		<b>Direct on DPX</b>
1	4 210 00	Standard handle for thermal magnetic DPX <sup>3</sup> without earth leakage module
1	4 210 01	Standard handle for electronic DPX <sup>3</sup> and/or with earth leakage module
1	4 210 02	Handle for emergency use for thermal magnetic DPX <sup>3</sup> without earth leakage module
1	4 210 03	Handle for emergency use for electronic DPX <sup>3</sup> and/or with earth leakage module
		<b>Vari-depth handles</b>
		For all version of DPX <sup>3</sup>
1	4 210 04	Standard handle
1	4 210 05	Handle for emergency use
		<b>Locking accessories</b>
1	4 228 00	Key barrel and Ronis key EL43525 for direct handle
1	4 228 01	Key barrel and Ronis key EL43363 for direct handle
1	4 228 02	Key barrel and Ronis key EL43525 for vari-depth handle
1	4 228 03	Key barrel and Ronis key EL43363 for vari-depth handle
1	4 210 06	Key barrel and flat key N° ABA90GEL6149 for direct handle
1	4 210 07	Key barrel and star key N° HBA90GPS6149 for direct handle
1	4 210 08	Key barrel and flat key N° ABA90GEL6149 for vari-depth handle
1	4 210 09	Key barrel and star key N° HBA90GPS6149 for vari-depth handle
		<b>Motor-driven handles</b>
		<b>Motor operators 24 to 230 V~/=</b>
1	4 210 60	Side motor operator
		<b>Locking accessories</b>
1	4 210 65	Key barrel and flat key N° ABA90GEL6149 for side motor operator
1	4 210 66	Key barrel and star key N° HBA90GPS6149 for side motor operator
1	4 210 67	Padlock for side motor operator

Pack	Cat.Nos	
		<b>Auxiliary contact or fault signal</b>
1	4 210 10	1 N/C + 1 N/O auxiliary contact for rotary handles
1	4 210 11	Auxiliary contact or fault signalling contact
		<b>Shunt releases</b>
		Allow remote tripping of a DPX <sup>3</sup> /DPX <sup>3</sup> -I 160 and 250
1	4 210 12	12 V~/=
1	4 210 13	24 V~/=
1	4 210 14	48 V~/=
1	4 210 15	110-130 V~
1	4 210 16	200-277 V~
1	4 210 17	380-480 V~
		<b>Undervoltage releases</b>
		Allow remote tripping of a DPX <sup>3</sup> /DPX <sup>3</sup> -I 160 and 250
1	4 210 18	12 V~/=
1	4 210 19	24 V~/=
1	4 210 20	48 V~/=
1	4 210 21	110-130 V~/=
1	4 210 22	200-240 V~
1	4 210 23	277 V~
1	4 210 24	380-415 V~
1	4 210 25	440-480 V~
		<b>Time lag (800 ms) undervoltage release</b>
		Allow remote tripping of a DPX <sup>3</sup> /DPX <sup>3</sup> -I 160 and 250 Prevents false tripping in the event of power supply microbreaks
		<b>Time-lag modules</b>
1	0 261 90	230 V~
1	0 261 91	400 V~
		<b>Release</b>
		To be equipped with a time-lag module Cat.Nos 0 261 90/91 For DPX <sup>3</sup> /DPX <sup>3</sup> -I 160 and 250
1	4 210 98	
		<b>Locking accessory</b>
1	4 210 49	Padlock for locking in "open" position

