


Convivio™ 3-phase distribution boards

technical characteristics

■ Dimensions


Distribution boards from 12 to 24 poles (outgoing terminals)

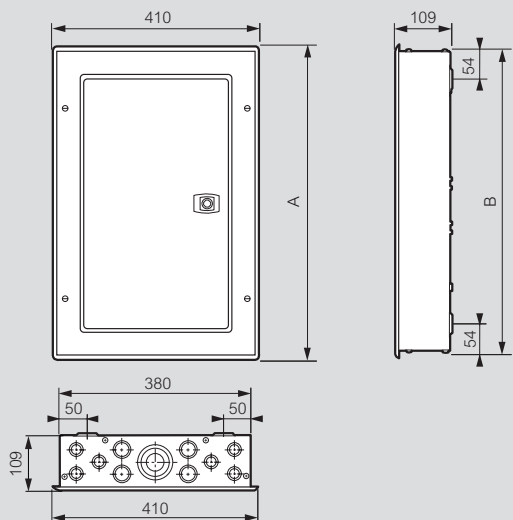

Cat.Nos	Number of poles	Dimensions (mm)	
		A	B
6 044 00	12	622	594
6 044 01	18	676	648
6 044 02	24	730	702
6 044 30	12	622	594
6 044 31	18	676	648
6 044 32	24	730	702
6 044 40	18	622	594
6 044 41	24	676	648

Number of knockouts	Size of the knockouts		
	∅18 / ∅27 mm	∅27 / ∅32 mm	∅32 / ∅52 / ∅65 mm
Top	2	2	1
Bottom	2	2	1

Distribution boards from 30 to 54 poles (outgoing terminals)

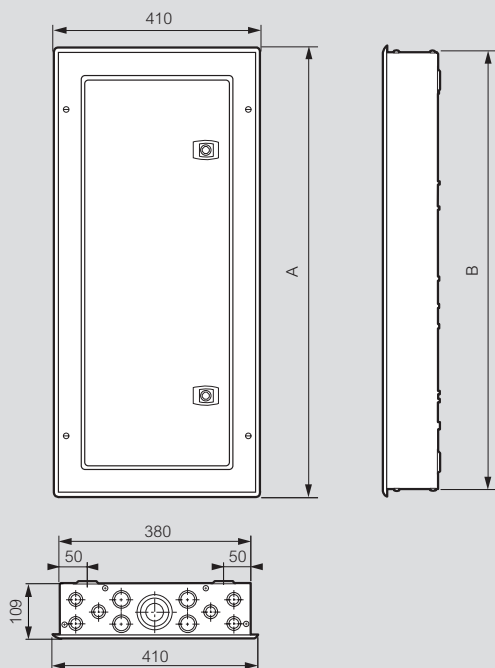

Cat.Nos	Number of poles	Dimensions (mm)	
		A	B
6 044 03	30	784	756
6 044 04	36	838	810
6 044 05	42	892	864
6 044 06	48	946	918
6 044 07	54	1000	972
6 044 33	30	784	756
6 044 34	36	838	810
6 044 35	42	892	864
6 044 36	48	946	918
6 044 37	54	1000	972
6 044 42	30	784	756
6 044 43	36	838	810
6 044 44	42	892	864
6 044 45	48	946	918
6 044 46	54	1000	972

Number of knockouts	Size of the knockouts		
	∅18 / ∅27 mm	∅27 / ∅32 mm	∅32 / ∅52 / ∅65 mm
Top	2	2	1
Bottom	2	2	1