


Equipment for XL³ 4000

for mounting on fixed plate : DPX³ 160 and DPX³ 250

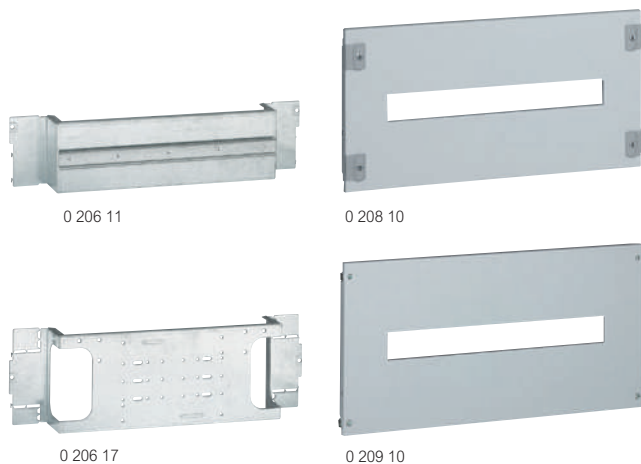


Pack	Cat.Nos	
		Plates for fixed version DPX³ 160/250 with front terminals
		Direct fixing on functional uprights
		Devices in vertical position
1	24 modules 0 206 11	Equipped with a rail for fixing DPX ³ . The DPX ³ must be equipped with a fixing plate Cat.Nos 4 210 68/69/71/72 or plate for manual supply inverter Cat.No 4 210 58. Designed for simultaneous mounting of DPX ³ 160/250 and modular equipment (with spacer Cat.No 0 262 99)
1	36 modules 0 206 61	
1	0 206 08	Plate for DPX ³ with direct rotary handle. The DPX ³ must be equipped with a fixing plate Cat.Nos 4 210 68/69
1	0 206 13	Plate for motor-driven transfer switch. The transfer switch must be equipped with a fixing plate Cat.Nos 4 210 58
		Devices in horizontal position
		For cut-out protection for cable passing, use seal Cat.No 0 202 40 (p. 275)
1	24 modules 0 206 15	For 1 DPX ³ 160
1	0 206 17	For 1 DPX ³ 250

		Metal faceplates
		For DPX³ in vertical position without direct rotary handle
1	24 modules 0 208 10 ¹	1/4 turn
1	0 209 10 ²	With captive screws
1	0 209 27	With captive screws for DPX ³ 250 with terminal shields
		For DPX³ in vertical position with direct rotary handle
1	24 modules 0 208 05 ¹	1/4 turn
1	0 209 05 ²	With captive screws
		For DPX³ 160
1	0 208 13 ¹	1/4 turn
1	0 209 13 ²	With captive screws
		For DPX³ 250
1	0 208 17 ¹	1/4 turn
1	0 209 17 ²	With captive screws

1: For fastening and sealing
2: Hinges Cat.No 0 209 59 available as an option

Equipment for XL³ 4000

for mounting on fixed plate: DPX³ 630 and DPX³ 1600

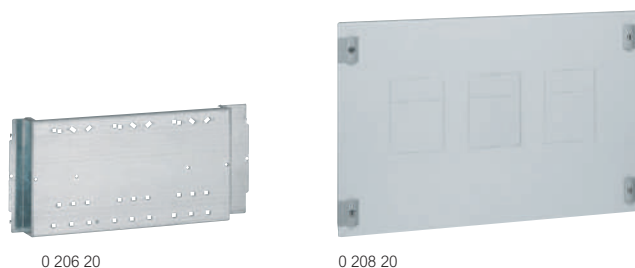

Pack	Cat.Nos	
		Plates for fixed version DPX³ 630/1600, with front terminals
		Direct fixing on functional uprights
		Devices in vertical position
1	24 modules 0 206 20 ¹	For 1 to 3 DPX ³ 630
1	36 modules 0 206 70	For 1 to 3 DPX ³ 630 with earth leakage module
1	0 211 00	For 1 DPX IS 1600 or 1 DPX ³ 1600 front terminal
		Devices in horizontal position
		For cut-out protection for cable passing, use seal Cat.No 0 202 40 (p. 275)
1	0 206 23	For 1 DPX ³ 630 with or without earth leakage module
1	0 211 00	For 1 DPX IS 1600 or 1 DPX ³ 1600 front terminal
		Metal faceplates for devices in vertical position
		For 1 to 3 DPX³ 630 only
1	24 modules 0 208 20 ²	1/4 turn
1	0 209 20 ³	With captive screws
		For 1 to 3 DPX³ 630 with downstream earth leakage module
1	0 208 22 ²	1/4 turn
1	0 209 22 ³	With captive screws
		For 1 DPX³ 1600
1	0 211 10 ²	1/4 turn
1	0 211 11 ³	With captive screws

		Metal faceplates for devices in vertical position
		For 1 DPX³ 630 with or without earth leakage module without motor
1	24 modules 0 208 23 ²	1/4 turn
1	0 209 21 ³	With captive screws
		For 1 DPX³ 630 with or without earth leakage module with motor
1	0 209 23 ³	With captive screws
		For 1 DPX³ 1600
1	24 modules 0 208 34 ³	1/4 turn
1	36 modules 0 209 34 ³	With captive screws

1: For 2 DPX 630 4P
2: For fastening and sealing
3: Hinges Cat.No 0 209 59 available as an option