


Equipment for Marina cabinets

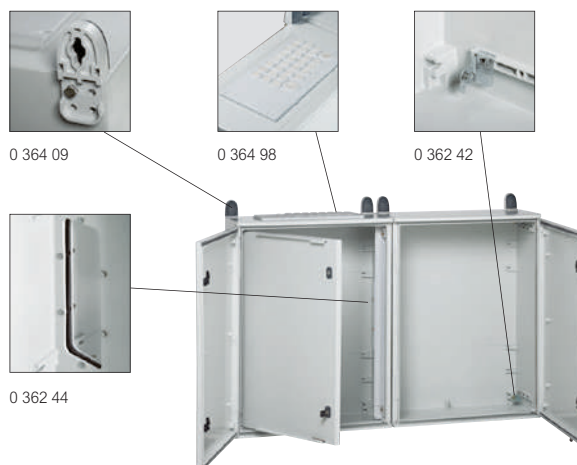


Example of cabinets Cat.No 0 362 61 associated and equipped:

- Lugs Cat.No 0 364 09
- Internal door Cat.No 0 363 63 (p. 308)
- Cabstop plate + kit Cat.No 0 364 98 (p. 291)
- Twin kit Cat.No 0 362 44
- Depth adjustment kit Cat.No 0 362 42

Cabinet and equipment selection chart **p. 288**
Technical characteristics **p. 301**

Pack	Cat.Nos	Plinths RAL 7035
1	0 362 91	Height 170 mm
1	0 362 92	Front and rear trap door
		Possibility to overlap 2 plinths
		For cabinets Cat.Nos 0 362 61/81
		For cabinets Cat.Nos 0 362 61/64/83/84
Roofs RAL 7035		
1	0 362 93	For cabinets Cat.Nos 0 362 56/76
1	0 362 94	For cabinets Cat.Nos 0 362 61/81
1	0 362 95	For cabinets Cat.Nos 0 362 61/64/83/84
Fixing accessories		
		IP 66 maintained
Wall mounting lugs		
		Set of 4, supplied with screws
1	0 364 08	For cabinets height 300 mm. For 100 kg load
1	0 364 09	For cabinets height 400 and 1200 mm. For 150 kg load
Rear with threaded rod		
10	0 362 40	M8 for cabinets height \geq 400 mm
		Mounting at back of cabinets
On ground		
		Stand comprised of 2 feet for fixing cabinets high up
		Supplied with cabinet fixing screws
		Hot galvanized steel
		Conform to EN 50125-3 (railway applications, fixed installations)
		For Atlantic, Atlantic stainless steel and Marina cabinets
1	0 364 36	For cabinets height 400 to 800 mm
1	0 364 37	For cabinets height 1000 to 1200 mm
1	0 364 39	Anti-tipping cross-pieces
		Option of fitting casters Cat.No 0 464 83
Vertical / horizontal on pole		
		For Atlantic, Atlantic stainless steel, and Marina enclosures and P17 combined units (p. 386)
		Features of the pole kit:
		- box / pole spacing = 30 mm
		- clamping the strip with tool Cat.No 0 364 45
		Load capacity: 300 kg
		Composed of:
		- 2 hot-dip galvanized steel crosspieces
		- 2 stainless steel strips length: 1200 mm, with integrated clip
		- screws
1	0 364 46	For enclosures width 300 mm
1	0 364 47	For enclosures width 400 mm
1	0 364 48	For enclosures width 500 mm
1	0 364 49	For enclosures width 600 mm
Cutter clamp tool		
1	0 364 45	Allows to stretch and cut the steel strips
		Supplied in a briefcase

Pack	Cat.Nos	Accessories
1	0 362 42	Depth adjustment kit for cabinets depth \geq 200 mm, for plate or uprights (p. 305)
10	0 394 49	Set of 4 lugs, supplied with screws
		Set of 2 supports for 45° rail slope
		Supplied with 4 M6 screws, nuts and washers
1	0 364 98	Kit for mounting Cabstop plate on plain plate
		Enables mounting of 2 Cabstop plates: Cat.Nos 0 364 94 or 95, and 0 364 96 or 97
		IP 55 maintained
1	0 362 44	Twin kit (horizontal or vertical) for cabinets \geq 500 mm height
		Comprising:
		- 1 frame for cable crossing and weather proofing
		- 2 linking pieces for fixing lugs (Cat.No 0 364 09 to be ordered separately)
1	0 365 13	Padlock adaptor stainless steel for Marina cabinets height \geq 400 mm
		additional to latches
		Takes 3 padlocks \varnothing 6 max.
Casters		
1	0 464 83	Set of 4 pivoting casters
		Total permissible load on the 4 casters: 380 kg

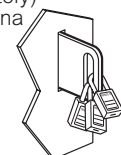

IP 66 ventilation glands for cabinets **p. 313**

