


# Equipment for Marina enclosures

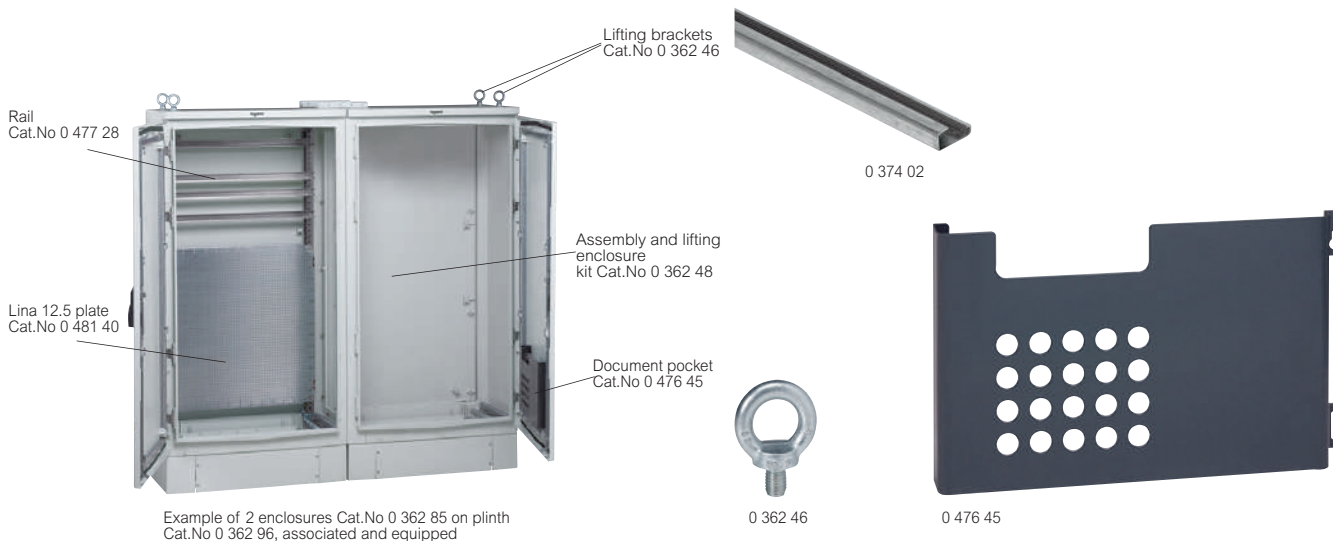

Example of 2 enclosures Cat.No 0 362 85 on plinth Cat.No 0 362 96, associated and equipped

Pack	Cat.Nos	Equipment
		<b>Plain plates</b> Galvanized steel. Pre-marked pitch 100 mm Admissible load: 200 kg/m <sup>2</sup>
		For enclosures
		Height x Width (mm)   Net weight (kg)
1	0 349 59	1400 x 800   27
1	0 349 50	1600 x 800   30.5
1	0 344 18	1800 x 800   34
		<b>Lina 12.5 plates</b> Galvanized steel With drilling for fixing equipment without marking Automatic bracket: - Ø6.5 mm for plastic rivet Cat.No 0 366 44 (trunking) - Ø3.3 mm for equipment with screw Cat.No 0 347 45 For installation of Cat. No 0 481 40/43, use Lina 25 sectioned uprights (p. 305) Cat. No 0 364 08 can be fixed directly on the back of the enclosure (1400 mm height enclosures) Admissible load: 150 kg/m <sup>2</sup>
		Plates
		Height x Width (mm)   Net weight (kg)
1	0 481 40	800 x 800   5.9
1	0 481 43	1000 x 800   7.6
1	0 346 08	1400 x 800   14.6
		<b>Lina 25 perforated plates</b> Zinc steel For mounting with sectioned uprights (except plain plate Cat.No 0 346 09) Admissible load: 50 kg/m <sup>2</sup>
		Plates
		Height x Width (mm)   Net weight (kg)
1	0 474 90	800 x 800   3.9
1	0 474 95	1000 x 800   5
1	0 346 09	1400 x 800   6.7
		<b>Internal doors RAL 7035</b> IP xxB steel. Textured polyester coated steel Double bar lock. Take key barrels and other knockouts (p. 310) Distance between enclosure door and internal door 78 mm Right or left opening, handle included
		For cabinets
		Door dim. (mm)   Door usable dim. (mm)
		Height x Width   Height x Width   Height x Width
1	0 363 66	1400 x 800   1280 x 675   1200 x 580
1	0 363 67	1600 x 800   1480 x 675   1400 x 580
1	0 363 68	1800 x 800   1680 x 675   1600 x 580

Pack	Cat.Nos	Screws
500	0 366 44	Rivet reinforced plastic Ø6 mm for drilling Ø6.5 mm
100	0 347 45	Screw head H 4.8 x 16 mm self-drilling, self-tapping for Ø3.3 mm
200	0 347 50	Screw caps for isolation of screw head Cat.No 0 347 45 inside the trunking
		<b>Sectioned uprights</b> For Lina 25 rail, Lina rail and Lina 12.5 or Lina 25 plates Set of 2 uprights galvanized steel
		For enclosures
		Height (mm)   Length (mm)
1	0 363 90	1400   1284
1	0 363 91	1600   1484
1	0 363 92	1800   1684
		<b>Rails</b>
		<b>Lina 25 rail</b> Galvanized steel For enclosures width 800 mm 15 mm depth
5	0 477 28	
		<b>Rail to be cut</b> EN 60715
10	0 374 02	
		<b>Lifting accessories</b>
1	0 362 46	Lifting brackets M14 Set of 4 brackets for max. load 500 kg/m <sup>3</sup> Supplied with blanking plates
1	0 362 48	Assembly and lifting enclosures kit: - 2 support brackets - screws - weatherproof seal For 500 kg/m <sup>3</sup> lifting, order separately one set of 4 brackets Cat.No 0 362 46
		<b>Metal document holder (for plans)</b>
1	0 476 45	RAL 7012. Fixed on door width 800 mm Internal dimensions: W. 425 x H. 275 x D. 50 mm



Legrand custom made ranges  
**Please, consult your Area Commercial Manager**

