


Viking™ 3 terminal blocks with spring connection

for copper cables (continued)

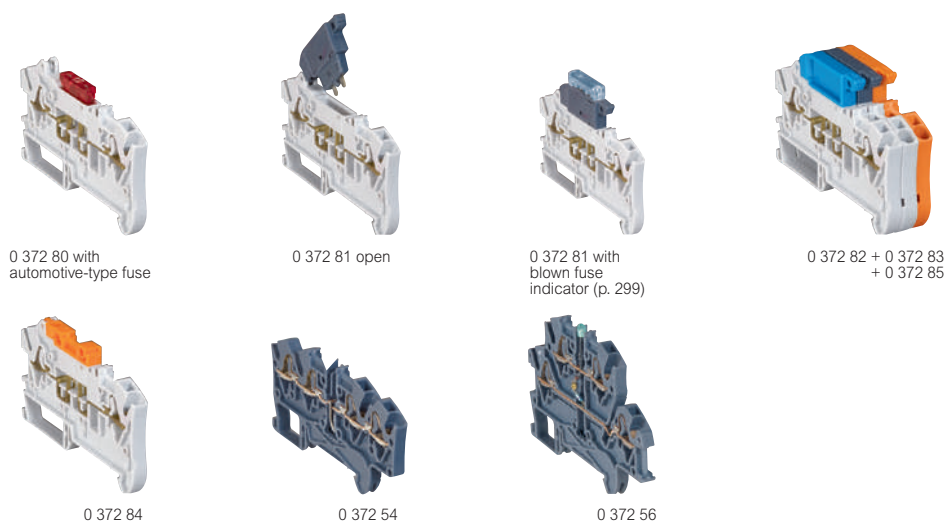

Technical characteristics **p. 336** dimensions **see e-catalogue**
 Approvals **p. 919**

Screwless connection system, stainless steel spring type
 Used to make the electrical connection between 2 copper wires, or flexible copper wires with or without ferrules (p. 306)
 Direct tool-free insertion of a rigid wire or flexible wire with ferrule, up to 6 mm pitch
 2 areas for automatic insertion bridging combs (upper level only for 2-level blocks)
 For rails depth 15 mm, EN 60715 depth 7.5 mm and 15 mm

Pack	Cat.Nos	Disconnect terminal blocks 1 connection - 2 wires				
		Opening by means of blade type lever, handle lever or mini lever (with tool)				
		Open (to be equipped)				
		Can take blade type levers Cat.Nos 0 375 15/16/17/18 or in ELV installations a blade-type automotive fuse or a miniature circuit-breaker				
			Capacity			
		Colour	Nominal cross-section (mm ²)	Rigid wire (mm ²)	Flexible wire (mm ²)	Flexible wire with ferrule (mm ²)
20	0 372 80	Grey	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5
20	0 372 81	Grey	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5
20	0 372 82	Grey/blue	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5
20	0 372 83	Grey	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5
20	0 372 84	Grey	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5
20	0 372 85	Orange	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5
20	0 372 86	Orange	2.5	0.5 to 2.5	0.5 to 2.5	0.5 to 2.5

Pack	Cat.Nos	Function blocks				
		1 connection - 4 wires - 2 entries/2 outlets - diode carrier				
			Capacity			
		Colour	Nominal cross-section (mm ²)	Rigid wire (mm ²)	Flexible wire (mm ²)	Flexible wire with ferrule (mm ²)
60	0 372 54	Grey	4	0.5 to 6	0.5 to 4	0.5 to 2.5
60	0 372 55	Grey	4	0.5 to 6	0.5 to 4	0.5 to 2.5
60	0 372 56	2 connections - 4 wires - 2 levels - with LED				
		Voltage presence indicator (12/24V _~ et \sim)				
		Grey	4	0.5 to 6	0.5 to 4	0.5 to 2.5

Blade type levers, joining rods and blown fuse indicators **p. 333**

Accessories **p. 332**

Starfix ferrules and crimping tools **p. 340**



For detailed dimensions, **see e-catalogue**

