

Hotel equipment

Arteor wiring devices square version



5 737 22




5 720 57



5 725 54



5 722 24

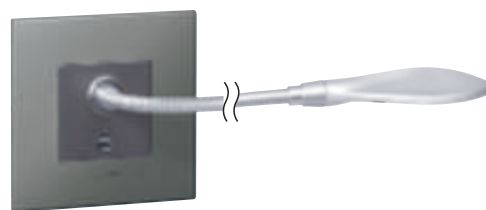

5 727 57 + plate Magnesium 5 713 12

Support frame and plate selection charts p. 476 to 487

Mechanisms supplied with rocker plates, to be equipped with support frames (p. 476) and plates (p. 480 to 487)

Pack	Cat.Nos	Lighting control
10	5 732 84	Master switch - 2 modules 2-way double pole 20 AX - 250 V~ for general control: all ON / all OFF ○ White ● Magnesium
10	5 737 84	
10	5 732 86	Master push-button - 2 modules 2-way 6 A - 250 V~ for general control: all ON/ all OFF ○ White ● Magnesium
10	5 737 86	
10	5 732 94	Switch for bed lights - 2 x 1 module 2 x 2-way switch - 10 AX - 250 V~ ○ White ● Magnesium
5	5 737 94	
10	5 732 96	Push-button for bed lights - 2 x 1 module 2 x 2-way push-button - 6 A - 250 V~ ○ White ● Magnesium
5	5 737 96	

Pack	Cat.Nos	Electric roller blinds control - 250 VA
10	5 732 22	Double switch 10 A - 2 modules For direct control of a motor (mechanism with fixed positions) ○ White ● Magnesium
10	5 737 22	
10	5 732 24	Double push-button 10 A - 2 modules For control via automatic box (N/O mechanism) ○ White ● Magnesium
10	5 737 24	

Pack	Cat.Nos	Curtain control - 250 VA
10	5 732 34	Double switch 10 A - 2 modules For direct control of a motor (mechanism with fixed positions) ○ White ● Magnesium
10	5 737 34	
10	5 732 36	Double push-button 10 A - 2 modules For control via automatic box (N/O mechanism) ○ White ● Magnesium
10	5 737 36	

Pack	Cat.Nos	Hotel bedroom call indicators
5	5 720 57	Enable the resident to inform hotel staff of the room status Two settings are possible: - Do not disturb - Please clean the room 2 x 1 module Indicator for corridor Indicator lamp and bell push Installed in the corridor, display calls Supplied with LED ○ White ● Magnesium
5	5 725 57	
5	5 720 54	Internal control unit Allows the user to select the desired setting Supplied with LED ○ White ● Magnesium
5	5 725 54	

Pack	Cat.Nos	Illuminated signs
5	5 722 24	Mechanisms integrating LEDs and a pivoting window that can take customised labels (printed using a simple text editor on transparent printing paper) 2 modules Green or red LEDs Sign with 2-state LEDs with choice of green or red configurable on the mechanism. Power level: 1 W ○ White ● Magnesium
5	5 727 24	
5	5 722 25	Blue LEDs Sign with blue LEDs A choice of 2 power levels: 0.2 or 1 W ○ White ● Magnesium
5	5 727 22	

Pack	Cat.Nos	Buzzers
10	5 722 04	230 V - 1 module ○ White ● Magnesium
5	5 727 04	
10	5 722 07	230 V - 2 modules ○ White ● Magnesium
10	5 722 47	

Pack	Cat.Nos	Reading lights
1	5 722 57	Fitted with maintenance-free LEDs LED colours: 3000 K (neutral white) 230 V power supply - energy class A Screw terminals. For installation in the bedhead Offers directional lighting. Equipped with a flexible cable so the head can swivel Built-in dimmer. Consumption 3.3 W Luminous flux 110 lumen (equivalent to 15 W incandescent) Service life 4000 hours. For installation in box depth 40 mm min. 2 modules ○ White ● Magnesium
1	5 727 57	