


Arteor™ USB charging sockets

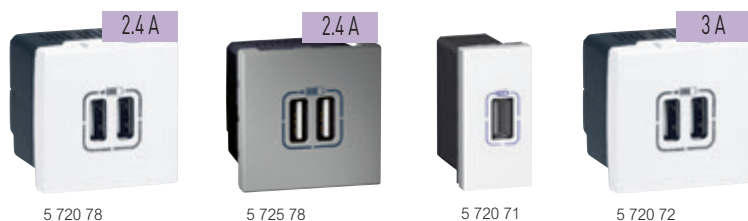

Support frame and plate selection charts **p. 480-487**

Mechanisms supplied with rocker plates, to be equipped with support frames (p. 476) and plates (p. 480 to 487)

Pack	Cat.Nos	USB A-type charging sockets
5 1	5 720 78 ¹ 5 725 78 ¹	<p>For recharging portable devices Conform to IEC 62684-2011-01 Consumption in passive mode < 0.6 W 2P+E tap-off connection via 2x2.5 mm² screw terminals Supplied without cord</p> <p>Double USB sockets - 5 V - 3 A - 15 W For fast charging smartphones and tablet PC 2 modules</p> <p> ○ White ● Magnesium</p>
10 10	5 720 71 5 725 71	<p>Single USB sockets - 5 V - 1.1 A - 5.5 W For Smartphone or Powerbank 1 module</p> <p> ○ White ● Magnesium</p>

1: Can be installed in receptacles for floor sockets p. 479

Pack	Cat.Nos	USB C-type charging sockets
1 1	5 720 77 5 725 77	<p>Used for charging the battery of a portable device without a mobile charger with USB Type-C plug Standby consumption < 0.06 W Conform to IEC 62684-2011-01 Supplied without cord</p> <p>1 USB A-Type + 1 USB C-Type - 230 V - 5 V= - 3 A - 15 W 2 modules</p> <p> ○ White ● Magnesium</p>
1 1	5 720 72 5 725 72	<p>2 USB C-Type - 230 V - 5 V= - 3 A - 15 W 2 modules</p> <p> ○ White ● Magnesium</p>
10 10	5 724 84 5 733 94	<p>1 USB C-Type - 230 V - 5 V= - 1.5 A - 7.5 W 2 modules</p> <p> ○ White ● Magnesium</p>

Floor sockets see **p. 479**



USB cords see **p. 755-756**