

Products always PROTECTED

Thanks to the flowpack, the products can be easily identified and remain protected until the installation.



ADVANTAGES FOR WHOLESALE AND RETAILERS

- products are individually protected and can be hanged on or placed in bulk
- the product is always visible for quick identification

ADVANTAGES FOR THE INSTALLERS

- the product is protected throughout the delivery process, until the installation
- all useful information is printed on the flow pack
- additional information by scanning the QR code



Valena™ Life

dimmers with cover plate



7 521 60 + 7 540 01
(White)



7 523 62 + 7 541 31
(Aluminium)





 


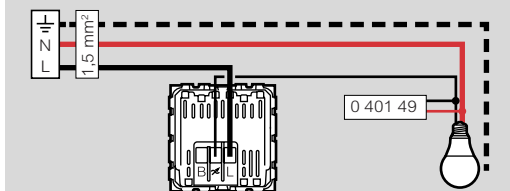


0 401 49

Valena In'Matic mechanisms supplied with cover plates and support frames. To be equipped with plates.

Supplied with mounted dust protection transparent shield

Flowpack packaging: robust protection to ensure optimum operation

Pack	Cat.Nos	Dimmers 240 V~ - 50 Hz
		<p>Equipped with overvoltage and short-circuit protection When switched on, lights up at the level set before last switch-off Can be remotely controlled via non-illuminated push-buttons (Cat.No 7 520 11), with each push-button able to perform the ON/OFF and dimming function</p> <p>Rotary dimmer without neutral For all types of lamps: - dimmable LEDs: 5 W to 75 W (10 lamps max.) - dimmable compact fluorescent lamps: 5 W to 75 W (10 lamps max.) - halogen with ferromagnetic or electronic transformer: 5 VA to 300 VA - fluorescent tube - ballast: 5 VA to 300 VA - halogen and incandescent 240 V~: 5 W to 300 W When switched on, gradually (2 seconds) lights up at the level set before last switch-off</p> <p>1 7 521 60  <input type="checkbox"/> White 1 7 522 60  <input type="checkbox"/> Ivory 1 7 523 60  <input type="checkbox"/> Aluminium</p> <p>Push-dimmer without neutral For all types of lamps: - dimmable LEDs: 5 W to 75 W (10 lamps max.) - dimmable compact fluorescent lamps: 5 W to 75 W (10 lamps max.) - halogen with ferromagnetic or electronic transformer: 3 VA to 400 VA - fluorescent tube - ballast: 3 VA to 200 VA - halogen and incandescent 240 V: 3 W to 400 W When switched on, gradually (2 seconds) lights up at the level set before last switch-off Functioning: - dimming mode - pre-set level mode (0%, 33%, 66% and 100%) - nightlight mode: dimming of the lamp for 1 hour</p> <p>1 7 521 62  <input type="checkbox"/> White 1 7 522 62  <input type="checkbox"/> Ivory 1 7 523 62  <input type="checkbox"/> Aluminium</p>
1	0 401 49	<p>Active Power Compensator</p> <p> Allows 2-wire electronic switches without neutral to be compatible with all loads (LED, fluocompact...)</p> <p></p>