 


Rigid conduits



6 514 16



0 319 06



0 319 00



0 313 82



0 313 83

Conduit supports installation p. 625

Pack	Cat.Nos	Medium impact rigid conduits with integrated coupling															
		<p>PVC without Pb, Sn, Cd (RoHS compliant) Non flame propagating Surface-mounting or flush-mounting Suitable for prefabricated concrete Conforming to European standard: EN/IEC 61386-21 Crush resistance: 750 Newtons Impact resistance: 2 joules at - 5 °C Min operating t°: - 5 °C Max operating t°: + 60 °C IK 07 Can be used outside Supplied wrapped in film. Light grey (RAL 7035) Length of tubes: 3 m</p> <table border="1"> <thead> <tr> <th>∅ exterior (mm)</th> <th>∅ interior (mm)</th> <th>thickness (mm)</th> </tr> </thead> <tbody> <tr> <td>16</td> <td>13</td> <td>1.50</td> </tr> <tr> <td>20</td> <td>16.9</td> <td>1.55</td> </tr> <tr> <td>25</td> <td>21.4</td> <td>1.80</td> </tr> <tr> <td>32</td> <td>27.8</td> <td>2.10</td> </tr> </tbody> </table>	∅ exterior (mm)	∅ interior (mm)	thickness (mm)	16	13	1.50	20	16.9	1.55	25	21.4	1.80	32	27.8	2.10
∅ exterior (mm)	∅ interior (mm)	thickness (mm)															
16	13	1.50															
20	16.9	1.55															
25	21.4	1.80															
32	27.8	2.10															
30	6 514 16																
30	6 514 20																
30	6 514 25																
15	6 514 32																

Pack	Cat.Nos	Clipsotubes								
		<p>Fixing by ∅7 mm thread 150 mm pin, screw-in wall plugs Cat.No 0 319 57, screw ∅5 mm or nail For interior use Holding of flexible and rigid conduits</p> <table border="1"> <thead> <tr> <th>∅ mini (mm)</th> <th>∅ maxi (mm)</th> </tr> </thead> <tbody> <tr> <td>15</td> <td>16</td> </tr> <tr> <td>18.4</td> <td>20.6</td> </tr> <tr> <td>22.3</td> <td>25</td> </tr> </tbody> </table>	∅ mini (mm)	∅ maxi (mm)	15	16	18.4	20.6	22.3	25
∅ mini (mm)	∅ maxi (mm)									
15	16									
18.4	20.6									
22.3	25									
100	0 319 03	For IRL ∅16 mm								
100	0 319 04	For IRL ∅20 mm								
100	0 319 06	For IRL ∅25 mm								

Pack	Cat.Nos	Cable ties with base
		<p>Adjustable for conduits IRL ∅16 to 32 mm or for cable ∅13 to 38 mm Fixing by ∅7 mm thread 150 mm pin, screw in wall plugs Cat.No 0 319 57, screw ∅5 mm Can be fixed using Pulsa 700 E staple gun For interior and exterior use - U.V. protected Black colour</p>
100	0 319 02	For interior use - Light grey RAL 7035
1000	0 319 00	

Pack	Cat.Nos	Conduit supports with screw-in wall plug
		<p>Conduit supports For conduit ∅16 For conduit ∅20 For conduit ∅25</p>
100	0 313 80	
100	0 313 81	
50	0 313 82	
		<p>Conduit supports accessory For fixing in plasterboard plate</p>
200	0 313 83	

Accessories for flexible and rigid conduits



6 516 01



6 516 08



6 516 11




6 516 18




6 516 32

Light grey (RAL 7035)


Pack	Cat.Nos	Couplings
100	060 01	For connecting conduits of the same diameter ∅16 mm
100	060 02	∅20 mm
50	060 03	∅25 mm
25	060 04	∅32 mm




Pack	Cat.Nos	Reducers
50	6 516 09	For connecting conduits of different diameters ∅25 x 20 mm




Pack	Cat.Nos	Elbows
50	6 516 11	∅16 mm
50	6 516 12	∅20 mm
25	6 516 13	∅25 mm



Pack	Cat.Nos	Tees
50	6 516 18	∅16 mm
25	6 516 19	∅20 mm
25	6 516 20	∅25 mm



Pack	Cat.Nos	Bends
20	060 42	90° curves ∅20 mm - length: 130 mm
10	060 43	∅25 mm - length: 160 mm
25	060 44	∅32 mm - length: 200 mm

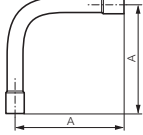

Pack	Cat.Nos	Bending springs
1	6 516 32	∅ (mm) Length (mm) 16 600
1	6 516 33	20 800
1	6 516 34	25 800

Pack	Cat.Nos	Nylon draw tape
1	060 82	Flexible cable which can be used to guide the wires into an unwired conduit. 2 metal end caps End cap diameter: 6 mm at both ends for attaching the wires Length: 20 m