


Multi-outlet extensions with cord

German standard (continued)



Multi-outlet extensions with cord

Multi-standard

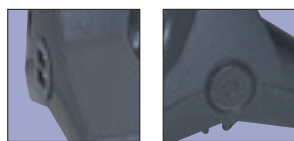


6 948 10

6 948 11

To connect several devices equipped with plugs with or without earth: appliances class I (simple insulation) or class II (double insulation), lamps, PC, TV, stereo, etc.

Extra-flat (only 30 mm thick): can be slid underneath furniture
Integrated cable compartment

Pack	Cat.Nos	
10	<div style="display: flex; justify-content: space-around;"> <div style="text-align: center;"> White/Grey 6 948 10 </div> <div style="text-align: center;"> Black 6 948 11 </div> </div>	Multi-outlet extensions with tablet support - switched 1.5 m cord (3G 1.5 mm ²) 3 x 2P+⊕ 2 USB Type-A ports for recharging mobile devices : 2.4 A shared maximum - 12W 1 built-in non-slip tablet stand 1 On/Off illuminated switch with resettable circuit breaker (16 A)

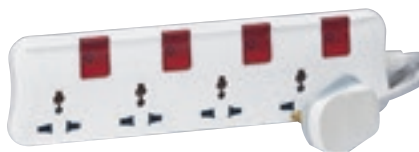

6 985 44

To connect several devices equipped with plugs with or without earth: appliances class I (simple insulation) or class II (double insulation), lamps, PC, TV, stereo, etc.

Extra-flat (only 30 mm thick): can be slid underneath furniture

Pack	Cat.Nos	
		Multi-standard multi-outlet extensions Can receive different type of standard plugs : US, British, EU... Sockets equipped with: - shutters for child protection - an on/off single pole safety switch, with light indicator Extra flat (only 30 mm thick) can be slid underneath furniture Can be wall, desk or floor-mounted thanks to key holes at the back Flame-retardant material (up to 850°C) Overload protection by fuse (integrated into the molded plug) Power supply cord 3m or 5m, with 1.25 mm ² section 13 A max. Power: 3250W at 250 V - 50/60 Hz
		<div style="text-align: center;"> White/Grey </div>
10	6 985 44	3 m cord
10	6 985 45	4 x 2P+E 5 x 2P+E
		5 m cord
10	6 985 74	4 x 2P+E
10	6 985 75	5 x 2P+E
		Multi-outlet extensions with 2 USB ports type A - 2.4 A 12 W <div style="text-align: center;"> </div>
10	6 985 00	3 m White/Grey
10	6 985 02	3 m Black
		5 m
10	6 985 01	5 m White/Grey
		<div style="text-align: center;"> White/Grey </div>
		Multi-outlet extensions Type O Plug (Myanmar) 2 m
10	6 984 17	4 x 2P+E
10	6 984 18	5 x 2P+E
10	6 984 19	4 x 2P+E with 2 USB ports type A 2.4 A 12 W



British standard multi-outlet extensions, p. 638

