


Legrand cabling system LCS³ category 6A and category 7

cables and cords

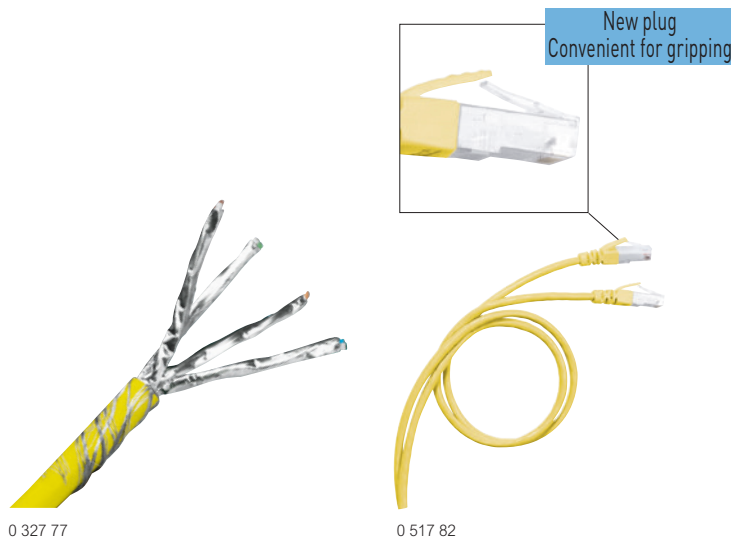

Pack	Cat.Nos	Cables for local networks cat. 6A
500 ¹	0 327 87	<p>Cables 4 pairs or 2 x 4 twisted pairs 100 ohms LSZH sleeve: halogen-free Yellow RAL 1018 Colour code TIA/EIA Conform to standards ISO/IEC 11801 Ed. 2.0, EN 50173-1 and TIA/EIA 568C</p> <p>U/UTP - 4 pairs Performance 500 MHz Length 500 m Supplied on reel. Weight 25 kg</p>
500 ¹	0 327 78	<p>F/UTP - 4 pairs Performance 500 MHz Length 500 m Supplied on reel. Weight 25 kg</p>
500 ¹	0 328 78	<p>F/UTP - 2 x 4 pairs Performance 500 MHz Length 500 m Supplied on reel. Weight 65 kg</p>
500 ¹	0 328 83	<p>F/FTP - 4 pairs Performance 500 MHz Length 500 m Supplied on reel. Weight 25 kg</p>
500 ¹	0 328 84	<p>U/FTP - 4 pairs Performance 500 MHz Length 500 m Supplied on reel. Weight 25 kg</p>

Pack	Cat.Nos	Cables for local networks cat. 7
500 ¹	0 327 77	<p>Cables 4 pairs or 2 x 4 twisted pairs 100 ohms LSZH sleeve: halogen-free Yellow RAL 1018 Colour code TIA/EIA Conform to standards ISO/IEC 11801 Ed. 2.0, EN 50173-1</p> <p>S/STP - 4 pairs Performance 600 MHz Euroclass Dca Length 500 m Supplied on reel. Weight 30 kg</p>
500 ¹	0 327 79	<p>S/FTP - 2 x 4 pairs Performance 600 MHz Length 500 m Supplied on reel. Weight 58 kg</p>
500 ¹	0 328 82	<p>S/FTP - 4 pairs Performance 600 MHz Euroclass B2ca Length 500 m Supplied on reel. Weight 58 kg</p>

1: in metre(s)

Pack	Cat.Nos	RJ 45 patch cords and user cords cat. 6A
1	0 518 82	RJ 45 - RJ 45 right Conform to standards ISO/IEC 11801 Ed. 2.0, EN 50173-1 and TIA/EIA 568C U/UTP unshielded impedance 100 Ω Length 1 m
1	0 518 83	Length 2 m
1	0 518 84	Length 3 m
1	0 518 85	Length 5 m
1	0 518 78	Length 1 m
1	0 518 79	Length 2 m
1	0 518 80	Length 3 m
1	0 518 81	Length 5 m
1	0 518 74	Length 1 m
1	0 518 75	Length 2 m
1	0 518 76	Length 3 m
1	0 518 77	Length 5 m
1	0 518 16	S/FTP shielded impedance 100 Ω Length 0.5 m
5	0 517 80	Length 1 m
5	0 517 81	Length 2 m
5	0 517 82	Length 3 m
5	0 517 83	Length 5 m
1	0 518 70	Length 1 m
1	0 518 71	Length 2 m
1	0 518 72	Length 3 m
1	0 518 73	Length 5 m
1	0 518 66	Length 1 m
1	0 518 67	Length 2 m
1	0 518 68	Length 3 m
1	0 518 69	Length 5 m