

Legrand cabling system LCS³ fibre optic

19" high density and very high density fibre optic drawers




0 321 50




0 321 55




0 321 56

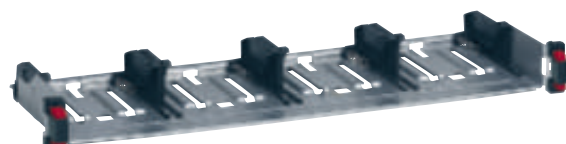


0 321 40

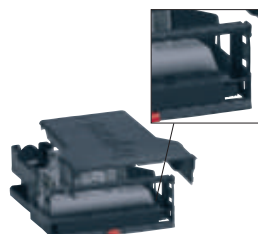

0 321 41

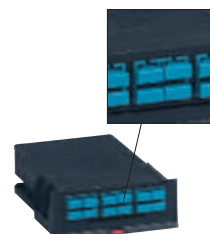

0 321 43

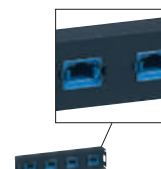

0 321 33

Pack	Cat.Nos	Ultra high density modular fibre optic drawers to be equipped with cassettes
		Fixed and modular chassis for the reception of the drawers Fibre optic drawers with front facing cord management Maximum capacity 4 U (up to 48 cassette) - 576 LC connectors Maximum capacity 2 U (up to 24 cassette) - 288 LC connectors Maximum capacity 1 U (up to 12 cassette) - 144 LC connectors
1	0 321 50	1 U
1	0 321 52	2 U
1	0 321 53	4 U
1	0 321 51	UHD panel to be equipped with cassettes without rear management 1 U

Pack	Cat.Nos	Very high density cassettes
		They are clipped directly to the fibre optic drawers Cat.Nos 0 321 50/51/52/53 Sliding cassette for the above chassis Front or rear cassette extraction MTP ¹ high performance cassette Low insertion loss < 0,35 dB A/C polarity
1	0 321 54	Multimode OM4 cassette (50/125 µm) For OM4 type 50/125 µm multimode installations MPO cassette 12 LC OM4 Type A/C
1	0 321 55	OS2 cassette (9/125 µm) For OS2 type 9/125 µm multimode installations MPO cassette 12 LC OS2 Type A/C

Pack	Cat.Nos	MTP ¹ adaptors (MPO compatible)
		To be clipped directly to the fibre optic drawers Cat.Nos 0 321 50/51/52/53
1	0 321 56	Multimode 4 MTP ¹ adaptor
1	0 321 57	Single-mode 4 MTP ¹ adaptor

Pack	Cat.Nos	LC adaptor
		To be clipped directly to the fibre optic drawers Cat.Nos 0 321 50/51/52/53
1	0 321 58	Adaptor 12 LC multimode

Pack	Cat.Nos	Modular 19" panel to be equipped with cassettes
		To be equipped with a maximum of 4 automatic extraction cassettes Complete with new generation Quick-Fix for automatic mounting (no screws required) on the risers of cabinets or enclosures Maximum capacity either 96 LC connectors, 48 SC connectors or 24 ST connectors Depth 190 mm, height 1 U
1	0 321 40	

Pack	Cat.Nos	High density MTP ¹ cassette (MPO compatible)
		To be installed in the modular panel Cat.No 0 321 40 Sliding cassette that can be extracted by simple pressure, making installation and maintenance easier Front and rear extraction High performance MTP ¹ cassette, low insertion loss <0.35 dB, A/C polarity
1	0 321 41	Fibre optic splice cassette Accepts all modular fibre optic blocks
1	0 337 55	Copper cassette to be equipped Accepts 6 cat. 5e, cat. 6 and cat. 6 _A connectors
1	0 321 42	Multimode OM4 cassettes (50/125 µm) MTP ¹ cassette (MPO compatible) 24 LC OM4 Type A/C
1	0 321 43	MTP ¹ cassette (MPO compatible) 12 SC OM4 Type A/C
		Single-mode OS2 cassettes (9/125 µm)
1	0 321 44	OS2 type MTP ¹ cassette (MPO compatible) 24 LC OS2 Type A/C
1	0 321 45	MTP ¹ cassette (MPO compatible) 12 SC OS2 Type A/C
1	0 337 57	Blanking cassette To be used for blanking the panel

Pack	Cat.Nos	MTP ¹ adaptors
		To be installed in splice cassette Cat.No 0 321 41 Enables MTP ¹ /MTP ¹ feedthrough
1	0 321 33	Single-mode 4 MTP ¹ adaptor
1	0 321 34	Multimode 4 MTP ¹ adaptor

Pack	Cat.Nos	Accessories for 19" panel to be equipped with cassette
		Rear cable management accessory For installation on panel Cat.No 0 321 40
1	0 321 46	
		Cord management kit (guide/support/door) For installation on panel Cat.No 0 321 40; 2 side cord management and front door with integrated marking to ensure correct front and side cord management Cord support to be installed on the cassette to make side passages easier
1	0 321 47	

1: MTP is a registered trademark of US Conec Ltd