


Legrand cabling system LCS³ Energy Distribution

1U Power Distribution Units

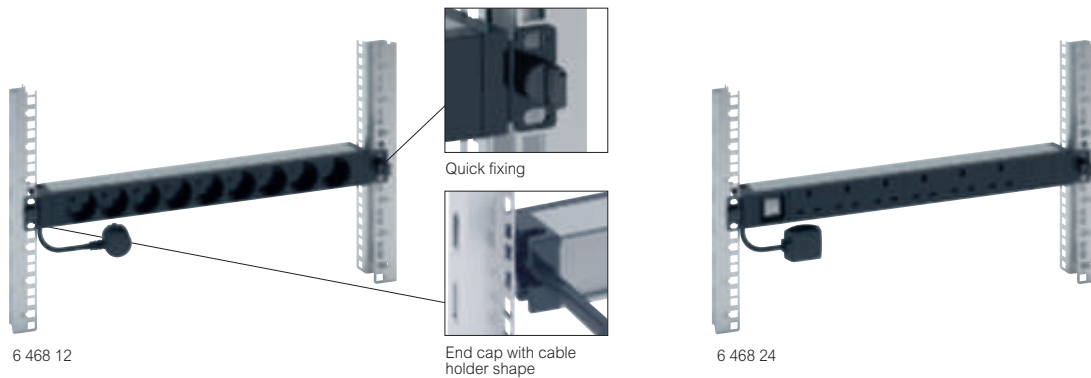


To provide ~ electric power for IT equipment in enclosure. 230 V - 50/60 Hz power supply. 1U aluminium profile. End cap with metallic brackets and cable holder shape. Quick fixing (no screws) on 19" fixing centers. Can also be installed vertically by reverting the brackets (no screws)

2P+E outlets:

- C13 and C19 standard outlets are equipped with cord locking system to avoid any accidental disconnection. Universal solution compatible with all the cords (C14 plugs for C13 and C20 plugs for C19).
 - French, German and British standard outlets are equipped with blanks
 - French and German standard outlets are inclined at 55°
- Black modules (outlets and functions)

Pack	Cat.Nos	19" - PDU standard
		German standard
1	6 468 06	3 m power supply cord with 16 A 2P+E French/German plug
1	6 468 12	6 outlets
		9 outlets
		British standard
1	6 468 13	3 m power supply cord with 13 A 2P+E British plug
		8 outlets
		French standard
		3 m power supply cord with 16 A 2P+E French/German plug
1	6 468 05	6 outlets
1	6 468 10	9 outlets
1	6 468 11	9 tamperproof red outlets
		IEC 60320 standard
		Connection on terminal block (except Cat.No 6 468 15)
1	6 468 14	10 C13 outlets with cord locking system
1	6 468 15	12 C13 outlets with cord locking system
		3 m power supply cord with 16 A IEC 60309 2P+E
1	6 468 09	6 C13 outlets + 2 C19 outlets with cord locking system
1	6 468 07	6 C19 outlets with cord locking system

Pack	Cat.Nos	10" - PDU standard
		1 m power supply cord 2P+E French/German plug
		4 x 2P+E outlets
1	6 468 01	German standard
1	6 468 00	French standard

 

Pack	Cat.Nos	19" - PDU with power indicator or luminous switch
		LED indicator: signals whether the PDU is supplied with power or not
		LED indicator switch: powers on/off the PDU
		German standard
		3 m power supply cord with 16 A 2P+E French/German plug
1	6 468 21	9 outlets and 1 power indicator
1	6 468 23	8 outlets and 1 luminous switch
		British standard
		3 m power supply cord with 13 A 2P+E British plug
1	6 468 24	6 outlets and 1 luminous switch
		French standard
		3 m power supply cord with 16 A 2P+E French/German plug
1	6 468 20	9 outlets and 1 power indicator
1	6 468 22	8 outlets and 1 luminous switch