

# Linkeo 19" freestanding cabinets

## General characteristics

Metallic extendable freestanding cabinets  
 RAL 7016 textured polyester coating providing excellent resistance to corrosion and scratching  
 Reversible simple or double front glass door with screen-printing  
 Protection index (weatherproof) against solid objects and liquids: IP 20  
 Protection index against mechanical impacts: IK 08  
 Perforations in 19" uprights: 9.5 x 9.5 mm  
 Permissible load: 400 kg

## Compliance with standards


Linkeo cabinets comply with the following standards:

<b>IEC 60529</b> <b>EN 60529</b>	(NF C 20-010) Degrees of protection provided by enclosures (IP code)
<b>IEC 62262</b> <b>EN 62262</b>	(NF EN 50102, NF C 20-015) Degrees of protection provided by enclosures for electrical equipment against external mechanical impacts (IK code)
<b>IEC 60950-1</b> <b>EN 60950-1</b> <b>C 77-210-1</b>	Safety of data processing equipment
<b>EIA-310-E</b>	Cabinets, racks, panels and associated equipment (ANSI/EIA/310-E-2005)
<b>IEC 60297-3-100</b> <b>DIN 41414-7</b>	(NF C 20-150, NF C 20-151) Dimensions of mechanical structures of the 482.6 mm (19 in) series

Linkeo cabinets can be integrated in installations complying with the following standards:

<b>EN 50173-1</b>	Information technology - Generic cabling systems
<b>EN 50174-1 &amp; 2</b> <b>C 90-480-1 &amp; 2</b>	Information technology - Cabling installation
<b>ISO IEC 11801</b>	Information technology - Generic cabling for customer premises
<b>NF C 15-100</b> <b>Part 4-41</b>	Low voltage electrical installations - recommendations
<b>IEC 60364-4-41</b>	Low voltage electrical installations - Protection for safety - Protection against electric shock

## Dimensions (mm)

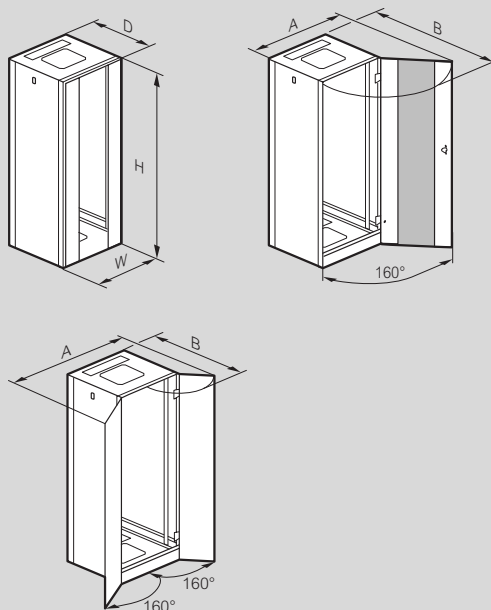

### Cabinets with single front door

Cabinet dimensions	Overall dimensions				
	H <sup>(1)</sup>	W	D	A	B
<b>24 U 600 x 600</b>	1226	610	630	1138	1210
<b>24 U 800 x 800</b>		810	830	1525	1610
<b>33 U 600 x 600</b>	1626	610	630	1138	1210
<b>33 U 800 x 800</b>		810	830	1525	1610
<b>42 U 600 x 600</b>	2026	610	630	1138	1210
<b>42 U 600 x 800</b>		610	830	1138	1410
<b>42 U 600 x 1000</b>		610	1030	1138	1610
<b>42 U 800 x 600</b>		810	630	1525	1410
<b>42 U 800 x 800</b>		810	830	1525	1610
<b>42 U 800 x 1000</b>		810	1030	1525	1810
<b>47 U 800 x 800</b>		2248	810	830	1525
<b>47 U 800 x 1000</b>	810		1030	1525	1810

1: Without adjustment levelling feet (+19 to 39 mm with feet)

### Cabinets with double front door

Cabinet dimensions	H <sup>(1)</sup>	W	D	A	B
<b>42 U 800 x 600</b>	2026	810	630	1164	1011
<b>42 U 800 x 800</b>			830		1211
<b>42 U 800 x 1000</b>			1030		1411

1: Without adjustment levelling feet (+19 to 39 mm with feet)