


## Wall-mounting rack for weatherproof cabinets

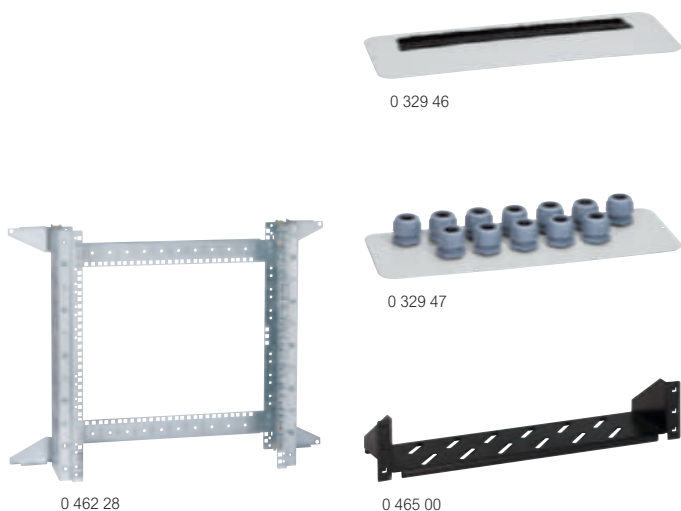

Pack	Cat.Nos	Wall-mounting VDI rack for Atlantic and Marina cabinets
		For integrating 19" VDI equipment in Atlantic cabinets (Cat.Nos 0 355 xx) and Marina cabinets, width 600 or 800 mm and depth 250 mm min. In cabinets width 400 mm, the rack enables 10" VDI equipment to be incorporated (p. 771) Can be fixed directly on the wall to create a wall-mounted rack (without cabinet) Self-locking cable ties and cable ties with tightening indicator (p. 795) can be fitted
1	0 462 27	6 U rack
1	0 462 28	12 U rack
1	0 462 29	16 U rack

Pack	Cat.Nos	Cable entry for Atlantic cabinets width 600 or 800 mm and 19" equipment
		<b>Cable entry</b> IP 43 cable entry plate with brush (cable feedthrough 385 x 30 mm) IP 55 cable entry plate with multi-entry cable glands Supplied with 12 ISO 32 cable glands Each cable gland allows the insertion of 4 UTP/FTP/SFTP cables (Ø6.5 to 9.5 mm) Cords with connectors can be fed through without having to dismantle the cable gland Supplied with blanking plates for unused entries
1	0 329 46	IP 43 cable entry plate with brush (cable feedthrough 385 x 30 mm)
1	0 329 47	IP 55 cable entry plate with multi-entry cable glands Supplied with 12 ISO 32 cable glands Each cable gland allows the insertion of 4 UTP/FTP/SFTP cables (Ø6.5 to 9.5 mm) Cords with connectors can be fed through without having to dismantle the cable gland Supplied with blanking plates for unused entries
		<b>Fixed shelf</b> Projecting mounting on 2 x 19" uprights Fast screw-free assembly Max. load 15 kg Height 2 U Black RAL 9005 Depth 115 mm
1	0 465 00	Fixed shelf



## Wall-mounting rack for weatherproof cabinets


### Rack mounting in weatherproof cabinets

Perforations in uprights: 9.5 x 9.5 mm


Atlantic cabinets					
Rack Cat.Nos	Capacity	Cat.Nos	Dimensions H x W x D (mm)	Usable dim. under door	
				A (mm)	B (mm)
0 462 27	6 U	0 369 77	400 x 600 x 250	145	105
0 462 28	12 U	0 369 26	600 x 400 x 250	145	105
0 462 28	12 U	0 369 64	600 x 600 x 250	145	105
0 462 28	12 U	0 369 72	600 x 600 x 400	145	255
0 462 28	12 U	0 369 78	600 x 800 x 300	145	155
0 462 29	16 U	0 369 31	800 x 600 x 250	145	105
0 462 29	16 U	0 369 37	800 x 600 x 300	145	155
0 462 29	16 U	0 369 44	800 x 600 x 400	145	255
0 462 29	16 U	0 369 68	800 x 800 x 300	145	155
Marina cabinets					
0 462 28	12 U	0 362 55/75	600 x 400 x 250	150	100
0 462 29	16 U	0 362 61/81	800 x 600 x 300	150	150
Atlantic stainless steel food industry cabinets					
0 462 28	12 U	0 352 36	600 x 400 x 250	145	70 <sup>(1)</sup>
0 462 29	16 U	0 352 38	800 x 600 x 300	145	120 <sup>(2)</sup>

1: only 20mm in front of the 2 hinges  
2: only 70mm in front of the 2 hinges


### Width 400 mm

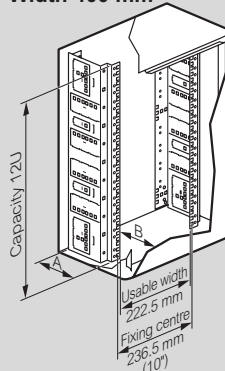

### Width 600 mm

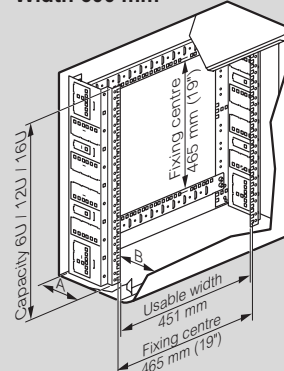


### Width 800 mm

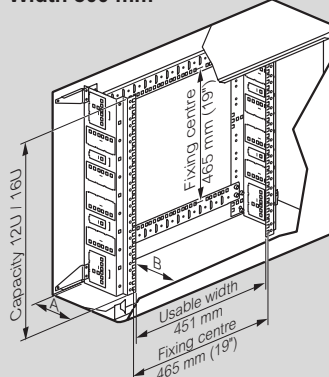


Depth adjusting aid with slides Cat.Nos 0 367 44/45 for Atlantic cabinets depth 300 and 400 mm

### Rack fixing centres (mm)

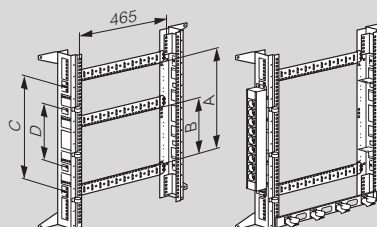

Cat.Nos	Capacity	A	B	C	D
0 462 27	6 U	-	236.5	-	236.5
0 462 28	12 U	465	236.5	465	236.5
0 462 29	16 U	465	236.5	465	236.5

### Wall fixing (mm)

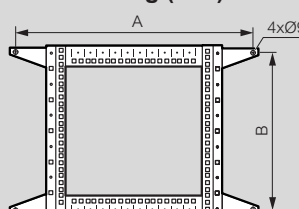

Wall-mounting rack			
Cat.Nos	Capacity	A	B
0 462 27	6 U	725	325
0 462 28	12 U	725	525
0 462 29	16 U	725	725