


# DLPlus mini-trunking 60 x 20 and 75 x 20

profiles and finishing accessories

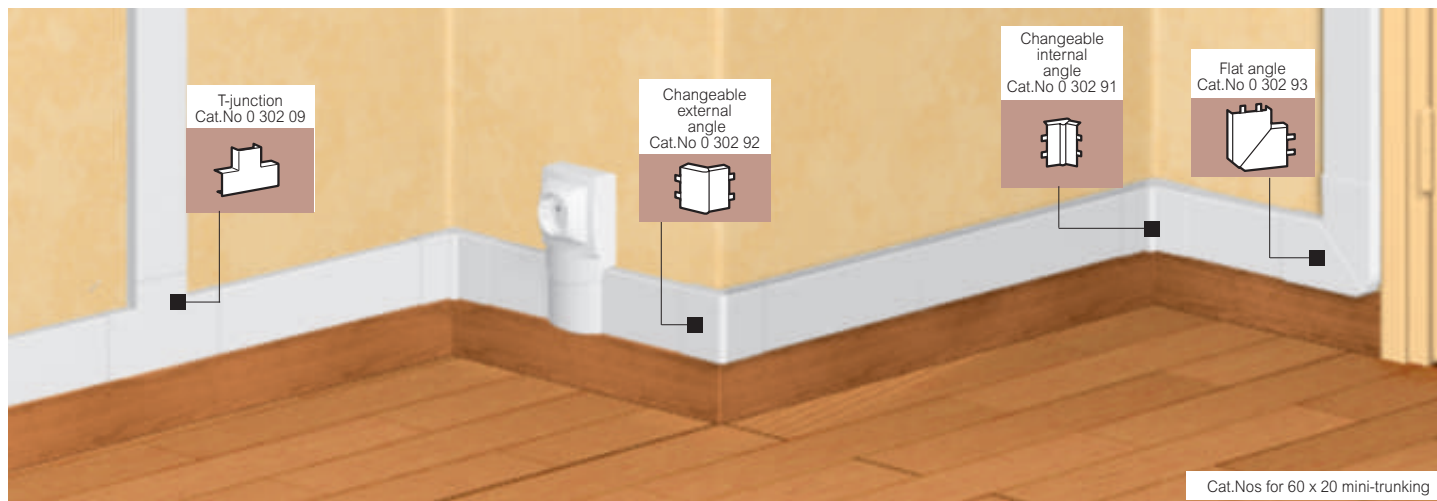

Selection chart **p. 796-797**  
Wiring capacity chart **see e-catalogue**

Pack	Cat.Nos	<b>3-compartment mini-trunking</b>
32'   20'	60 x 20 0 301 14   75 x 20 0 300 33	3 compartments for distribution of high and low currents Length 2.10 m White 

Pack	Cat.Nos	<b>Finishing accessories</b>
10	60 x 20 0 302 90   75 x 20 0 303 00	End cap
10	0 302 91   0 303 01	Changeable internal angle
10	0 302 92   0 303 02	Changeable external angle
10	0 302 93   0 303 03	Flat angle
20	0 336 08   0 336 09	Cover joint
10	0 302 09   0 302 18	Flat T-junction
1	0 328 05	Junction to floor duct

Pack	Cat.Nos	<b>Special frames</b>
10	0 314 08	Supplied with end cap and divider for separation of currents <b>Installation alongside the mini-trunking</b> For vertical or horizontal mounting of surface mounting wiring accessories (p. 804) 1 gang
5	0 314 18	2 gang

1: Number of metres in pack

Pack	Cat.Nos	<b>Adaptors</b>
10	0 316 45	<b>Adaptors for mounting Mosaic frames at the end of the mini-trunking</b> For 60 x 20 mini-trunking
10	0 316 48	For 75 x 20 mini-trunking (for 4 and 6 modules only)
10	0 317 07	<b>Adaptors for mounting Mosaic frames alongside the mini-trunking</b> For Mosaic frames Cat.No 0 316 11 (p. 801)
5	0 317 08	For Mosaic frames Cat.Nos 0 316 13 and 0 316 21 (p. 801)
5	0 317 09	For Mosaic frames Cat.Nos 0 316 14 and 0 316 22 (p. 801)

Other frames for wiring accessories  
**(see opposite)**

Surface-mounting wiring accessories **p. 804**