


# Flexible cover snap-on DLP trunking 45 mm cover 50 x 180

## routing sections and accessories

Cat.Nos for trunking 50 x 180

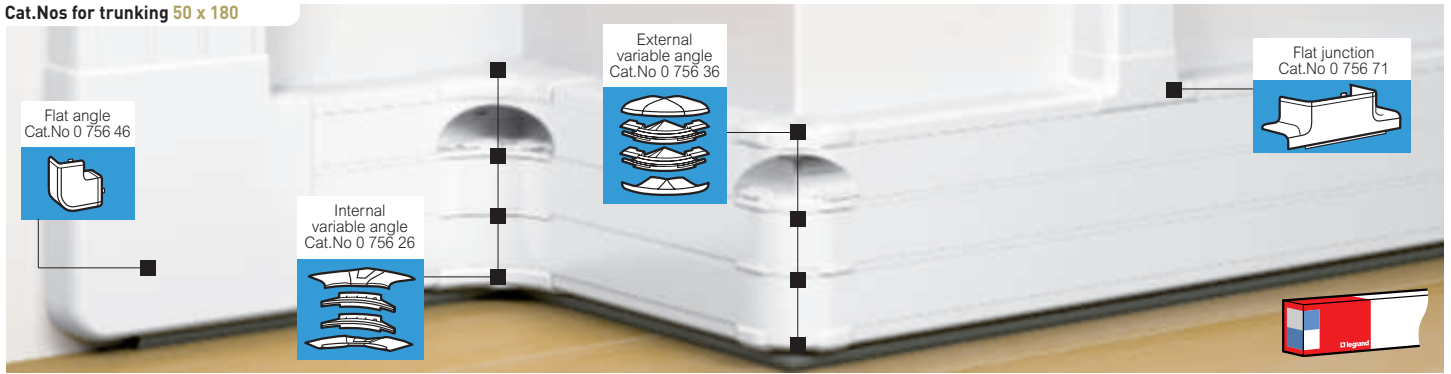

**Example of installation:**  
One current type per compartment



**Example of installation:**  
Wiring accessories in central compartment and distribution in side compartments



Selection chart **p. 808-809**  
Wiring capacity chart **see e-catalogue**

Pack	Cat.Nos	Flexible cover snap-on trunking
		<b>3-compartment trunking</b> Snap-on trunking Can take any Mosaic or Arteor wiring accessory Includes: - 1 body with 3 compartments - 3 flexible covers, width 45 mm Length 2 m Length 2.5 m
8 <sup>1</sup>	0 756 06	
5 <sup>1</sup>	0 110 24	
20 <sup>1</sup>	0 756 08	<b>Extra cover</b> Width 45 mm Length 2 m
10	0 756 61	<b>Fishplate body joint</b> Used to join 2 bodies and simplifies fixing sections to the wall - set of 2
20	0 756 66	<b>Stick-on body joints</b> For top part of body
10 <sup>1</sup>	0 756 69	<b>Cover joint</b> Cover joint, width 45 mm
24	0 105 80	<b>Height spacer</b> Length 2 m, colour charcoal grey For fitting 15 mm from the ground
10	0 756 90	<b>Soluclip accessory</b> For installation with any Mosaic or Arteor function

Pack	Cat.Nos	Angles
5	50 x 180 0 756 26	Internal angle, varies from 80° to 100°
5	0 756 36	External angle, varies from 85° to 120°
5	0 756 46	Flat angle at 90°
5	0 756 16	<b>End cap</b> Left or right end cap
5	0 756 71	<b>Flat junctions</b> <b>With 80 mm wide sections</b> Creates a junction with snap-on trunking 50 x 80 mm
5	0 756 75	<b>With 105 mm wide sections</b> Creates a junction with snap-on trunking 50 x 105 mm
5	0 756 81	<b>Angled junction</b> Creates a junction in an internal angle with snap-on trunking 50 x 80 mm, 50 x 105 mm, 50 x 130 mm Must be used in conjunction with internal angle
5	0 756 88	<b>Junction with floor duct</b> Creates a junction with a floor duct size 50 x 12 mm or 92 x 20 mm

1: Number of metres in pack