

Rigid cover DLP-S snap-on trunking 130 x 50


45 mm cover

Cat.Nos for trunking 130 x 50



Selection chart (p. 830-831)
Technical characteristics see e-catalogue

Pack	Cat.Nos	Rigid cover snap-on trunking
12 ¹	N 130 x 50 6 380 40	2-compartment trunking Includes: - 1 body - 2 covers width 45 mm Supplied in 6 units of 2 m length Can take 45 mm wiring accessories, such as Arteor or Mosaic
10	6 380 46	Body joint For aligning trunking body during installation
10	6 380 00	Cover joint Cover joint for 45 mm cover
8	N 130 x 50 6 380 47	Angles Fixed angles at 90° Internal angle
12	6 380 48	External angle
8	6 380 49	Flat angle at 90°
10	N 130 x 50 6 380 45	End cap End cap
5	N 130 x 50 6 380 44	Flat junction Creates a junction between 130 x 50 mm vertical trunking and any other size of the range
10	6 038 57	Normaclip anti-pullout accessory For 45 mm wiring devices like Mosaic and Arteor With anti-pullout and anti-slip system for perfect fitting of the mechanisms on DLP-S and DLP aluminium snap-on trunking and snap-on columns and mini-columns White finish

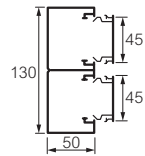

Pack	Cat.Nos	Mosaic Programme socket outlets
10	Standard 0 776 01	Sockets with connection at both sides for snap-on mounting on trunking with 45 mm cover. Particularly suitable for installation on snap-on trunking Connected with screw terminals German standard 2P+E (2 modules) 2 x 2P+E (4 modules) 3 x 2P+E (6 modules) 4 x 2P+E (8 modules)
10	Tamperproof 0 776 21	
10	0 776 02 0 776 22	
10	0 776 03 0 776 23	
5	0 776 04 0 776 24	4 x 2P+E (8 modules)
10	Red 0 776 12	2 x 2P+E (4 modules)
10	0 776 13	3 x 2P+E (6 modules)
10	5 721 11	Arteor British standard socket outlets Shuttered for child safety ASTA licence Conform to BS 1363 Part 2 2P+E - 13 A Conform to BS 1363 Part 2; ASTA licence 2 modules ○ White
5	5 721 30	2P+E switched - 13 A Conform to BS 1363 Part 2; ASTA licence 3 modules ○ White
5	5 724 67	● Red dedicated non standard pin Use with plug Cat.No 6 745 32

1: Number of meters in pack