


# Aluminium universal DLP trunking system

## 50 x 150 / 65 x 150 / 50 x 195 and 65 x 195

Cat.Nos for 50 x 195 trunking

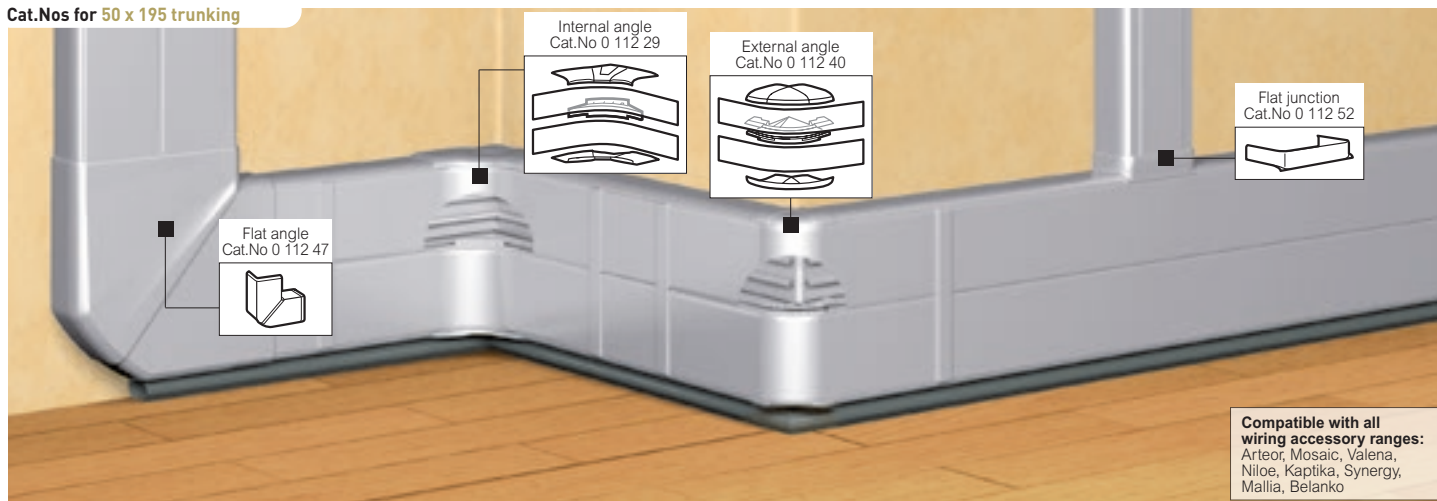

Selection chart **p. 840**  
 Technical characteristics **see e-catalogue**

Pack	Cat.Nos	Bodies		Pack	Cat.Nos	Bodies	
4'	50 x 150 0 111 02   65 x 150 0 111 03	Supplied without cover Allow fitting of partial covers length 2 m		4'	50 x 195 0 111 04   65 x 195 0 111 05	Supplied without cover Allow fitting of partial covers length 2 m	
16'	0 111 10	<b>Covers and partitions</b> Partial rigid cover 65 mm width Full rigid cover 130 mm width Division partition for cover 65 mm width Separation partition		16'	0 111 11	<b>Covers and partitions</b> Partial rigid cover 85 mm width Separation partition Division partition for cover 85 mm width	
8'	0 111 12			24'	50 x 195 0 111 08   65 x 195 0 111 09		
12'	50 x 150 0 111 06   65 x 150 0 111 07			12'	50 x 195 0 111 06   65 x 195 0 111 07		
24'	0 111 08   0 111 09						
10	50 x 150 0 111 60   65 x 150 0 111 89	<b>Finishing accessories</b> End cap Flat angle External angle Internal angle Flat junction 50 x 105 trunking, cover width 65 mm Flat junction 50 x 105 trunking, cover width 85 mm Body joint attached with adhesive (fit at the end of installation) For aligning bases during installation Cover joint for 65 mm cover		10   5	50 x 195 0 111 61   65 x 195 0 111 90	<b>Finishing accessories</b> End cap Flat angle External angle Internal angle Flat junction 50 x 105 trunking, cover width 65 mm Flat junction 50 x 105 trunking, cover width 85 mm Body joint attached with adhesive (fit at the end of installation) For aligning bases during installation Cover joint for 85 mm cover	
5   2	0 112 45   0 112 46			2	0 112 47   0 112 48		
1	0 112 38   0 112 39			1	0 112 40   0 112 41		
1	0 112 27   0 112 28			1	0 112 29   0 112 30		
5	0 112 52   0 112 54			5	0 112 52   0 112 54		
5	0 112 51   0 112 53			5	0 112 51   0 112 53		
20	0 111 66			20	0 111 66		
20	0 111 92			20	0 111 92		
10	0 111 62			10	0 111 63		

1: Number of metres in pack