


6 531 79

Pack	Cat.Nos	Accessories
1	6 531 69	Metal separation partition, length 1.1 m
1	6 531 80	Panel indicator 150 x 150 mm
1	6 531 81	Support for fixing TV screen 10-26 inch / 25-66 cm
1	6 531 82	Support for fixing TV screen 26-42 inch / 66-107 cm
1	6 531 83	Shelf, white finish
Boxes		
1	5 102 01	1-gang mounting box
1	5 102 02	2-gang mounting box
1	5 102 03	Junction box
Supports for wiring accessories		
1	6 531 79	Support for mounting Arteor, Mosaic and Belanko wiring accessories
1	6 531 78	Support adaptor for Mosaic wiring accessories 2 and 3 modules
Supports for rail equipment (columns and mini-columns)		
For mounting rail equipment (such as MCBs) on columns and mini-columns. To be used with two 0.5-module spacing units Cat.No 4 063 07 (p. 73) Capacity: 1 module Equipped with protective cover to prevent unwanted triggering For installation on universal columns and mini-columns use a fixing support Cat.No 6 531 79, a 4-module Mosaic Programme support plate Cat.No 0 802 52 (p. 906) and a 4-module Mosaic Programme plate Cat.Nos 0 788 14, 0793 14 or 0 790 54 (p. 904)		
5	0 310 69	White finish
5	0 307 87	Aluminium finish
5	6 530 75	Black finish




■ Dimensions (in mm)

1-compartment columns and mini-columns

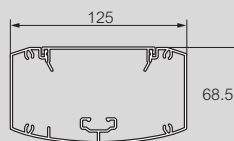

2-compartment columns and mini-columns

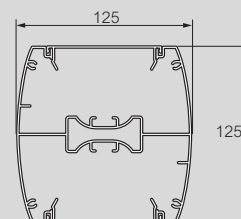

■ Wiring capacity

1-compartment columns

Max. capacity of conductors (for each type of conductor)	1-compartment	1-compartment (with 1 mechanism)
Compartment	A	A
Total cross-section (mm ²)	6900	5050
Number of cables	Ø7 mm	120
	Ø9 mm	72
	Ø11 mm	50

2-compartment columns

Max. capacity of conductors (for each type of conductor)	2-compartment		2-compartment (with 1 mechanism)	
Compartment	A	B	A	B
Total cross-section (mm ²)	6170	6170	4280	6170
Number of cables	Ø7 mm	106	72	106
	Ø9 mm	62	42	62
	Ø11 mm	44	26	44

■ Installation principle for special support for mounting rail equipment Cat.Nos 0 307 87, 0 310 69 and 6 530 75

