
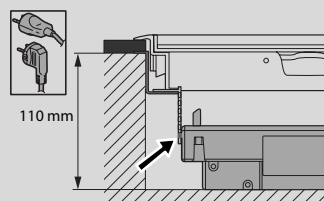
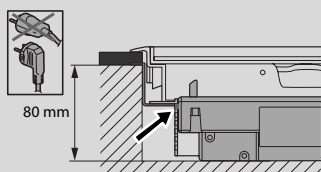
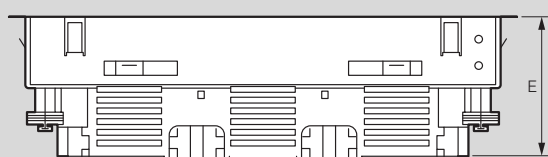


# Standard version floor boxes - sockets in horizontal position


## technical characteristics

### ■ Dimensions

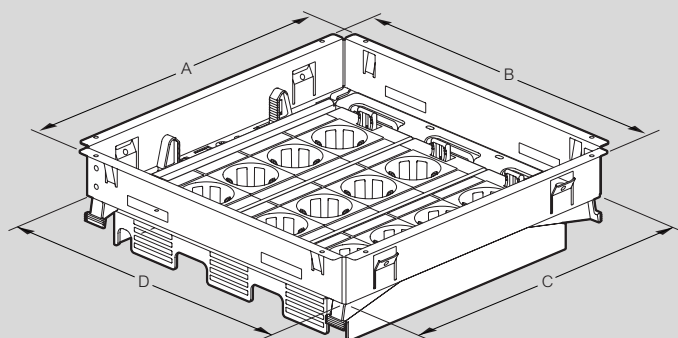

| Cat.No   | A (mm) | B (mm) | C (mm) | D (mm) | E (mm) |
|----------|--------|--------|--------|--------|--------|
| 0 880 20 | 199    |        | 181    |        |        |
| 0 880 21 | 234    | 282    | 219    | 264    | 78     |
| 0 880 22 | 282    |        | 264    |        |        |


### ■ For installation in raised floor

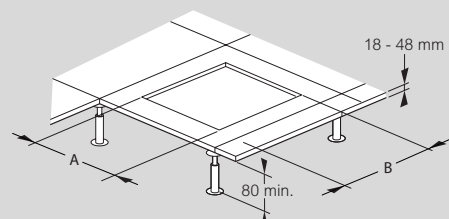


| Cat.No   | A (mm) | B (mm) |
|----------|--------|--------|
| 0 880 20 | 181    |        |
| 0 880 21 | 219    | 264    |
| 0 880 22 | 264    |        |

### ■ Installation principle in concrete floor

With auto-adjusting  
backbox

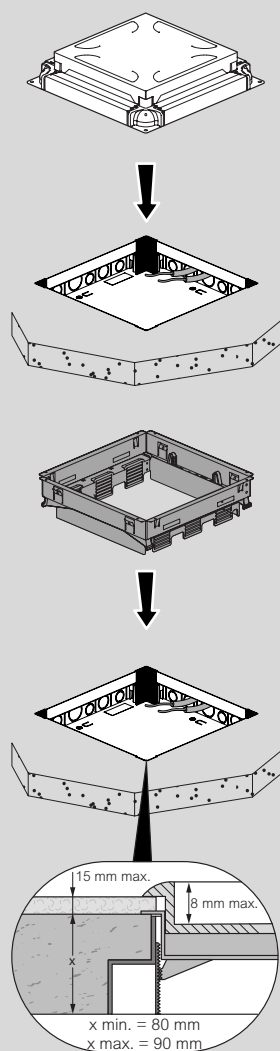


With universal adjustable  
backbox

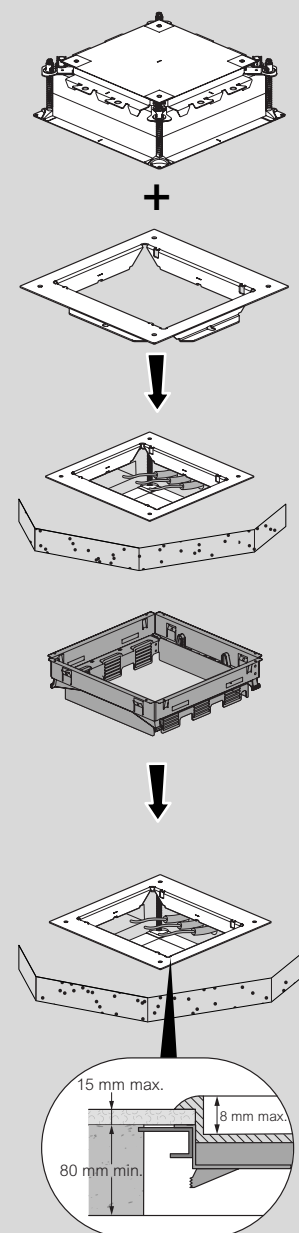


# Standard version floor boxes - sockets in vertical position

## technical characteristics


### ■ Dimensions

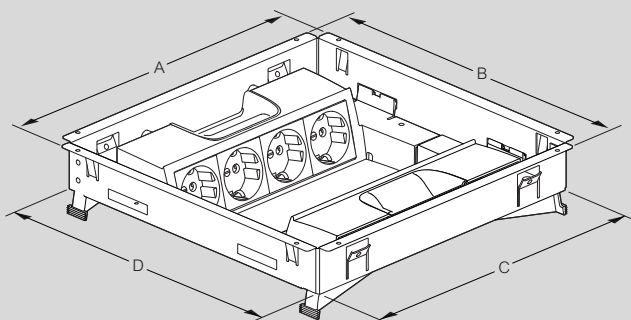

Installation in a raised floor with electrical insulation kits  
Cat.Nos 0 880 26/27/28

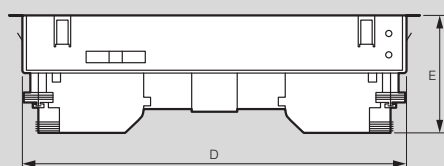


Installation in a backbox for concrete floor

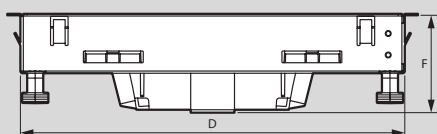


| Cat.No   | A (mm) | B (mm) | C (mm) | D (mm) | E (mm) | F (mm) |
|----------|--------|--------|--------|--------|--------|--------|
| 0 880 23 | 199    | 282    | 181    | 264    | 81     | 67     |
| 0 880 24 | 237    |        | 219    |        |        |        |
| 0 880 25 | 282    |        | 264    |        |        |        |

### ■ For installation in raised floor

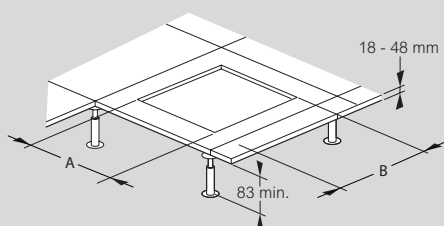


| Cat.No   | A (mm) | B (mm) |
|----------|--------|--------|
| 0 880 23 | 181    | 264    |
| 0 880 24 | 219    |        |
| 0 880 25 | 264    |        |

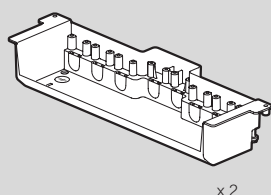


### ■ Installation principle in concrete floor

With auto-adjusting backbox

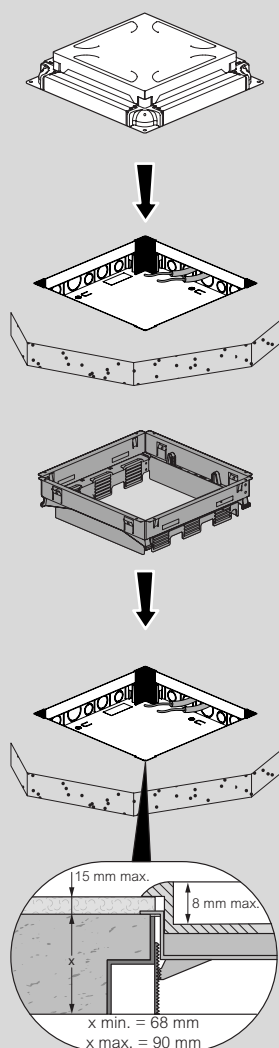


With universal adjustable backbox

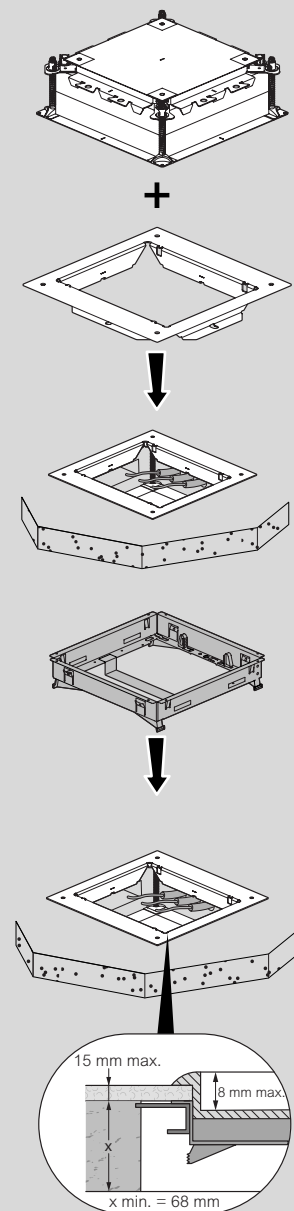


standard version Floor boxes - plastic lid and trim and finishing plate

technical characteristics


■ Dimensions

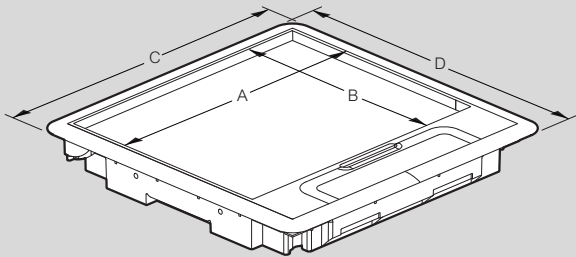


| Cat.No   | A (mm) | B (mm) | C (mm) | D (mm) |
|----------|--------|--------|--------|--------|
| 0 880 00 | 245    | 117    | 286    | 203    |
| 0 880 01 |        | 155    |        | 241    |
| 0 880 02 |        | 200    |        | 286    |

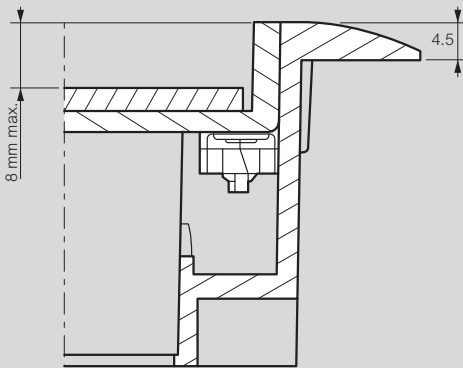

■ Dimensions

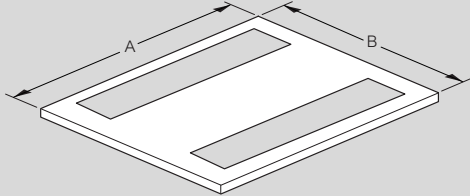


| Cat.No   | A (mm) | B (mm) |
|----------|--------|--------|
| 0 880 15 | 244    | 116    |
| 0 880 16 |        | 154    |
| 0 880 17 |        | 199    |

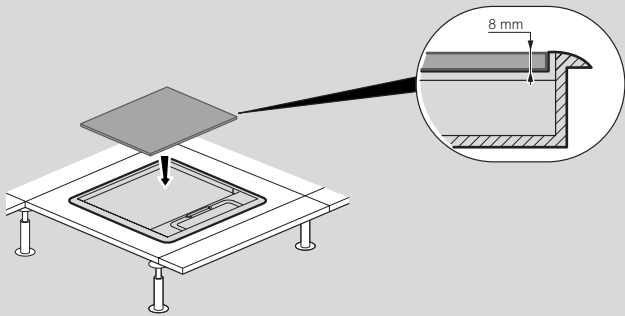


# Standard version floor boxes - metal lid and trim and finishing plate

## technical characteristics


### ■ Dimensions

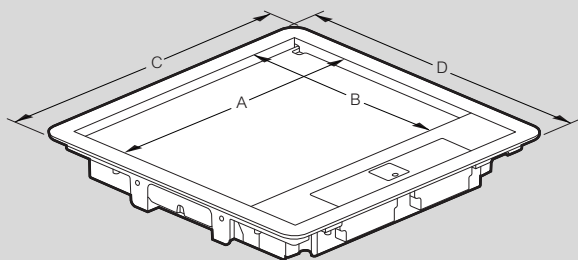

| Cat.No      | A (mm) | B (mm) | C (mm) | D (mm) |
|-------------|--------|--------|--------|--------|
| 0 880 03/06 | 250    | 118    | 286    | 203    |
| 0 880 04/07 |        | 156    |        | 241    |
| 0 880 05/08 |        | 200    |        | 286    |

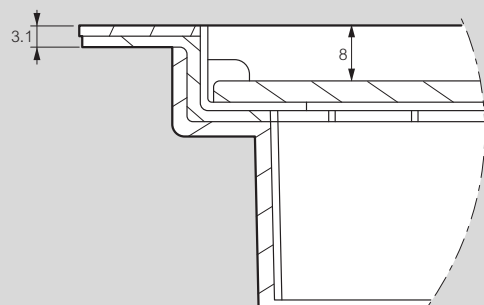

### ■ Dimensions

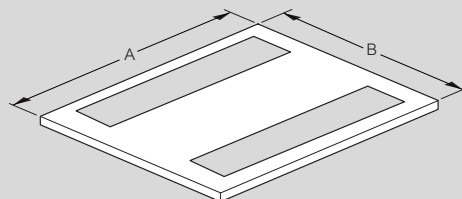

| Cat.No      | A (mm) | B (mm) |
|-------------|--------|--------|
| 0 880 45/48 | 248    | 116    |
| 0 880 46/49 |        | 154    |
| 0 880 47/50 |        | 199    |

