



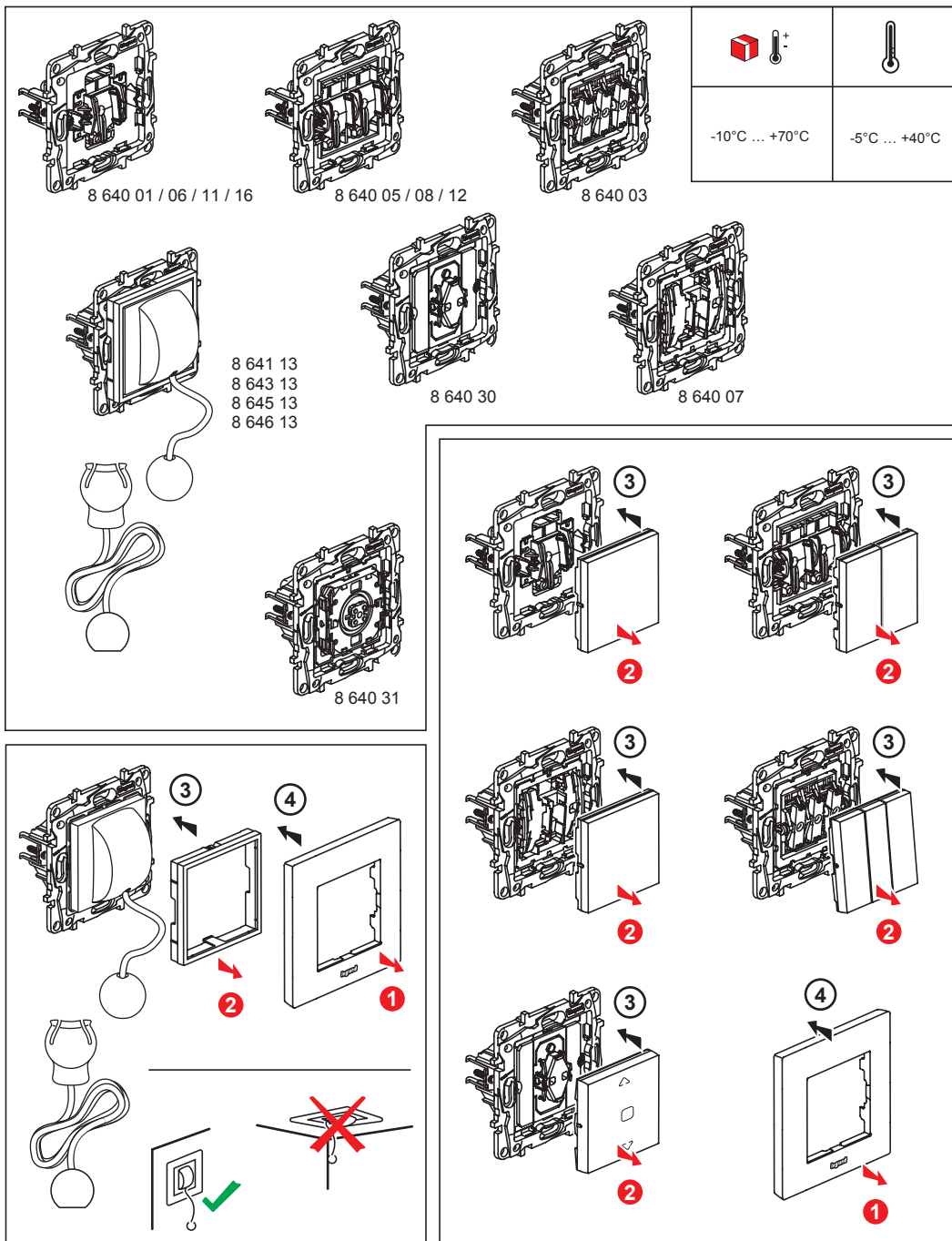

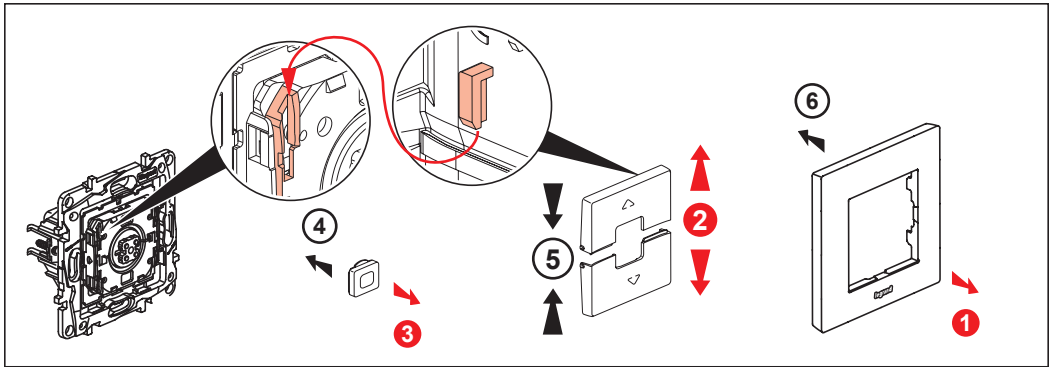


8 640 01

10 AX - 250 V~

≤ 2,5 mm²

13 mm

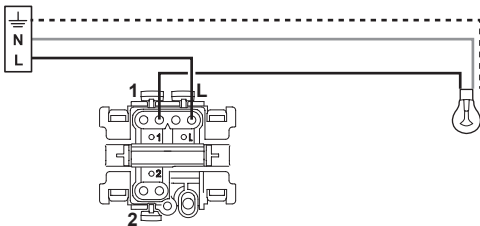


8 640 03

10 AX - 250 V~

≤ 2,5 mm²

10 mm

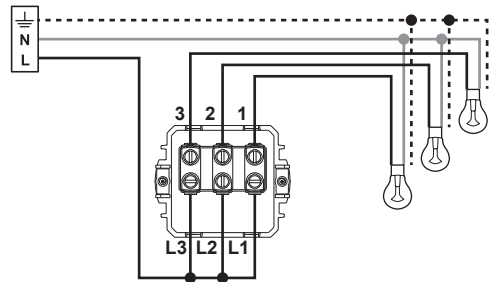


8 640 05

10 AX - 250 V~

≤ 2,5 mm²

13 mm

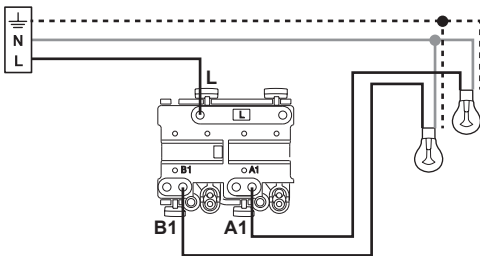


8 640 06 / 16

10 / 16 AX - 250 V~


≤ 2,5 mm²

13 mm

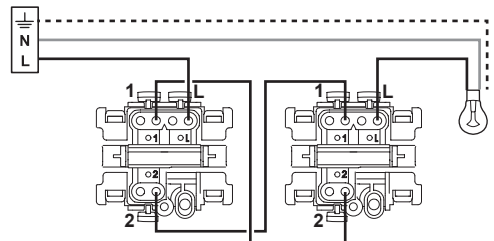

8 640 07

 10 AX - 250 V~





8 640 06

8 640 07

8 640 06



8 640 08

 10 AX - 250 V~

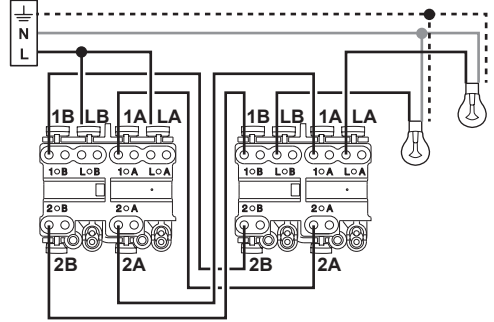



8 640 11

 6 A - 250 V~

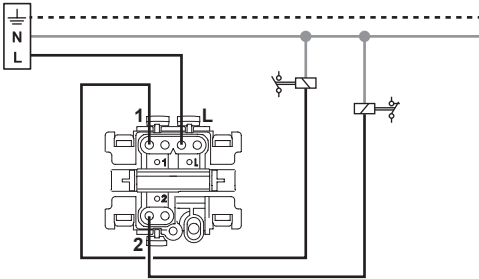



8 640 12

 6 A - 250 V~

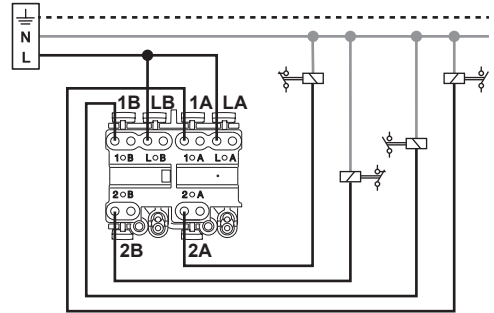



8 640 30

 6 A - 250 V~

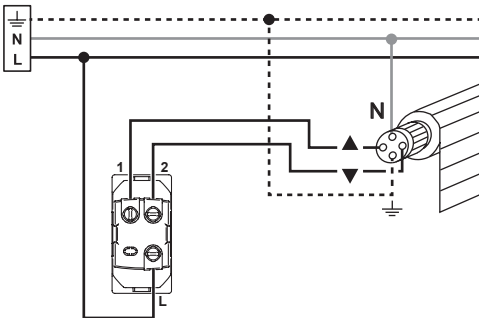

8 640 31

 6 AX - 250 V~

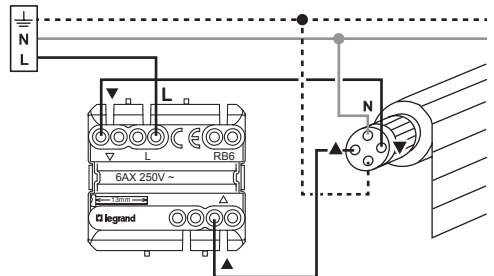

8 641 13
8 643 13
8 645 13
8 646 13

6 A - 250 V~ m	
	≤ 2,5 mm²
	12 mm

