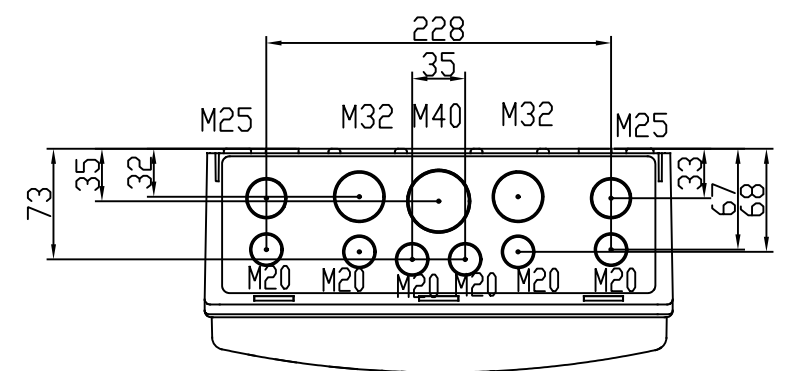
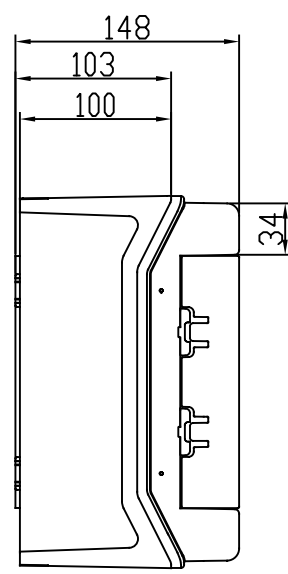
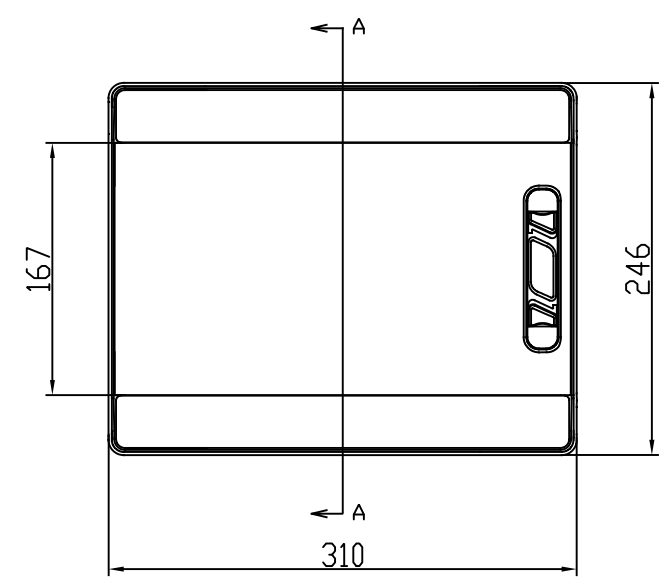
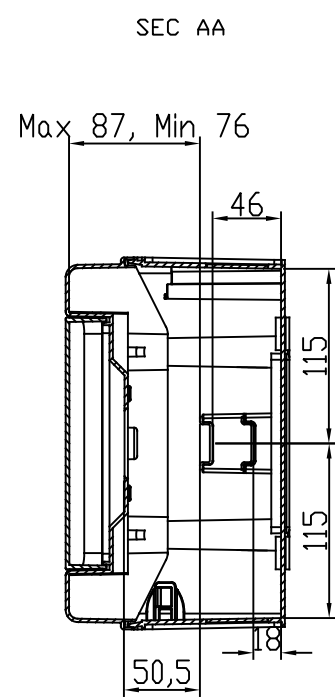
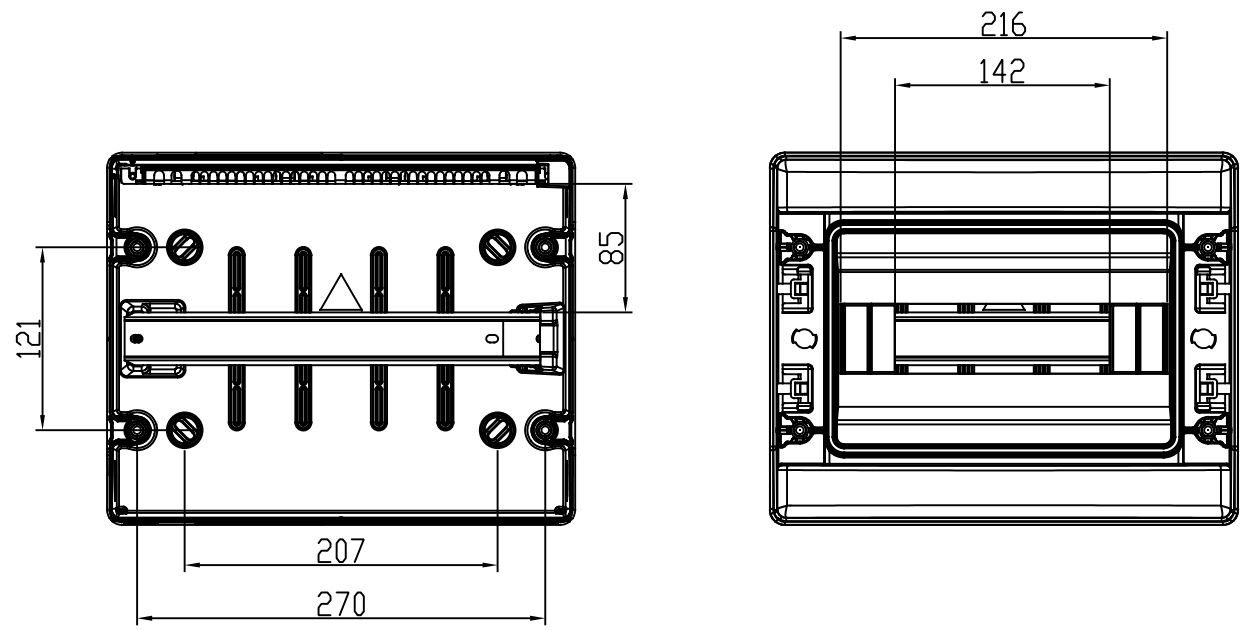

 


1 2 3 4 5 6 7 8

| Id | Description | By | Appr. |
|----|-------------|----------|-------|
| | | | |
| A | First issue | 08.01.18 | AKu |



6 x M20
 2 x M25
 2 x M32
 1 x M40

| Part | Code | Description | Information | Pcs Kpl |
|---|------|---|-------------|---------|
| - | - | - | - | - |
| - | - | - | - | - |
| | | | PC | |
|  Ensto Finland Oy | |  Distribution enclosure 12 mod Moduulikotelo 12 moluulia | Replays: | |
| Scale A3 | | | Replaced: | |
| Date 08.01.18 | | | Drw No: A | |
| By AKu | | | Ref: | |
| Ctrl | | Code: MODPC121PN | | |
| - | | Sheet No: 1 | | |

Toleranssi/Tolerance ISD 2768-c
 Meisto/Holes ISD 5803-m
 Hitsaus/Welded ISD 13920-BF

A
 B
 C
 D
 E