


# Product data sheet

# JUNG

Timer switch insert 1-pole, 2-way, max. 30 min.

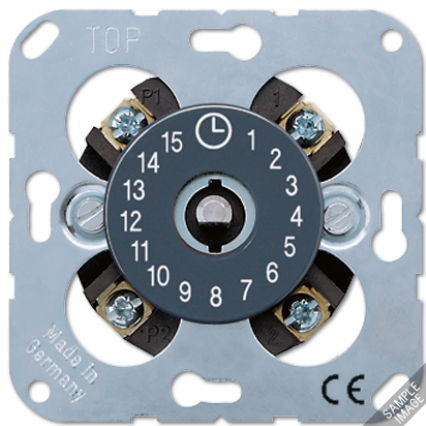

## Reference number

11030-20

Timer switch insert 16 AX / 250 V ~

Screw terminals for wires up to 4 mm<sup>2</sup>

screw fixing only, without claws  
with scale disc  
accuracy  $\pm 10\%$

### Spare scale disc

for ref.-no. 11015: SKS 11015

for ref.-no. 11120-20: SKS 11120-20

### Centre plates:

AS / A ranges: ref.-no. .. 1541 ..

CD range: ref.-no. CD 1541 ..

SL range: ref.-no. SL 1541 ..

LS range: ref.-no. LS 1941 .., .. 1941 ..

### Version:

1-pole, 2-way

### Version:

max. 30 min.

