



Aino alavalolla

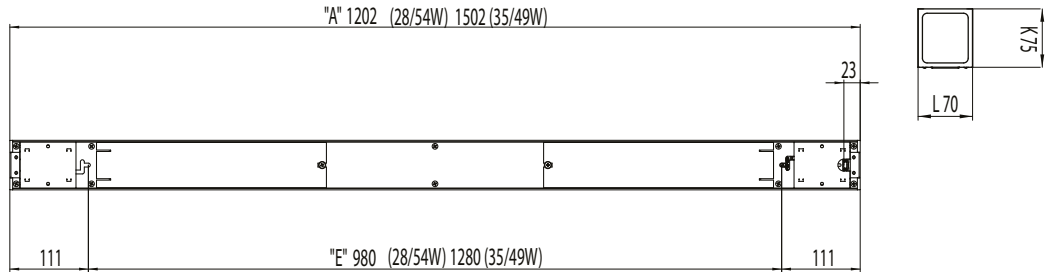

Aino ala-/ylävalolla

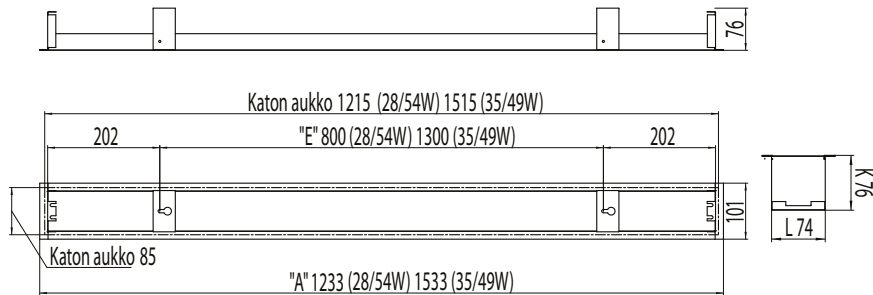

Aino upotuskehys (T5-mallit)

Tyyppi	Tuotenimi	A	E
<b>Aino LED - alavalomallit - satiinikupu (93)</b>			
AIL144F	AIL144F LED 24W/840 AC F	1150	928
AIL144FED	AIL144FED LED 24W/840 F DALI	1150	928
AIL154F	AIL154F LED 28W/840 AC F	1430	1208
AIL154FED	AIL154FED LED 28W/840 F DALI	1430	1208
<b>Alavalomallit - puolikiiltävä matalaluminanssiritilä (33)</b>			
AI281033	AI281033 T5 28W	1202	980
AI281033ED	AI281033ED T5 28W DALI	1202	980
AI351033	AI351033 T5 35W	1502	1280
AI351033ED	AI351033ED T5 35W DALI	1502	1280
AI491033	AI491033 T5 49W	1502	1280
AI491033ED	AI491033ED T5 49W DALI	1502	1280
AI541033	AI541033 T5 54W	1202	980
AI541033ED	AI541033ED T5 54W DALI	1202	980
<b>Hajavalomallit, ylävalo 10 % - puolikiiltävä matalaluminanssiritilä (33)</b>			
AI281033Y	AI281033Y T5 28W	1202	980
AI281033YED	AI281033YED T5 28W DALI	1202	980
AI351033Y	AI351033Y T5 35W	1502	1280
AI351033YED	AI351033YED T5 35W DALI	1502	1280
AI491033Y	AI491033Y T5 49W	1502	1280
AI491033YED	AI491033YED T5 49W DALI	1502	1280
AI541033Y	AI541033Y T5 54W	1202	980
AI541033YED	AI541033YED T5 54W DALI	1202	980
<b>Alavalomallit multilaitteella - puolikiiltävä matalaluminanssiritilä (33)</b>			
AI28M1033	AI28M1033 T5 28/54W	1202	980
AI35M1033	AI35M1033 T5 35/49W	1502	1280

Tyyppi	Tuotenimi	A	E
<b>Hajavalomallit, ylävalo 10%, multilaitteella - puolikiiltävä matalaluminanssiritilä (33)</b>			
AI28M1033Y	AI28M1033Y T5 28/54W	1202	980
AI35M1033Y	AI35M1033Y T5 35/49W	1502	1280
<b>Alavalomallit - uritettu satiinikupu (93)</b>			
AI281093	AI281093 T5 28W AC C	1202	980
AI281093ED	AI281093ED T5 28W AC C DALI	1202	980
AI351093	AI351093 T5 35W AC C	1502	1280
AI351093ED	AI351093ED T5 35W AC C DALI	1502	1280
AI491093	AI491093 T5 49W AC C	1502	1280
AI491093ED	AI491093ED T5 49W AC C DALI	1502	1280
AI541093	AI541093 T5 54W AC C	1202	980
AI541093ED	AI541093ED T5 54W AC C DALI	1202	980
<b>Hajavalomallit, ylävalo 10 % - uritettu satiinikupu (93)</b>			
AI281093Y	AI281093Y T5 28W AC C	1202	980
AI281093YED	AI281093YED T5 28W AC C DALI	1202	980
AI351093Y	AI351093Y T5 35W AC C	1502	1280
AI351093YED	AI351093YED T5 35W AC C DALI	1502	1280
AI491093Y	AI491093Y T5 49W AC C	1502	1280
AI491093YED	AI491093YED T5 49W AC C DALI	1502	1280
AI541093Y	AI541093Y T5 54W AC C	1202	980
AI541093YED	AI541093YED T5 54W AC C DALI	1202	980
<b>Alavalomallit multilaitteella - uritettu satiinikupu (93)</b>			
AI28M1093	AI28M1093 T5 28/54W AC C	1202	980
AI35M1093	AI35M1093 T5 35/49W AC C	1502	1280
<b>Hajavalomallit, ylävalo 10 %, multilaitteella - uritettu satiinikupu (93)</b>			
AI28M1093Y	AI28M1093Y T5 28/54W AC C	1202	980
AI35M1093Y	AI35M1093Y T5 35/49W AC C	1502	1280