

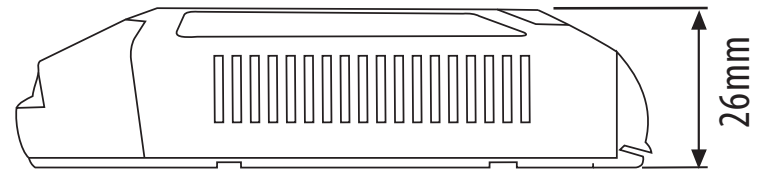


ALSD168NU - min. 340 mm
ALSD180PU - min. 360 mm
ALSD240PU - min. 480 mm

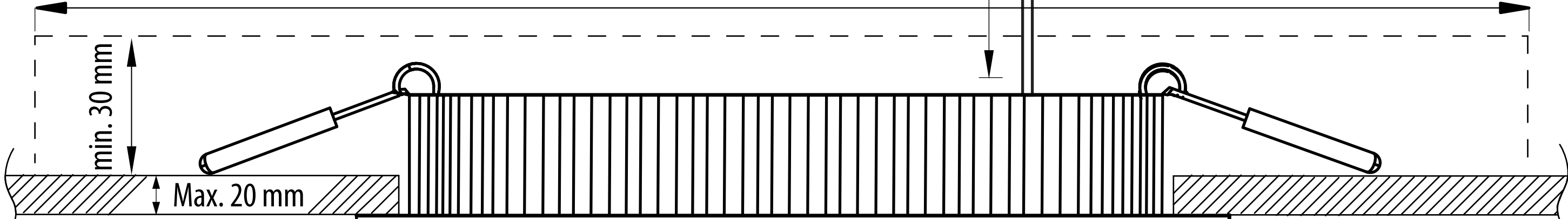


245mm

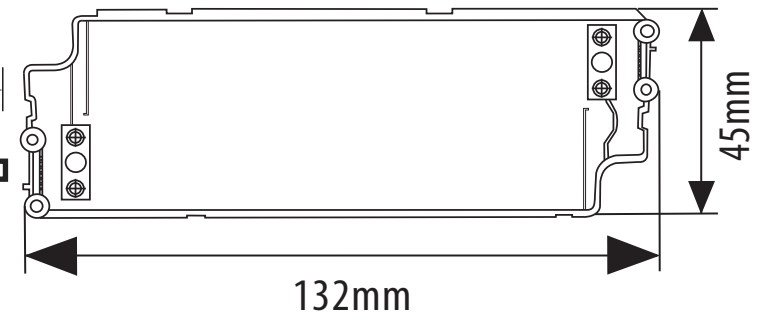

IP 20

IP 44

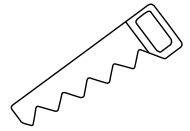

ALSD168NU - 152x152 mm
ALSD180PU - Ø165 mm
ALSD240PU - Ø225 mm

ALSD168NU - 168x168 mm
ALSD180PU - Ø180 mm
ALSD240PU - Ø240 mm

