



Ref. Certif. No.

FR_719038/A1

IEC SYSTEM FOR MUTUAL RECOGNITION OF TEST CERTIFICATES FOR ELECTRICAL EQUIPMENT (IECEE) CB SCHEME

CB TEST CERTIFICATE

Product

Socket-outlet for fixed-electrical installations
Socket-outlets for fixed installations

Name and address of the applicant

Legrand Intelligent Electrical (Huizhou) Co., Ltd.
Bldg. B1-B3, East No. 39 Hechang 6th Rd., HZZK Hi-tech
Industrial Development Zone, Huizhou, Guangdong - CHINA

Name and address of the manufacturer

LEGRAND FRANCE
128 AVENUE DU MARECHAL DE LATTRE DE TASSIGNY
87045 LIMOGES CEDEX - FRANCE

Name and address of the factory

Note: When more than one factory, please report on page 2

☒ Additional Information on page 2

Ratings and principal characteristics

See Annex

Trademark / Brand (if any)



Customer's Testing Facility (CTF) Stage used

/

Model / Type Ref.

AC3173MW, AC3173MT, AC3173MB

Additional information (if necessary may also be reported on page 2)

Supersedes CBTC FR_719038 dated 28/05/2024.
Editorial correction

☐ Additional Information on page 2

A sample of the product was tested and found to be in conformity with

IEC 60884-1:2022

As shown in the Test Report Ref. No. which forms part of this Certificate

ARLI-ESH-P24020237

This CB Test Certificate is issued by the National Certification Body

 


LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE
33 avenue du Général Leclerc
92260 Fontenay-aux-Roses, FRANCE
www.lcie.fr

Date: 18/06/2024



LABORATOIRE CENTRAL DES
INDUSTRIES ELECTRIQUES
S.A.S au capital de 15.745.984 €
RCS Nanterre B 408 343 174
33 avenue du Général Leclerc
F - 92266 FONTENAY AUX ROSES

Signature: 
Julien GAUTHIER
Certification Officer

ANNEX

Name and address of the factories:

Legrand Intelligent Electrical (Huizhou) Co., Ltd.

Bldg. B1-B3, East No. 39 Hechang 6th Rd., HZZK Hi-tech Industrial Development Zone, Huizhou, Guangdong - CHINA

NOVATEUR ELECTRICAL & DIGITAL SYSTEMS PVT. LTD

A-2, MIDC AREA, MALEGAON VILLAGE, SINNAR, DIST. NASHIK 422113 MAHARASHTRA - INDIA

LEGRAND

AVENUE DU PARC ALATA - 60550 VERNEUIL EN HALATTE - FRANCE

RAIS HASSAN SAADI Logistics Dubai

Jebel Ali Free Zone, P.O. Box 7 Dubai – UNITED ARAB EMIRATES

References, ratings and main characteristics:

All the commercial references listed below may be supplemented with a prefix of type LG-, BT-, ... (to indicate the brand) and/or suffix of type 0, 1, 2, 3, 4, FI, EX, ... In this case, the products are technically the same.

References

Matt White	Matt Titanium	Matt Black			
Commercial ref	Commercial ref	Commercial ref	Rated values	Module	Specificities
AC3173MW	AC3173MT	AC3173MB	15A 127V~	3	douplex

Blank

Commercial ref			Designation
Matt White	Matt Titanium	Matt Black	
AC150MW	AC150MT	AC150MB	1 BLANK MODULE
AC153MW	AC153MT	AC153MB	2 BLANK MODULES

Frame

Commercial ref	Designation
A1404	1G 3M HORIZOVERTICAL BS FRAME
A1408	2G 3M BS FRAME
A1417	6M BS FRAME
A1411	8M BS FRAME
A1406	4M IT/FR/SCH FRAME
A1407	6M IT/FR/SCH FRAME
A1405	3M IT/US FRAME




LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE

33 avenue du Général Leclerc

92260 Fontenay-aux-Roses, FRANCE

www.lcie.fr

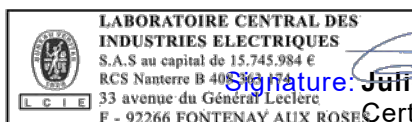

Signature: *Julien GAUTHIER*
Certification Officer

Date: 18/06/2024

ANNEX

Cover plates

Commercial ref									Designation
Matt White	Matt Titanium	Matt Black	Frosted White	Frosted Black	Dark Aluminium	Brushed Stainless Steel	Night Blue	Solid Aluminium	
Classic									
AC1104 MW	AC1104M T	AC1104 MB	AC1104FW	AC1104FB	AC1104DA	AC1104BS	AC1104 NB	AC1104SA	1G 3M BS HORIZVERT PLATE
AC1105 MW	AC1105M T	AC1105 MB	AC1105FW	AC1105FB	AC1105DA	AC1105BS	AC1105 NB	AC1105SA	3M BS PLATE FOR 2G BOX
AC1107 MW	AC1107M T	AC1107 MB	AC1107FW	AC1107FB	AC1107DA	AC1107BS	AC1107 NB	AC1107SA	3M IT/US PLATE
AC1110 MW	AC1110M T	AC1110 MB	AC1110FW	AC1110FB	AC1110DA	AC1110BS	AC1110 NB	AC1110SA	4M IT/FR/SCH PLATE
AC1111 MW	AC1111M T	AC1111 MB	AC1111FW	AC1111FB	AC1111DA	AC1111BS	AC1111 NB	AC1111SA	6M IT/FR/SCH PLATE
Hybrid									
			AB1201FW	AB1201FB	AB1201DA	AB1201BS	AB1201 NB	AB1201SA	6M HYBRID PLATE 3M + 2M SWITCH
			AB1204FW	AB1204FB	AB1204DA	AB1204BS	AB1204 NB	AB1204SA	6M HYBRID PLATE 4M + 1M SWITCH
			AB1200FW	AB1200FB	AB1200DA	AB1200BS	AB1200 NB	AB1200SA	6M HYBRID PLATE 3M + 2M DIMMER
			AB1206FW	AB1206FB	AB1206DA	AB1206BS	AB1206 NB	AB1206SA	8M HYBRID PLATE 5M +2M DIMMER


Cover plates + Frame

Commercial ref									Designation
Matt White	Matt Titanium	Matt Black	Frosted White	Frosted Black	Dark Aluminium	Brushed Stainless Steel	Night Blue	Solid Aluminium	
Classic									
AC1204MW	AC1204MT	AC1204MB	AC1204FW	AC1204FB	AC1204DA	AC1204BS	AC1204NB	AC1204SA	6M BS PLATE+FRAME
AC1209MW	AC1209MT	AC1209MB	AC1209FW	AC1209FB	AC1209DA	AC1209BS	AC1209NB	AC1209SA	2 X 6M BS PLATE+FRAME
AC1206MW	AC1206MT	AC1206MB	AC1206FW	AC1206FB	AC1206DA	AC1206BS	AC1206NB	AC1206SA	8M PLATE+FRAME



LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE
33 avenue du Général Leclerc
92260 Fontenay-aux-Roses, FRANCE
www.lcie.fr

Date: 18/06/2024

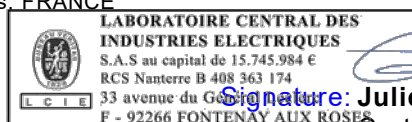


Signature: **Julien GAUTHIER**
Certification Officer

ANNEX

standard Sheet:	Figure 5-15 of NEMA WD6
rated current (A)	15A
rated load (W)	-
rated voltage (V)	127V~
household voltage (V)	-
degree of protection	IP20
provision for earthing	with earthing contact
method of connecting the cable	rewirable
type of terminals	screw-type
type of connections	-
socket-outlets	
multiple socket-outlets	15A: 2
number of socket-outlets	
degree of protection against electric shock	normal protection
existence of shutters	with shutters
method of application - mounting	flush-type
method of installation	design A
plugs:	
class of equipment	-
entry of cable	-



LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE
33 avenue du Général Leclerc
92260 Fontenay-aux-Roses, FRANCE
www.lcie.fr

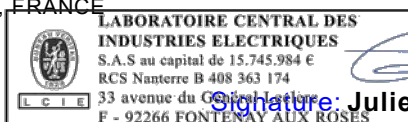

Signature
Julien GAUTHIER
Certification Officer

Date: 18/06/2024