

IEC**IECEE**

®

™

Ref. Certif. No.

FR_717646

IEC SYSTEM FOR MUTUAL RECOGNITION OF TEST CERTIFICATES FOR ELECTRICAL EQUIPMENT (IECEE) CB SCHEME

CB TEST CERTIFICATE

Product

Fixed switched socket-outlet

Switched socket-outlets for fixed installations

Name and address of the applicant

Legrand Intelligent Electrical (Huizhou) Co., Ltd.

Bldg. B1-B3, East No. 39 Hechang 6th Rd., HZZK Hi-tech Industrial Development Zone, 516001, Huizhou Guangdong - CHINA

Name and address of the manufacturer

LEGRAND FRANCE

128 AVENUE DU MARECHAL DE LATTRE DE TASSIGNY 87045 LIMOGES CEDEX - FRANCE

Name and address of the factory

Legrand Intelligent Electrical (Huizhou) Co., Ltd.

Bldg. B1-B3, East No. 39 Hechang 6th Rd., HZZK Hi-tech Industrial Development Zone, 516001, Huizhou Guangdong - CHINA

Note: When more than one factory, please report on page 2

 Additional Information on page 2

Ratings and principal characteristics

See Annex

Trademark / Brand (if any)



1)

2) tenby

Customer's Testing Facility (CTF) Stage used

/

Model / Type Ref.

1) 730089, 733889, 733889S

2) 738055

Additional information (if necessary may also be reported on page 2)

 Additional Information on page 2

A sample of the product was tested and found to be in conformity with

IEC 60884-2-3:2006

IEC 60884-1:2002(ed.3) +A1:2006 +A2:2013

As shown in the Test Report Ref. No. which forms part of this Certificate

ARLI-ESH-P22081037

This CB Test Certificate is issued by the National Certification Body

**LCIE**

LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE

33 avenue du Général Leclerc

92260 Fontenay-aux-Roses, FRANCE

www.lcie.fr

LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES

S.A.S au capital de 15.745.984 €

RCS Nanterre B 408 363 174

33 avenue du Général Leclerc

F - 92266 FONTENAY AUX ROSES

Signature: 
Certification Officer

Date: 15/09/2023

ANNEX

References, ratings and main characteristics:

Reference	Description	Color of enclosure
738055	Without box flush-type	White
730089		White
733889	Totally the same With box 736400 surface-type	Metalclad Grey
733889S		Metalclad Grey

Classification

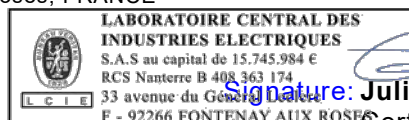
standard Sheet:	standard sheet of BS 546
rated current (A)	15A
rated voltage (V)	250V
degree of protection	IP20
provision for earthing	with earthing contact
method of connecting the cable	rewirable
type of terminals	screw-type
colour	See the table above
socket-outlets	
multiple socket-outlets	15A : 1
number of socket-outlets	
degree of protection against electric shock	normal protection
existence of shutters	with shutters
method of application - mounting	flush-type /surface type
method of installation	design B
Intended for circuits where	a single earthing circuit provides protective earthing
Switched socket-outlets without interlock	
According to the method of actuating the switch	rocker
According to the switching of the neutral	unswitched neutral

type of components	manufacturer	Certification
Box for 733889 and 733889S	LEGRAND FRANCE	LCIE test report No. ARLI-ESH-P22081644



LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE
 33 avenue du Général Leclerc
 92260 Fontenay-aux-Roses, FRANCE
www.lcie.fr

Date: 15/09/2023


 Signature: **Julien GAUTHIER**
 Certification Officer