

IEC**IECEE**

Ref. Certif. No.

FR_706409/M1

IEC SYSTEM FOR MUTUAL RECOGNITION OF TEST CERTIFICATES FOR ELECTRICAL EQUIPMENT (IECEE) CB SCHEME

CB TEST CERTIFICATE

Product

Fixed socket-outlet

Socket-outlets for fixed installations

Name and address of the applicant

LEGRAND MAGYARORSZAG VILLAMOSSAGI RENDSZEREK ZRtIPARTELEPI UT 14 PF 10
6600 SZENTES - HUNGARY

Name and address of the manufacturer

LEGRAND MAGYARORSZAG VILLAMOSSAGI RENDSZEREK ZRtIPARTELEPI UT 14 PF 10
6600 SZENTES - HUNGARY

Name and address of the factory

LEGRAND MAGYARORSZAG VILLAMOSSAGI RENDSZEREK ZRtIPARTELEPI UT 14 PF 10
6600 SZENTES - HUNGARY

Note: When more than one factory, please report on page 2

 Additional Information on page 2

Ratings and principal characteristics

See annex

Trademark / Brand (if any)

legrand

Customer's Testing Facility (CTF) Stage used

/

Model / Type Ref.

077505, 678148, 678198, 678240, 678241, 678242

Additional information (if necessary may also be reported on page 2)

Supersedes CBTC FR_706409 dated 22/07/2019.
Re-issue date Additional Information on page 2

A sample of the product was tested and found to be in conformity with

IEC 60884-1:2002+A1:2006 +A2:2013

As shown in the Test Report Ref. No. which forms part of this Certificate

ABND-ESH-P22071953

This CB Test Certificate is issued by the National Certification Body

 
**LCIE**LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE
33 avenue du Général Leclerc
92260 Fontenay-aux-Roses, FRANCEwww.lcie.frLABORATOIRE CENTRAL DES
INDUSTRIES ELECTRIQUES

S.A.S au capital de 15.745.984 €

RCS Nanterre B 408 263 174

33 avenue du Général Leclerc

F - 92266 FONTENAY AUX ROSES

Signature: 
Julien GAUTHIER
Certification Officer

Date: 26/09/2022

ANNEX

REFERENCES, RATING AND MAIN CHARACTERISTICS :

Reference	Range*	Description	Color of enclosure	with cover plate	with support frame
077505	MOSAIC	2P+E 13A British Standard unswitched 1 gang	White	678011	678000
678148	MOSAIC	2P+E 13A British Standard unswitched 1 gang Antimicrobial	White	678026	678000
678198	MOSAIC	2P+E 13A British Standard unswitched 1 gang	Alu	678031	678000
678240	MOSAIC	2P+E 13A British Standard unswitched 1 gang	Red cover with white cover plate	678011	678000
678241	MOSAIC	2P+E 13A British Standard unswitched 1 gang	Green cover with white cover plate	678011	678000
678242	MOSAIC	2P+E 13A British Standard unswitched 1 gang	Orange cover with white cover plate	678011	678000


* The "range" denotes applicant's categorization.

standard Sheet:	standard sheet of BS 1363-2
rated current (A)	13A
rated voltage (V)	250V
degree of protection	IP20
provision for earthing	with earthing contact
method of connecting the cable	rewirable
type of terminals	screw-type
colour	See the table above
socket-outlets	
multiple socket-outlets	
number of socket-outlets	13A : 1
degree of protection against electric shock	normal protection
existence of shutters	with shutters
method of application - mounting	flush-type
method of installation	design A



LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE
33 avenue du Général Leclerc
92260 Fontenay-aux-Roses, FRANCE
www.lcie.fr

Date: 26/09/2022

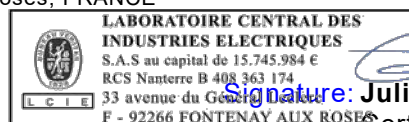

Signature: **Julien GAUTHIER**
Certification Officer