



LCIE

LICENCE



APPAREILLAGE ELECTRIQUE
DOMESTIQUE

LCIE N° : NF012_3762

Titulaire :
License Holder:

LEGRAND FRANCE
128 AVENUE DU MARECHAL DE LATTRE DE TASSIGNY
87045 LIMOGES CEDEX
France

Site de fabrication :
Factory:

0002A
1456AP
28850
1968AP;

Produit :
Product:

Socle fixe de prise de courant pour installations fixes
Socket-outlet for fixed-electrical installations

Marque commerciale (s'il y a lieu) :
Trade mark (if any):



Modèle, type, référence :
Model, type, reference:

Voir Annexe / *See Annex*

Caractéristiques principales :
Main characteristics:

Voir Annexe / *See Annex*

Informations complémentaires :
Additional information:

/

Le produit est conforme à :
The product is in conformity with:

NF C 61-314:2017

Documents pris en compte :
Relevant documents:

TR n° 16291432-782924

Annule et remplace (s'il y a lieu) :
Cancels and replaces (if necessary):

La licence / *License* NF012_1880 du/of 09/04/2019. Mise à jour suite à évolution de(s) norme(s)/update further to the evolution of the standard(s), Ajout d'un site de fabrication/addition of factory, ajout de références/addition of references

En vertu de la présente décision notifiée par le LCIE organisme mandaté, AFNOR Certification accorde le droit d'usage de la Marque NF à la société qui en est titulaire pour les produits visés ci-dessus, dans les conditions définies par les règles générales de la Marque NF et par les règles de certification NF, pour autant que les contrôles réguliers de la fabrication et les vérifications par tierce partie soient satisfaisants.


On the strength of the present decision notified by LCIE mandated certification body, AFNOR Certification grants the right to use the NF Mark to the licence holder for the above mentioned products, within the frame of the general rules of the NF Mark and of the NF certification rules, as far as the regular checking and third party verifications of the production are satisfactory.

Fontenay-aux-Roses, 13/01/2023

Date de fin de validité / *Expiry date* :

La validité de la présente licence cesse dès l'annulation de l'une des normes sur lesquelles elle est fondée.

The present license is valid until the cancellation of one of the standards on which it is based.

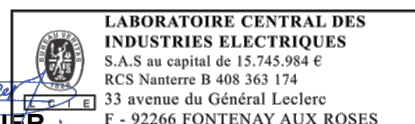

Julien Gauthier
Julien GAUTHIER
Responsable Certification/Certification Officer



Accréditation
N° 5-0014
Portée disponible sur
www.cofrac.fr

LCIE
Laboratoire Central des Industries Electriques
Une société de Bureau Veritas

33 Avenue du Général Leclerc
92260 Fontenay-aux-Roses
FRANCE

WWW.LCIE.FR

RÉFÉRENCES - CARACTÉRISTIQUES PRINCIPALES REFERENCES - MAIN CHARACTERISTICS

Type references	References Blanc with claw and plate	References Aluminium with claw and plate	References Blanc with plate	References Blanc	References Aluminium	References Noir velour	Function	Terminals	Specificity	Product put on sale
LOP12 6 00X 34	6 007 34			6 003 34	6 004 34	6 005 34	2P	slt	low depth	
				0 952 14	0 952 44	0 952 74	2P	slt	low depth	6 00X 34
LOR12 6 00X 28	6 007 28			6 003 28	6 004 28	6 005 28	2P+E	slt	low depth	
				0 952 17	0 952 47	0 952 77	2P+E	slt	low depth	6 00X 28
LOF12 6 00X 37				6 003 37	6 004 37		2P+E	slt		
				0 952 16	0 952 46	0 952 76	2P+E	slt		6 00X 37
LOF12			6 003 44				2P+E	slt	IP44	
LOF12 6 00X 35	6 007 35			6 003 35	6 004 35		2P+E	slt	mobile face of entry plug	
				6 006 35			2P+E	slt	mobile face of entry plug send by 50	50 x 6 00X 35
	0 950 15	0 950 35					2P+E	slt	mobile face of entry plug	6 00X 35 + 6 008 01/51
	0 950 25	0 950 45					2P+E	slt	mobile face of entry plug	6 00X 35 + 6 008 01/51
	0 950 55	0 950 75					2P+E	slt	mobile face of entry plug	6 00X 35 + 6 009 80/75
	0 950 65	0 950 85					2P+E	slt	mobile face of entry plug	6 00X 35 + 6 009 80/75
				0 952 15	0 952 45	0 952 75	2P+E	slt	mobile face of entry plug	6 00X 35
				300 440	300 441		2P+E	slt	mobile face of entry plug	10 x 6 00X 35 + 6 008 01
			300 421	300 423		2P+E	slt	mobile face of entry plug	5 x 6 00X 35 + 6 008 01	

	References Blanc with claw and plate	References Aluminium with claw and plate	References Blanc with plate	References Blanc	References Aluminium	References Noir velour	Function	Terminals	Specificity	Product put on sale
				300 425	300 427		2P+E	slt	mobile face of entry plug	5 x 6 00X 35 + 6 009 80/75
				300 431	300 433		2P+E	slt	mobile face of entry plug	6 x 6 00X 35 + 6 008 01
				300 435	300 437		2P+E	slt	mobile face of entry plug	6 x 6 00X 35 + 6 009 80/75
				300 453	300 454	300 455	2P+E	slt	mobile face of entry plug	6 x 6 00X 35
LOF12 6 00X 20				6 003 20	6 004 20		2P+E	slt	mobile face of entry plug and pilot light	
PFAG1	6 007 21			6 003 21			2 x 2P+E	slt	1 gang	
PFAD1 6 00X 32				6 003 32	6 004 32	6 005 32	3 x 2P+E	slt		
				0 952 18	0 952 48	0 952 78	4 x 2P+E	slt		6 00X 32
				300 400	300 401	300 402	5 x 2P+E	slt		6 00X 32 + 6 008 02/52 + 0801 02
				300 403			6 x 2P+E	slt		6 00X 32 + 6 008 02/52 + 6 000 42
PFAT1 6 00X 33				6 003 33	6 004 33	6 005 33	3 x 2P+E	slt		
				0 952 19	0 952 49	0 952 79	3 x 2P+E	slt		6 00X 33
				300 404	300 405	3 004 06	3 x 2P+E	slt		6 00X 33 + 6 008 03/53 + 0 801 03
LXX08	6 007 41			6 003 41	6 004 41	6 005 41	2P+E	slt	with usb type C*	

slt : sans vis / screwless terminal

* for USB type C see test report N° 158526-730181

Caractéristiques des appareils / characteristics of appliances

Standard sheet	I NF C 61-314 / V CEE7 (2P+T) - IIIA NF C 61-314 / I CEE7 (2P)
Rated current (A)	16A
Rated voltage (V)	250V
degree of protection	IP20 - IP44 with cover plate 6 009 44 or 6 003 44
Provision for earthing	Without earthing contact With earthing contact
Method of connecting the cable	Rewirable
Type of terminals	Screwless (rigid and flexible)
Degree of protection against electric shock	Normal protection
Existence of shutters	with shutters
Method of application - mounting	Surface type (with boxes for surface mounting) or flush-type
Method of installation	Design A

Accessories

References	Designation
6 000 47	short claw
6 000 48	claw
0 952 91	claw
6 000 49	long claw
6 000 45	Permeability socket

Pilot light

References	Designation
6 002 43	Indicator 230V 3mA

boxes for surface mounting

type references	References	Designation
6 00X 41	6 000 41	1 gang blanc
	0 952 92	1 gang blanc
	6 001 41	1 gang aluminium
6 00X 42	6 000 42	2 gang blanc
	0 952 93	2 gang blanc
	6 001 42	2 gang aluminium

Cover plate

	Blanc	Dune	Plume	Atoll	Raisin	Aluminium	Noir velour
1 gang square	6 008 01 6 009 01 6 009 41*	6 008 11	6 008 21	6 008 31	6 009 31	6 008 51	6 008 61
2 gangs square	6 008 02 6 009 02	6 008 12	6 008 22	6 008 32	6 009 32	6 008 52	6 008 62
3 gangs square	6 008 03 6 009 03	6 008 13	6 008 23	6 008 33	6 009 33	6 008 53	6 008 63
4 gangs square	6 008 04 6 009 04	6 008 14	6 008 24			6 008 54	6 008 64
2 gangs square entraxe 57	6 008 07						

* sold by 100

bague	Blanc	Style inox brossé	Style bois ébène	Style inox sombre	Blanc
	Chrome	Chrome	Chrome sombre	Chrome sombre	Chrome rosé
1 gang square	6 008 41	6 008 71	6 008 81	6 009 11	6 009 21
2 gangs square	6 008 42	6 008 72	6 008 82	6 009 12	6 009 22
3 gangs square	6 008 43	6 008 73	6 008 83	6 009 13	6 009 23

bague	Blanc	Blanc	Blanc	Blanc	Blanc	Blanc	Aluminium	Noir velour	Style inox sombre	Style inox brossé
		Dune	Plume	Atoll	Chrome	Chrome rosé	Chrome	Chrome sombre	chrome sombre	Chrome
1 gang round	6 009 80	6 009 70	6 009 71	6 009 72	6 009 73	6 009 20	6 009 75	6 009 76	6 009 78	6 009 79

1 gang square label holder	6 009 42
1 gang square IP 44 with lid	6 009 44