

**IEC****IECEE**

Ref. Certif. No.

**FR\_713385****IEC SYSTEM FOR MUTUAL RECOGNITION OF TEST CERTIFICATES FOR ELECTRICAL EQUIPMENT (IECEE) CB SCHEME****CB TEST CERTIFICATE**

Product

**Multiple cord extension set**

Name and address of the applicant

**LEGRAND FRANCE**128 AVENUE DU MARECHAL DE LATTRE DE TASSIGNY  
87045 LIMOGES CEDEX - FRANCE

Name and address of the manufacturer

**LEGRAND FRANCE**128 AVENUE DU MARECHAL DE LATTRE DE TASSIGNY  
87045 LIMOGES CEDEX - FRANCE

Name and address of the factory

**NINGBO BANMEN ELECTRIC APPLIANCE CO., LTD.**East Industrial Zone, Guanhaiwei  
315314 Cixi City, Zhejiang Province - CHINA

Note: When more than one factory, please report on page 2

 Additional Information on page 2

Ratings and principal characteristics

See Annex

Trademark / Brand (if any)

**legrand**

Customer's Testing Facility (CTF) Stage used

/

Model / Type Ref.

See Annex

Additional information (if necessary may also be reported on page 2)

 Additional Information on page 2

A sample of the product was tested and found to be in conformity with

IEC 60884-1:2002(ed.3) +A1:2006 +A2:2013  
IEC 60884-2-7:2011 +A1:2013

As shown in the Test Report Ref. No. which forms part of this Certificate

ABND-ESH-P21123164-1  
ABND-ESH-P21123164-2

This CB Test Certificate is issued by the National Certification Body

**LCIE**

LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE

33 avenue du Général Leclerc

92260 Fontenay-aux-Roses, FRANCE

[www.lcie.fr](http://www.lcie.fr)LABORATOIRE CENTRAL DES  
INDUSTRIES ELECTRIQUES

S.A.S au capital de 15.745.984 €

RCS Nanterre B 408 363 174

33 avenue du Général Leclerc

F - 92260 Fontenay-aux-Roses

Signature **Julien GAUTHIER**

Certification Officer

Date: 07/03/2022

## ANNEX

## References, ratings and main characteristics:

Model	Reference	Number of 16A socket-outlets	Number of 10A socket-outlets	Color of enclosure
RNC11V	6 945 96	4	4	BLACK


## CLASSIFICATION

standard Sheet:	Standard sheet V of CEE 7 (16A socket-outlet) / Standard sheet ESC 10a of UNE 20315-1-2 (10A socket-out-let) / Standard sheet VII of CEE 7 (Plug)
rated current (A)	16A
rated load (W)	3680W
rated voltage (V)	250V
household voltage (V)	230V~
degree of protection	IP20
provision for earthing	with earthing contact (Solid earthing pin)
method of connecting the cable	Non-rewirable
type of terminals	-
type of connections	soldered / other (riveted)
colour	Black
<b>socket-outlets</b>	
multiple socket-outlets	10A: 4
number of socket-outlets	16A: 4
degree of protection against electric shock	normal protection
existence of shutters	with shutters
method of application - mounting	portable type
method of installation	-
<b>plugs:</b>	
class of equipment	I
entry of cable	lateral


Type of components	manufacturer	Certification
Plug	Legrand France	VDE 40018331
		CB FR 558589/M1
Cable	Legrand France	VDE 40017697
Built-in switch module	Legrand France	LCIE test report No.: ABND-ESH-P20072873
SPD	Legrand France	LCIE test report No.: ABND-ESH-P20072863
Socket-outlets	Legrand France	LCIE test report No.: ABND-ESH-P21123164-1



LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE  
 33 avenue du Général Leclerc  
 92260 Fontenay-aux-Roses, FRANCE  
[www.lcie.fr](http://www.lcie.fr)

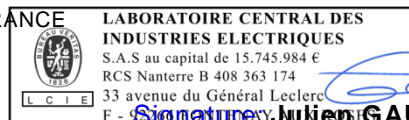

Date: 07/03/2022

 Signature:  Julien GAUTHIER  
 Certification Officer