



Ref. Certif. No.

FR_710044/M1

IEC SYSTEM FOR MUTUAL RECOGNITION OF TEST CERTIFICATES FOR ELECTRICAL EQUIPMENT (IECEE) CB SCHEME

CB TEST CERTIFICATE

Product

Portable socket-outlet
Rewirable portable socket-outlets

Name and address of the applicant

LEGRAND FRANCE
128 AVENUE DU MARECHAL DE LATTRE DE TASSIGNY
87045 LIMOGES CEDEX - FRANCE

Name and address of the manufacturer

LEGRAND FRANCE
128 AVENUE DU MARECHAL DE LATTRE DE TASSIGNY
87045 LIMOGES CEDEX - FRANCE

Name and address of the factory

NINGBO BANMEN ELECTRIC APPLIANCE CO., LTD.
East Industrial Zone, Guanhaiwei Town
315314 Cixi City, Ningbo
Zhejiang Province - CHINA

Note: When more than one factory, please report on page 2

Additional Information on page 2

Ratings and principal characteristics

See Annex

Trademark / Brand (if any)

legrand

Customer's Testing Facility (CTF) Stage used

/

Model / Type Ref.

See Annex

Additional information (if necessary may also be reported on page 2)

Supersedes CBTC FR_710044 dated 19/11/2020.
Update the list of components

Additional Information on page 2

A sample of the product was tested and found to be in conformity with

IEC 60884-1:2002(ed.3) +A1:2006 +A2:2013

 
As shown in the Test Report Ref. No. which forms part of this Certificate

ABND-ESH-P21080565

This CB Test Certificate is issued by the National Certification Body



LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE
33 avenue du Général Leclerc
92260 Fontenay-aux-Roses, FRANCE
www.lcie.fr



Date: 31/12/2021

Signature: **Didier BOURGES**
Manager of Certification Operations

ANNEX

References, ratings and main characteristics:

Model	Reference	Number of socket-outlets	With USB charger	Color of enclosure
RNC11X	6 945 03	4	N	WHITE
RNC11UX	6 945 04	3	Y	ALUMINIUM PAINTED WHITE

N = Not include this function; Y = include this function.


standard Sheet:	Standard sheet III of CEE 7
rated current (A)	16A
rated load (W)	3680W
rated voltage (V)	250V
household voltage (V)	230V
degree of protection	IP20
provision for earthing	with earthing contact
method of connecting the cable	rewirable
type of terminals	screw-type
type of connections	-
colour	white, aluminium painted white
socket-outlets	
multiple socket-outlets	
number of socket-outlets	16A : 3/4
degree of protection against electric shock	normal protection
existence of shutters	with shutters
method of application - mounting	portable type
method of installation	-
plugs:	
class of equipment	-
entry of cable	-

type of components	manufacturer	Certification
USB charger	Legrand France	LCIE test report No. ABND-ESH-P20071475
Alternative	Legrand France	ITS test report No. 210611012SZN-001



LABORATOIRE CENTRAL DES INDUSTRIES ELECTRIQUES - LCIE
 33 avenue du Général Leclerc
 92260 Fontenay-aux-Roses, FRANCE
www.lcie.fr

Date: 31/12/2021

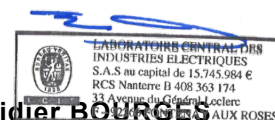

Signature: **Didier BOURGES**
 Manager of Certification Operations