


Angel intérieur	Angle extérieur	Dérivation en T	Pièce en T	Raccord de montée/ descente	Pièce terminale et réduction	Longueur 795 mm	Largeur
8312412	8312422	8312612	8312432	8312452	VG341161		200 mm
8312413	8312423	8312613	8312433	8312453			300 mm
8312414	8312424	8312614	8312434	8312454			400 mm
8312415	8312425	8312615	8312435	8312455			500 mm
8312416	8312426	8312616	8312436	8312456			600 mm
4x	4x	4x	6x	4x	2x		

P31+ H = 25 mm cloison de séparation			Angle universel	Plaque de montage rapide	Plaque de montage universelle	Plaque de montage horizontale <sup>(4)</sup>	Largeur
Largeur 75 mm	Largeur 100 mm	Largeur 200 mm					
VG480045	VG480046	VG480048	8312490	8312010	8235200	8312020	200 - 600 mm
Fixer avec colliers de câblage Colring			2x		2x		

#### Application plaque de montage connexion enfichable

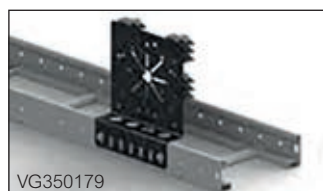

Systèmes de suspension (p. 894)

Collier de câblage Colring (voir [www.e-catalog.be](http://www.e-catalog.be))