
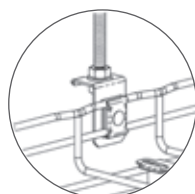


| Constructions E30 - E90 | | | | | | | Largeur en mm |
|-------------------------|---|---------------------------------|--------------------------------|---|--------------------------------------|-------------------------------------|---------------|
| SF50 | Support U55 Galvanisé à chaud | Console CSN/CSNC mur/plafond | Console CB | Support de montage pour tige filetée | Tige filetée M10 longueur 1000 mm | Tige filetée M8 longueur 1000 mm | |
| | | | | | | | |
| CM586140 | - | - | - | - | - | 8234008 | 50 mm |
| - | VG348362 jusqu'à VG348372 (p. 943) | - | VG350810 | VG350122 | 8234000 | - | 100 mm |
| - | | - | VG350820 | | | - | 150 mm |
| - | | - | VG350830 | | | - | 200 mm |
| - | | - | VG350840 | | | - | 300 mm |
| - | | - | VG350850 | | | - | 400 mm |
| - | - | - | VG350810 | - | 8234000 | - | 100 mm |
| - | - | - | VG350820 | - | | - | 150 mm |
| - | - | - | VG350830 | - | | - | 200 mm |
| - | - | - | VG350840 | - | | - | 300 mm |
| - | - | - | VG350850 | - | | - | 400 mm |
| - | - | CM556310 ou CM556110 | - | - | - | 8234008 | 100 mm |
| - | - | CM556320 ou CM556120 | - | - | - | | 150 mm |
| - | - | CM556330 ou CM556130 | - | - | - | | 200 mm |
| - | 2x M6 x 10 mm ⁽³⁾ | | | - | 2x M10 ⁽⁷⁾ | 2x M8 ⁽⁸⁾ | - |
| - | Plafond : 2x M10 ⁽⁴⁾ | 1x M8 ⁽⁵⁾ | Mur : 1x M8 ⁽⁵⁾ | 2x M8 ⁽⁶⁾ | - | - | - |

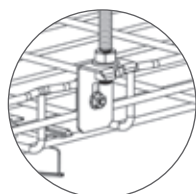

Support de montage pour tige filetée
Fixation au chemin de câbles BRTCC 6x20 (CM801011) + 2x CE35 (CM558180)