


Keuzetabel stalen wandgoot Van Geel GW0 klik-in

85 x 50 mm / 100 x 50 mm / 130A x 50 mm

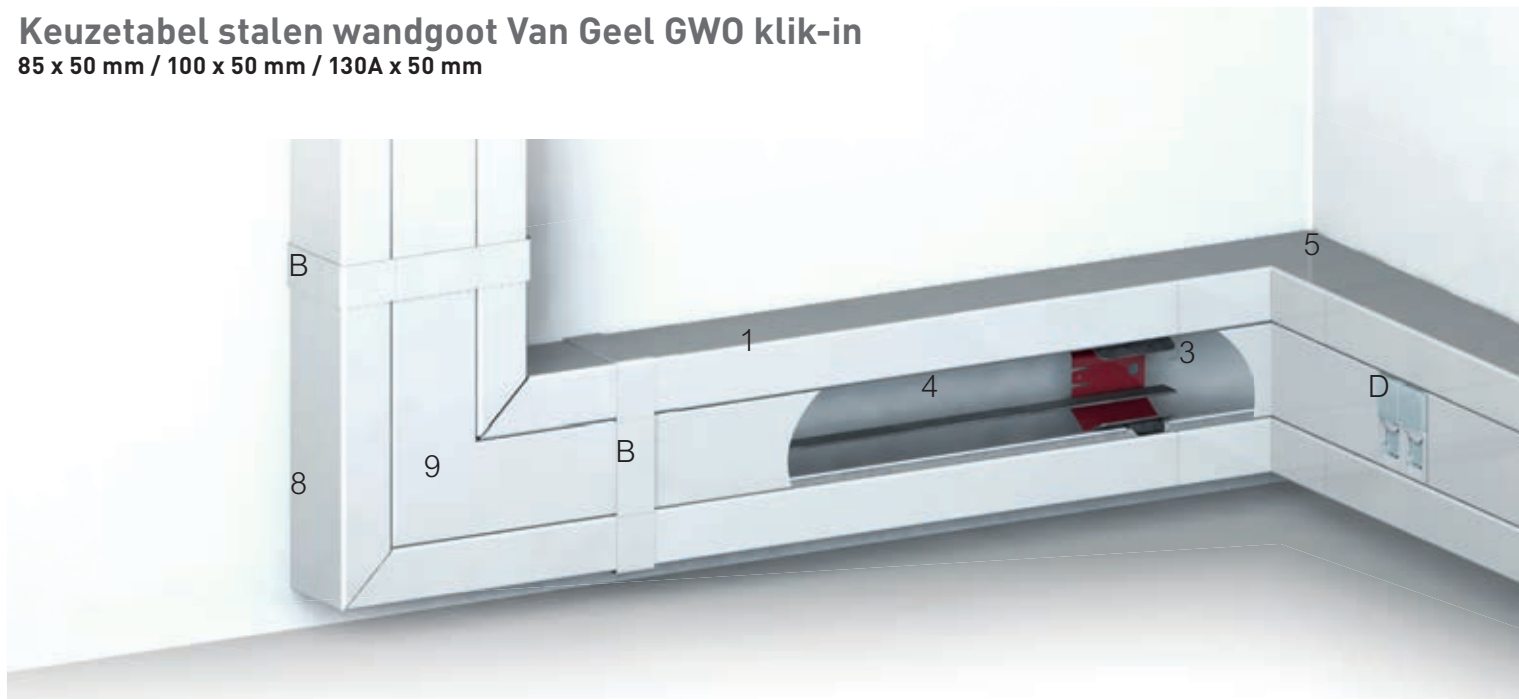

		Type	50 x 85 mm	50 x 100 mm	50 x 130 A
Wandgoot ⁽¹⁾	Lengte: 2000 mm		VG351211	VG351212	VG351214
Deksel	Lengte: 1000 mm		VG351270	VG351270	VG351270
	Lengte: 200 mm		VG351280	VG351280	VG351280
Snapper ⁽³⁾	Tussenschothouder		VG351539	VG351539	VG351539
Tussenschot ⁽⁴⁾	Lengte: 1000 mm gebruiken met 2x referentie VG351539		VG351549	VG351549	VG351549
Koppelset			VG351521	VG351522	VG351524
Binnenhoek ⁽⁵⁾			VG351271	VG351272	VG351274
Buitenhoek ⁽⁶⁾			VG351301	VG351302	VG351304
Deksel buitenhoek ⁽⁷⁾			VG351510	VG351510	VG351510
Platte hoek/zakstuk ⁽⁸⁾			VG351331	VG351332	-
Hoekstijgstuk			-	-	VG351334
Hoekzakstuk			-	-	VG351364
Deksel voor platte hoekzakstuk ⁽⁹⁾			VG351530	VG351530	VG351530
T-stuk ⁽¹⁰⁾			VG351391	VG351392	-
T-stijgstuk	als stijggoot gebruiken met ref. VG351212		-	-	VG351394
Einddeksel			VG351041	VG351042	VG351044
Profielafdichting ⁽¹¹⁾			VG351101	VG351102	VG351104
Zaagmal			VG351531	VG351532	VG351534
Aarddraad			VG351499	VG351499	VG351499