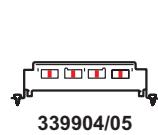
 
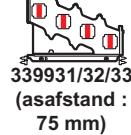
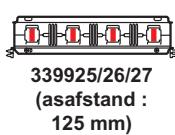
 
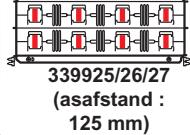


Aluminium C-rails
630

339902/03

339904/05
1600

339920/21/22/23
**(asafstand :
75 mm)**

**339931/32/33
(asafstand :
75 mm)**

**339925/26/27
(asafstand :
125 mm)**
3200

**339920/21/22/23
(asafstand :
75 mm)**

**339925/26/27
(asafstand :
125 mm)**
XL³ S 4000

339902/03 + 339734		339920/23 + 339940 ⁽³⁾	339931 ⁽³⁾		
339902/03 + 339735		339921/23 + 339940	339932	339925/27 + 339940	339921 + 339923 + 339924
339902/03 + 339735		339921/23 + 339940	339932	339925/27 + 339940	339921 + 339923 + 339924
339902/03 + 339736		339922/23 + 339940	339933	339926/27 + 339940	339922 + 339923 + 339924
339902/03 + 339736		339922/23 + 339940	339933	339926/27 + 339940	339922 + 339923 + 339924
339902/03 + 339734		339920/23 + 339940 ⁽³⁾	339931 ⁽³⁾		
339902/03 + 339735		339921/23 + 339940	339932	339925/27 + 339940	339921 + 339923 + 339924
339902/03 + 339735		339921/23 + 339940	339932	339925/27 + 339940	339921 + 339923 + 339924
339902/03 + 339736		339922/23 + 339940	339933	339926/27 + 339940	339922 + 339923 + 339924
339902/03 + 339736		339922/23 + 339940	339933	339926/27 + 339940	339922 + 339923 + 339924
339902/03 + 339734		339920/23 + 339940			
339902/03 + 339735		339921/23 + 339940		339925/27 + 339940	
	339904/05 + 337980				
	339904/05 + 337981				
	339904/05 + 337982				
		339920/23 + 339940 ⁽⁸⁾			
		339921/23 + 339940 ⁽⁸⁾		339925/27 + 339940 ⁽⁸⁾	
		339922/23 + 339940 ⁽⁸⁾		339926/27 + 339940 ⁽⁸⁾	
		339920 + 339940 + 339736 x 2		339925 + 339940 + 339736 x 2	339920 x 2 ⁽⁹⁾ + 339736 x 3
		339920 + 339940 + 339737 x 2		339925 + 339940 + 339737 x 2	339925 x 2 ⁽⁹⁾ + 339737 x 3
		339920 + 339940 + 339730 x 2		339925 + 339940 + 339730 x 2	339925 x 2 ⁽⁹⁾ + 339730 x 3
		339920 + 339940 + 339731 x 2		339925 + 339940 + 339731 x 2	339925 x 2 ⁽⁹⁾ + 339731 x 3
		339920 + 339940 + 339735 x 2		339925 + 339940 + 339735 x 2	339925 x 2 ⁽⁹⁾ + 339735 x 3
		339920 + 339940 + 339736 x 2		339925 + 339940 + 339736 x 2	339925 x 2 ⁽⁹⁾ + 339736 x 3

6 : montage op dwarssteunen in de kast

7 : montage achter stijgprofielen

8 : behalve diepte 400 mm ;

9 : de 2 samengestelde rails worden boven elkaar in de hoogte van de kast geplaatst