


Koperen rails en toebehoren

≤ 4000 A				≤ 6300 A			
rechtopstaande staven		liggende staven		rechtopstaande staven		liggende staven	
I (A)		I (A)		I (A)		I (A)	
IP ≤ 30	IP > 30	IP ≤ 30	IP > 30	IP ≤ 30	IP > 30	IP ≤ 30	IP > 30
-	-	-	-	-	-	-	-
-	-	-	-	-	-	-	-
-	-	-	-	-	-	-	-
-	-	-	-	-	-	-	-
700	630	500	420	-	-	-	-
1180	1020	750	630	-	-	-	-
1600	1380	1000	900	-	-	-	-
2020	1720	1120	1000	-	-	-	-
800	700	600	500	-	-	-	-
1380	1180	750	630	-	-	-	-
1900	1600	1100	1000	-	-	-	-
2350	1950	1350	1200	-	-	-	-
950	850	700	600	-	-	-	-
1600	1400	1000	850	-	-	-	-
2200	1900	1250	1100	-	-	-	-
2700	2300	1600	1400	-	-	-	-
1000	900	750	630	-	-	-	-
1700	1480	1050	900	-	-	-	-
2350	2000	1300	1150	-	-	-	-
2850	2400	1650	1450	-	-	-	-
1250	1050	850	700	-	-	-	-
2050	1800	1200	1050	-	-	-	-
2900	2450	1600	1400	-	-	-	-
3500	2900	1900	1650	-	-	-	-
1450	1270	1000	800	-	-	-	-
2500	2150	1450	1250	-	-	-	-
3450	2900	1800	1600	-	-	-	-
4150	3450	2150	1950	-	-	-	-
1460	1270	1150	950	-	-	-	-
2500	2150	1700	1500	-	-	-	-
3450	2900	2500	2000	-	-	-	-
1750	1500	1350	1150	-	-	-	-
3050	2550	2000	1650	-	-	-	-
4150	3500	2900	2400	-	-	-	-
2000	1750	1650	1450	-	-	-	-
3600	2950	2500	2000	-	-	-	-
4800	4000	3500	3000	-	-	-	-
-	-	-	-	3300	3000	2750	2400
-	-	-	-	5200	4800	3600	3250
-	-	-	-	7000	6400	5400	4800



Ref.	Koperen staven				
	Plat, stijf met schroefgaten				
Doorsnede (mm)	I (A)		Schroefgaten Ø mm	Lengte (mm)	
	IP ≤ 30	IP > 30			
037388	12 x 2	110	80	M5	990
037389	12 x 4	160	125	M5	990
037433	15 x 4	200	160	M6	990
037434	18 x 4	245	200	M6	990
037438	25 x 4	280	250	M6	990
037418	25 x 5	330	270	M6	1750
037419	32 x 5	450	400	M6	1750
Doorsnede (mm)	I (A)		Gaten Ø mm	Lengte (mm)	
	IP ≤ 30	IP > 30			
037440	50 x 5	700	630	10,5 - 6,5	1750
037441	63 x 5	800	700	10,5 - 8,5	1750
037459	75 x 5	950	850	10,5 - 6,5	1750
037443	80 x 5	1000	900	10,5 - 6,5	1750
037446	100 x 5	1250	1050	10,5 - 6,5	1750
Soepel					
Plat geleverd, lengte 2 m					
Doorsnede (mm)	I (A)				
	IP ≤ 30	IP > 30			
037410	13 x 3	200	160		
037467	20 x 5	400	250		
037411	24 x 4	400	250		
037412	32 x 5	630	400		
037457	50 x 5	850	630		
037458	50 x 10	1250	1000		

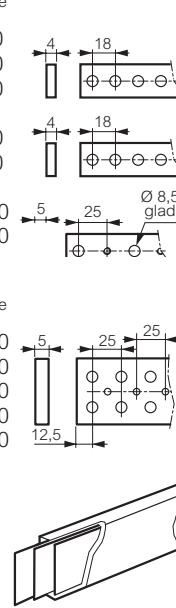

Geoptimaliseerde verdeling Aluminium railstellen VX³ Zie blz. 235

