


Plexo³ wandkasten

afmetingen, technische kenmerken


■ Afmetingen

Kasten 2, 4, 6 en 8 modules

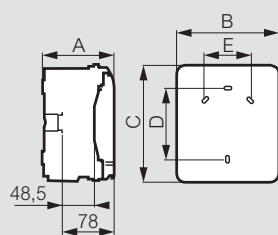


Ref.	Afmetingen (mm)				
	A	B	C	D	E
601932	109	93	174	94	-
601954	115,6	128	200	120	-
601956	115,6	164	200	120	70
601958	115,6	200	200	120	106

Kasten 12 en 18 modules

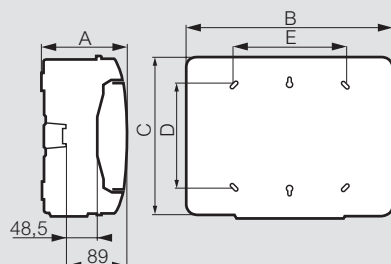


Ref.	Afmetingen (mm)				
	A	B	C	D	E
601961 414033	141	340	282	180	180
601962 414034	161	340	432	330	180
601963	161	340	622	480	180
601965 414035	141	448	282	180	288
601966 414036	161	448	432	330	290
601967 414037	161	448	622	480	290
601968 414038	161	448	822	680	290

 ■ Multifunctionele mantels



Ref.	Afmetingen (mm)		Aantal posities
	A	B	
001917	137	432	3
001918	137	622	4

■ Hartafstand voor montage Plexo³ apparatuur (ref. 001971)

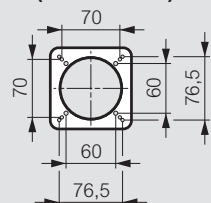

■ Aantal uitdrukopeningen aan elke kant

Ref.	Boven/onder			Links/rechts		
	Ø 20 mm	Ø 25 mm	Ø 32 mm	Ø 20 mm	Ø 25 mm	Ø 32 mm
601932	2	-	-	-	-	-
601954	2	1	-	2	-	-
601956	4	1	-	2	-	-
601958	6	1	-	2	-	-
601961	7	2	2	-	-	2
601962	13	2	2	-	-	3
601963	13	2	2	-	-	4
601965	12	2	3	-	-	2
601966	13	4	3	-	-	3
601967	13	4	3	-	-	4
601968	13	4	3	-	-	5

■ Aantal met de kasten meegeleverde sluitdoppen

Ref.	Aantal modules van 17,5 mm	Aantal sluitdoppen
601932	2 (+1)	2
601954	4	3
601956	6	5
601958	8	7
601961	1x12	10
601962	2x12	16
601963	3x12	16
601965	1x18	14
601966	2x18	16
601967	3x18	18
601968	4x18	18

■ Capaciteit van de IP 2x aardingsklemmenblokken met schroefaansluiting

Ref.	Aantal modules van 17,5 mm	Koosklemmen
601932	2 (+1)	/
601954	4	1x(4x16 ²)
601956	6	1x(4x16 ²)
601958	8	1x(8x16 ²)
601961	1x12	1x(1x25 ² + 12x16 ²)
601962	2x12	1x(1x25 ² + 16x16 ²)
601963	3x12	1x(1x25 ² + 21x16 ²)
601965	1x18	1x(1x25 ² + 16x16 ²)
601966	2x18	1x(1x25 ² + 21x16 ²)
601967	3x18	1x(1x25 ² + 26x16 ²)
601968	4x18	1x(1x25 ² + 34x16 ²)