

Thermisch beheer van wand- en vloerkasten (vervolg)


■ Klimaatregelaars (vervolg)

Technische kenmerken van de klimaatregelaars

Verticale klimaatregelaars										
Referenties	035346	035347	035348	035349	035350	035351	035353	035354	035355	035356
Koelvermogen (W)	380	640	820	1250	1600	2000	3850	1600	2000	3850
L35L35/EN 814										
L35L50/EN 814	240	470	680	910	1230	1510	2870	1230	1510	2870
Spanning (V/fase)	230/1	230/1	230/1	230/1	230/1	230/1	230/1	400/2	400/3	400/3
Frequentie (Hz)	50/60	50/60	50/60	50/60	50/60	50/60	50/60	50/60	50/60	50/60
Opgenomen vermogen (W)	330	470	490	760	940	1290	1990	960	1150	2050
Stroomverbruik (A) werking	1,6	2,1	2,6	3,8	5,3	6,5	9,5	2,9	2,5	3,6
Stroomverbruik (A) inschakeling	6	8,1	10,8	11	18	24	35,2	11	10	18
Debiet binnenluchtcircuit (m³/u)	280	330	330	570	570	860	1450	570	860	1450
Debiet buitenluchtcircuit (m³/u)	280	570	570	860	1050	1050	1450	1050	1050	1450
Hoeveelheid koelmiddel R134a (kg)	0,11	0,2	0,14	0,38	0,45	0,42	1,05	0,45	0,59	1,05
IP binnencircuit	54	54	54	54	54	54	54	54	54	54
IP buitencircuit¹⁾	24	24	24	24	24	24	24	24	24	24
Geluidsniveau (dB)	60	65	65	65	65	65	70	65	65	70
Afm. : H x B x D (mm)	460 x 285 x 176	605 x 315 x 209	783 x 348 x 213	999 x 406 x 237	999 x 406 x 237	999 x 406 x 237	1270 x 500 x 335	999 x 406 x 237	999 x 406 x 237	1270 x 500 x 325
Massa (kg)	17	21	27	38	40	52	82	42	54	85

■ Warmtewisselaars

Afmetingen en uitsnijmaten (mm)

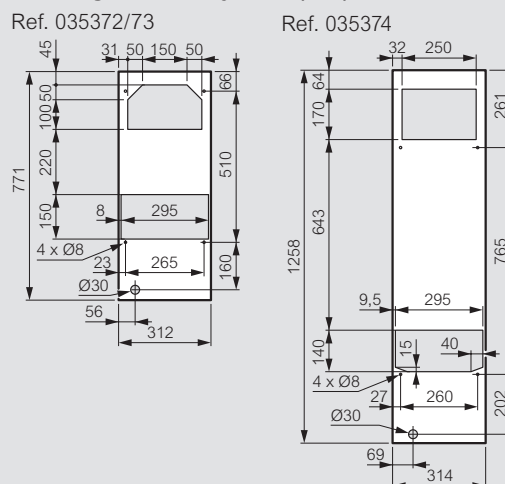

Technische kenmerken van de warmtewisselaars

Lucht/luchtwisselaars			
Referenties	035372	035373	035374
Specifiek vermogen (W/°C)	36	50	80
Spanning (V)	230	230	230
Frequentie (Hz)	50/60	50/60	50/60
Opgenomen vermogen (W)	140	140	240
Stroomverbruik (A)	0,64	0,64	1,06
Debiet binnenluchtcircuit (m³/u)	570	600	1050
Debiet buitenluchtcircuit (m³/u)	570	600	1050
IP binnencircuit	54	54	54
IP buitencircuit	24	24	24
Geluidsniveau (dB)	67	67	75
Afm. H x B x D (mm)	771 x 316 x 93	771 x 316 x 93	1260 x 317 x 108
Massa (kg)	10	10	17

Klimaatregelaars voor op het dak							
Referenties	035358	035359	035360	035362	035363	035364	035365
Koelvermogen (W)	1150	1550	2050	3850	1550	2050	3850
L35L35/EN 814							
L35L50/EN 814	900	1200	1560	2870	1200	1560	2870
Spanning (V/fase)	230/1	230/1	230/1	230/1	400/2	400/3	400/3
Frequentie (Hz)	50/60	50/60	50/60	50/60	50/60	50/60	50/60
Opgenomen vermogen (W)	660	930	1300	1950	940	1190	1890
Stroomverbruik (A) werking	3,2	4,5	6	9	2,8	1,9	3,4
Stroomverbruik (A) inschakeling	11	18	24	38,2	9,6	10	17
Debiet binnenluchtcircuit (m³/u)	570	860	1050	1450	860	1050	1450
Debiet buitenluchtcircuit (m³/u)	1010	1820	1820	3410	1820	1820	3410
Hoeveelheid koelmiddel R134a (kg)	0,63	0,8	1,05	1,8	0,8	0,55	1,6
IP binnencircuit	54	54	54	54	54	54	54
IP buitencircuit¹⁾	24	24	24	24	24	24	24
Geluidsniveau (dB)	65	65	65	75	65	65	75
Afm. : H x B x D (mm)	415 x 567 x 401	415 x 567 x 401	415 x 567 x 401	487 x 777 x 492	415 x 567 x 401	415 x 567 x 401	487 x 777 x 492
Massa (kg)	40	44	50	83	46	52	86

1 : IP 34 mogelijk: contacteer ons

■ Dimensionale compatibiliteit

Montage	Klimaatregelaar												Warmtewisselaar																
	Lateraal						Achteraan			Deuren			Dak ²⁾			Lateraal	Achteraan	Deuren											
	035346	035347	035348	035349	035350/54	035351/55	035353/56	035346	035347	035348	035349	035350/54	035351/55	035353/56	035358	035359/63	035360/64	035362/65	035372	035373	035374	035372	035373	035374	035372	035373	035374		
Hoogte	1600	1600	1600	1600	1600	1600	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800	1800		
Breedte	600	800	1000	1000 ¹⁾	1200	1200	600	800	1000	1000 ¹⁾	1200	1600	600	800	1000	1000 ¹⁾	1200	1600	600	800	1000 ¹⁾	1200	1600	600	800	1000 ¹⁾	1200	1600	
Diepte	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400	400

1 : 2 deuren - 2: Klimaatregelaar voor op het dak: de klimaatregelaar niet tussen 2 vloerkasten zetten (hijstringen)

Compatibele montage