


Toebehoren UPS

bekabelingsschema externe bypass verdeelborden


■ Schakelschema

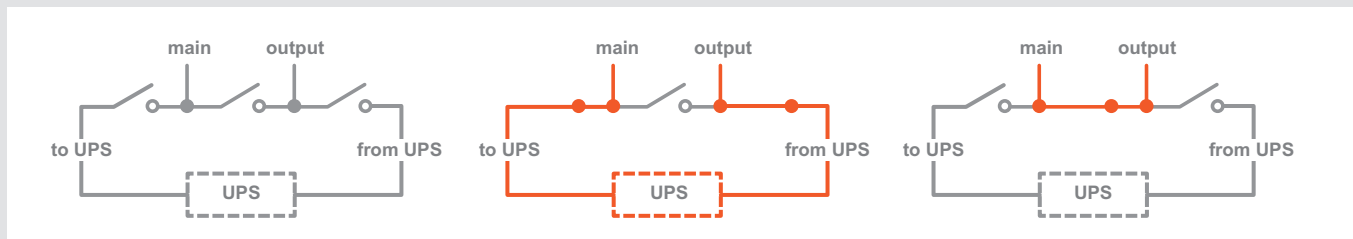

Kabelinvoer onderzijde

Kabelinvoer bovenzijde

Kabelinvoer onder- en bovenzijde

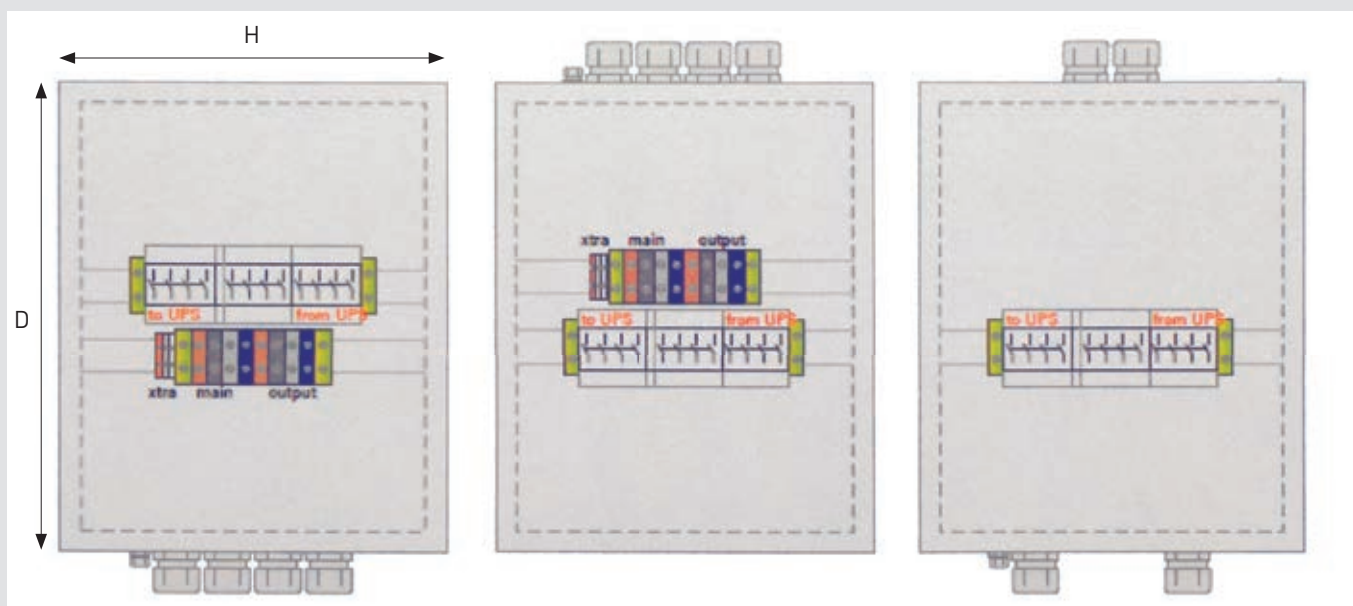

Referenties	Nom. stroomsterkte (A)	Hoogte (H) (mm)	Breedte (B) (mm)	Diepte (mm)	Aansluitingen
350291/371/379	20	300	300	155	≤ 10mm ²
350292/372/380	32	300	300	155	≤ 10mm ²
350293/373/381	40	300	300	155	≤ 16mm ²
350294/374/382	63	400	300	210	≤ 35mm ²
350295/375/383	100	500	400	210	≤ 35mm ²
350296/376/384	125	500	400	210	≤ 35mm ²
350297/377/385	160	800	600	250	Bout M8/M8
350298/378/386	250	800	800	300	Bout M8/M10