

Uurstanden volgens EN 60309-2



Ref. 057704 met noodstopknop, toestelcontactdoos en vergrendelde half-inbouwcontactdozen



Ref. 057720 met vergrendelde half-inbouwcontactdozen


HALF-INBOUWCONTACTDOZEN

ZLS (blz. 534)		IP 44			
20/25 V~	16 A	2P	055245		
	32 A	2P	055295		
Huishoudelijke aansluiting (blz. 534)		IP 54 ⁽³⁾			
250 V	16 A	2P+A	057671/72		
LS (blz. 532)		IP 44			
200/250 V~	16 A	2P+A	555184		555384
	32 A	2P+A	555284	555484	
	63 A	2P+A	-	555584	
380/415 V~	16 A	3P+A	555188	555388	
		3P+N+A	555189	555389	
	32 A	3P+A	555288	555488	
		3P+N+A	555289	555489	
	63 A	3P+A	-	555588	
		3P+N+A	-	555589	

HALF-INBOUWCONTACTDOZEN

ZLS (blz. 534)		IP 44			
20/25 V~	16 A	2P	055245		
	32 A	2P	055295		
Huishoudelijk aansluiting (blz. 534)		IP 54 ⁽³⁾			
250 V	16 A	2P+A	057671/72		
LS (blz. 532)		IP 44			
200/250 V~	16 A	2P+A	555184		555384
	32 A	2P+A	057300 ⁽⁵⁾	057320 ⁽⁶⁾	
	63 A	2P+A	-	555584	
380/415 V~	16 A	3P+A	555188	555388	
		3P+N+A	555189	555389	
	32 A	3P+A	555288	555488	
		3P+N+A	555289	555489	
	63 A	3P+A	-	555588	
		3P+N+A	-	555589	

Uurstanden volgens EN 60309-2

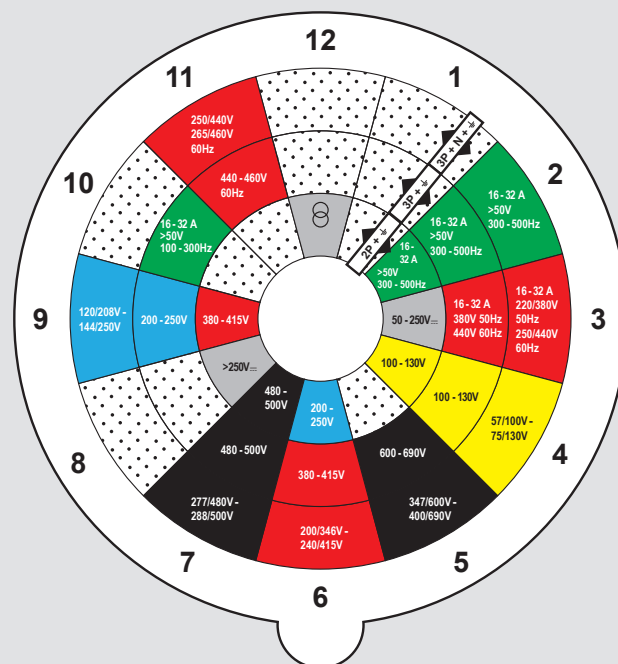

Deze uurstanden zijn niet genormeerd en daardoor vrij beschikbaar