


WANDBEVESTIGING										
Type	Breedte	Draadgoot		Montage- beugel UC 50	Muurbeugel CAT 40	Beugel CM 50	Universele beugel CM 50XL	Wandconsole CSN auto	Wandconsole CB	Wand-/plafond beugel CSNC
CF 54	50 mm	CM000061		CM586040	CM586190	CM586060	CM586130		VG350800	CM556300
	100 mm	CM000071						CM556100	VG350810	CM556310
	150 mm	CM000081						CM556110	VG350820	CM556320
	200 mm	CM000091						CM556120	VG350830	CM556330
	300 mm	CM000101						CM556130	VG350840	CM556340
	400 mm	CM000201						CM556140	VG350850	
	500 mm	CM000301							VG350860	
	600 mm	CM000401							VG350870	
CF 30	50 mm	CM000011		CM586040	CM586190				VG350800	CM556300
	100 mm	CM000021						CM556100	VG350810	CM556310
	150 mm	CM000031						CM556110	VG350820	CM556320
	200 mm	CM000041						CM556120	VG350830	CM556330
	300 mm	CM000051						CM556130	VG350840	CM556340
	400 mm	CM000801						CM556140	VG350850	
	500 mm	CM000811							VG350860	
	600 mm	CM000851							VG350870	
CF 105	100 mm	CM000891							VG350810	CM556300
	150 mm	CM000901							VG350820	CM556310
	200 mm	CM000911							VG350830	CM556320
	300 mm	CM000921							VG350840	CM556330
	400 mm	CM000931							VG350850	CM556340
	500 mm	CM000941							VG350860	
	600 mm	CM001031							VG350870	

CF150 = H150 mm op aanvraag

Overige draadgoten **blz. 866**

Koppelingen **blz. 868**

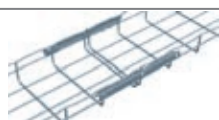

Dekfels en scheidingschotten **blz. 871**



Wijze van installeren **blz. 876**